

# THIN-FILM PRESSURE SENSOR

## 100 mV OUTPUT

### EXCELLENT LONG-TERM STABILITY

## PX602/PX612 Series

0-15 to 0-20,000 psi  
0-1.0 to 0-1379 bar



Starts at  
**\$220**

- ✓ All Stainless Steel Case
- ✓ Small and Lightweight
- ✓ NEMA 4 (IP65) Cable or Connector Models

### SPECIFICATIONS

Excitation: 10 Vdc (5 to 10 Vdc limits)

Output: 0 to 100 mV @ 10 Vdc

Sensitivity: 10 mV/V

Input Impedance: 1500 Ω

Output Impedance: 100 Ω

Insulation Resistance: 100 MΩ @50 Vdc

Accuracy: ±0.4% BFSL

Hysteresis: ±0.2%

Repeatability: ±0.05%

Stability: ±1%/year

Zero Balance: ±1%

Durability: 100 million cycles

Operating Temp: -48 to 91°C (-55 to 195°F)

Compensated Temp: -29 to 82°C (-20 to 180°F)

Thermal Zero Effect: ±0.07% FS/°C

Thermal Span Effect: ±0.07% FS/°C

Proof Pressure:

15 to 2000 psi = 200%

3000 to 5000 psi = 150%

7500 to 20,000 psi = 120%

Burst Pressure:

15 to 2000 psi = 800%

3000 to 20,000 psi = 500%

Gages: Thin film polysilicon

Diaphragm: 17-4 PH stainless steel

Case: 300 Series stainless steel

Pressure Connection:

15 to 10,000 psi: ¼ NPT

15,000 and 20,000 psi: ⅝-18

UNF Aminco fitting

Electrical Connection: 0.9 m (36")

braided-shield PVC cable or connector

Weight: 71 g (2.5 oz.) without cable

Response time: 5 ms


Construction: Sealed units (except PX602 ≤ 500 psi is vented to room)

PX612-100GV,  
connector  
style, \$245.


PX602-1KGV,  
cable style,  
\$220.

PT06F8-4S mating  
connector, \$24,  
sold separately.

 PS-4 snubbers  
sold separately.



¼ NPT Pressure Snubbers: \$10  
PS-4G = Gas PS-4E = Lt Oil  
PS-4D = Dense Lq

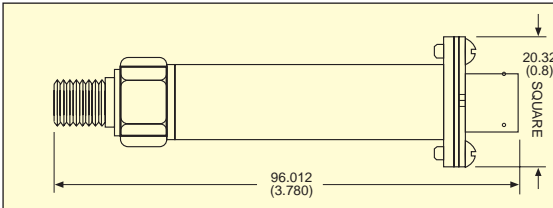

Connections  
Pin Wire  
A Red +Exc  
B Green +Out  
C Black -Out  
D White -Exc



books1.com  
omega.com

MILLIVOLT OUTPUT  
PRESSURE TRANSDUCERS  
**B**

**MOST POPULAR MODELS HIGHLIGHTED!**

### To Order (Specify Model Number)

RANGE		MODEL NO. [ ] Insert 0 or 1	PRICE PX602	PRICE PX612	COMPATIBLE METERS**
psi	bar				
0 to 15	0 to 1.0	PX6[ ] 2-015GV	\$230	\$260	DP41-S, DP25B-S, DP302-S
0 to 30	0 to 2.1	PX6[ ] 2-030GV	230	260	DP41-S, DP25B-S, DP302-S
0 to 60	0 to 4.1	PX6[ ] 2-060GV	220	245	DP41-S, DP25B-S, DP302-S
0 to 100	0 to 6.9	PX6[ ] 2-100GV	220	245	DP41-S, DP25B-S, DP302-S
0 to 150	0 to 10.3	PX6[ ] 2-150GV	220	245	DP41-S, DP25B-S, DP302-S
0 to 200	0 to 13.8	PX6[ ] 2-200GV	220	245	DP41-S, DP25B-S, DP302-S
0 to 300	0 to 20.7	PX6[ ] 2-300GV	220	245	DP41-S, DP25B-S, DP302-S
0 to 500	0 to 34.5	PX6[ ] 2-500GV	220	245	DP41-S, DP25B-S, DP302-S
0 to 1000	0 to 68.9	PX6[ ] 2-1KGV	220	245	DP41-S, DP25B-S, DP302-S
0 to 2000	0 to 138	PX6[ ] 2-2KGV	220	245	DP41-S, DP25B-S, DP302-S
0 to 3000	0 to 207	PX6[ ] 2-3KGV	220	245	DP41-S, DP25B-S, DP87
0 to 5000	0 to 345	PX6[ ] 2-5KGV	220	245	DP41-S, DP25B-S, DP87
0 to 7500	0 to 517	PX6[ ] 2-7.5KGV	220	245	DP41-S, DP25B-S, DP87
0 to 10,000	0 to 689	PX6[ ] 2-10KGV	250	275	DP41-S, DP25B-S, DP87
0 to 15,000	0 to 1034	PX6[ ] 2-15KGV*	260	290	DP41-S, DP87
0 to 20,000	0 to 1379	PX6[ ] 2-20KGV*	260	290	DP41-S, DP87

Comes with complete operator's manual.

\* 15,000 and 20,000 psi models supplied with female Aminco fitting.

\*\* See section D for compatible meters.

Ordering Examples: PX612-100GV, 100 psi connector-style transducer, \$245.

PX602-100GV, 100 psi cable-style transducer, \$220. DP41-S, meter, \$545.

PT06F8-4S, mating connector (sold separately), \$24. PS-4, snubber, \$10.

### ACCESSORY

MODEL NO.	PRICE	DESCRIPTION
GE-2117	\$23	Reference Book: Controller Tuning PID Without Math

# omega.co.uk<sup>®</sup>

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

[www.omega.co.uk](http://www.omega.co.uk)



#### UNITED STATES

[www.omega.com](http://www.omega.com)

1-800-TC-OMEGA  
Stamford, CT.

#### UNITED KINGDOM

[www.omega.co.uk](http://www.omega.co.uk)

Manchester, England  
0800-488-488  
+44-(0)161-777-6611

#### CANADA

[www.omega.ca](http://www.omega.ca)

Laval(Quebec)  
1-800-TC-OMEGA

#### FRANCE

[www.omega.fr](http://www.omega.fr)

0800-466-342

#### GERMANY

[www.omega.de](http://www.omega.de)

Deckenfronn, Germany  
0800-8266342

#### BENELUX

[www.omega.nl](http://www.omega.nl)

0800-099-33-44



## More than 100,000 Products Available!

### • Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

### • Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

### • pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

### • Data Acquisition

Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485, Ethernet and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

### • Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

### • Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters