

RTD Extension Cables


Starts at
£10

- ✓ Retractable Cables Have 300mm and 1.2m Initial Lengths with 5:1 Stretch
- ✓ Set-Length Extension Cables Provided in 3m and 7.5m Standard Lengths
- ✓ 3 Conductor Cables are Standard, 2 Conductor Cables are Provided When Ordered with 2-Pin Connectors Installed
- ✓ 3 Standard Cable Constructions Available
- ✓ Standard and Mini Quick Disconnect Connectors and

Retractable Extension Cables

Ordering Code	Description
OTP-U-M	3-Pin standard Plug
OTP-U-F	3-Pin standard Socket
MTP-U-M	3-Pin miniature Plug
MTP-U-F	3-Pin miniature Socket
OST-U-M	2-Pin standard Plug
OST-U-F	2-Pin standard Socket
SMP-U-M	2-Pin miniature Plug
SMP-U-F	2-Pin miniature Socket
TA3M	Series T, male†
TA3F	Series T, female†

† Add £20 to cost of cable for each end with Series T.

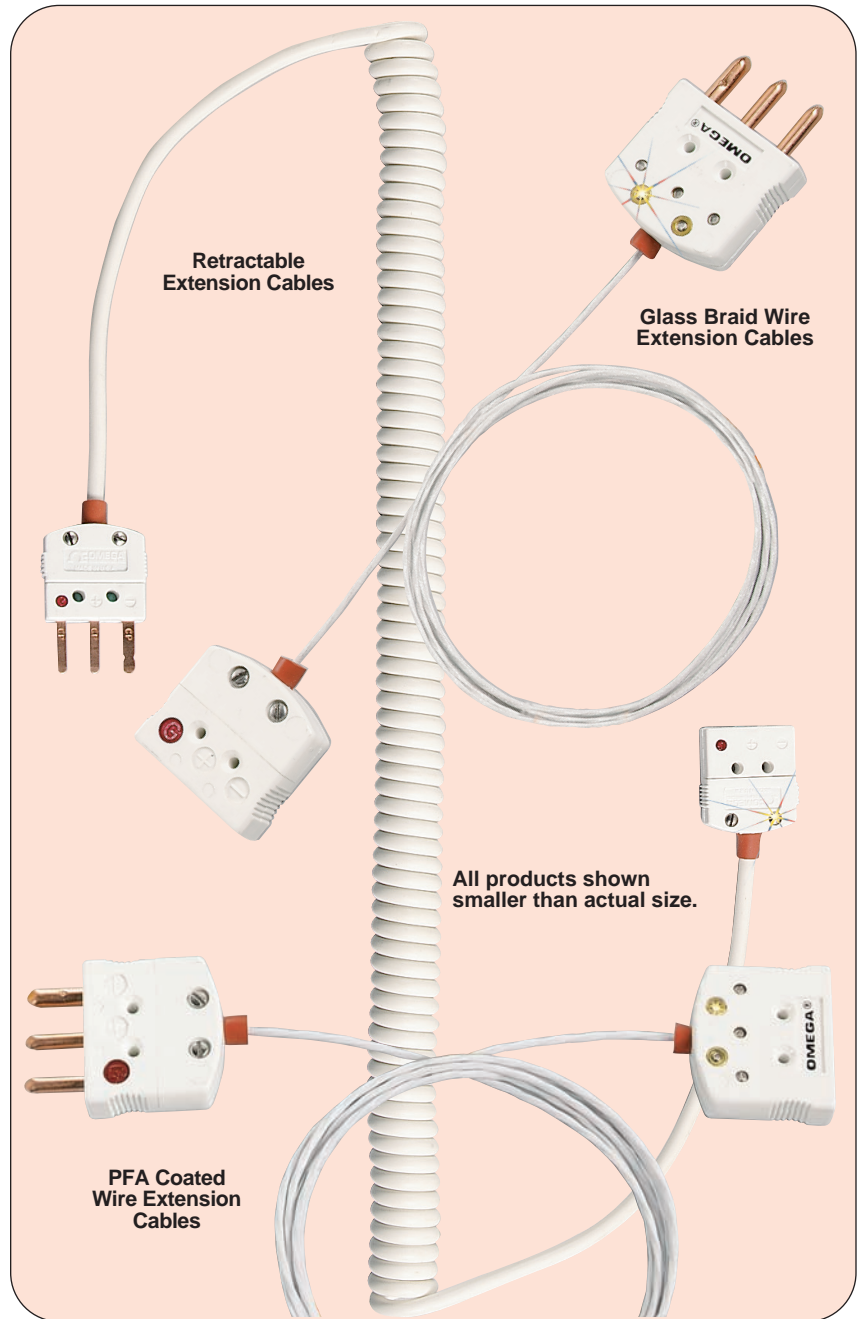

MOST POPULAR MODELS HIGHLIGHTED!

To Order (Specify Model Number)			
Model No.	Price	Description	Length
RECU1-(-)-(-)	£12.50	3 core TPE jacketed retractable extension cable	300mm, unstretched
RECU4-(-)-(-)	22.50	3 core TPE jacketed retractable extension cable	1.2m, unstretched
GECU10-(-)-(-)	10.00	3 core fibreglass insulated and jacketed cable	3m
GECU25-(-)-(-)	20.00	3 core fibreglass insulated and jacketed cable	7.5m
TECU10-(-)-(-)	10.00	3 core PFA insulated and jacketed cable	3m
TECU25-(-)-(-)	20.00	3 core PFA insulated and jacketed cable	7.5m

(*) If connectors are to be installed onto the cables, please insert the connection codes here.

Notes:
 RECU cables contain three core 7/0.13mm stranded copper wire with PFA insulation and TPE jacket. Temperature range is -30 to 150°C. Expansion ratio is 5:1.
 GECU cables contain three core 7/0.16mm nickel plated copper conductors with fibreglass insulation and fibreglass jacket. Temperature range is -73 to 482°C.
 TECU cables contain three core 7/0.16mm nickel plated copper conductors with PFA insulation and jacket. Temperature range is -267 to 260°C.

Ordering examples: RECU1-MTP-U-F-MTP-U-M, RECU1 cable with a MTP 3-pin plug on one end and a MTP socket on the other end, £12.50



UNITED STATES

www.omega.com

1-800-TC-OMEGA

Stamford, CT.

CANADA

www.omega.ca

Laval(Quebec)

1-800-TC-OMEGA

GERMANY

www.omega.de

Deckenpfronn, Germany

0800-8266342

UNITED KINGDOM

www.omega.co.uk

Manchester, England

0800-488-488

FRANCE

www.omega.fr

088-466-342

CZECH REPUBLIC

www.omegaeng.cz

Karviná, Czech Republic

596-311-899

BENELUX

www.omega.nl

0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Auto-Dialers and Alarm Monitoring Systems, Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485 and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters