




DISCONNECT AND FUSE SCREW CONNECTION TERMINAL BLOCKS


ASK T-BLOCK Series Starts at \$2.30_{ea} for pack of 20

- Allows For Circuit to Be “Opened” Without Removing the Wire
- Enhanced Troubleshooting with LED Fuse Blown Indicators
- Sized for 5 x 20 mm, 5 x 25 mm or 1¼ x ¼" Fuses
- Screw Connection for Secure, Maintenance Free Connection
- Self-Locking Zinc Plated Wire Clamps
- Full Line of Accessories: End Plate, Cross Connectors and Marking Tags

The ASK disconnect or fuse terminals allow a circuit to be “opened” without disconnecting the wire from the screw connections. These terminal blocks have screw connections for reliable and secure connections. The ASK-2S or ASK-2LD fuse terminals will hold 5 x 20 mm or 5 x 25 mm. The ASK-4S or ASK-4LD fuse terminals will hold a 1¼ x ¼" fuses. They're available for 24 Vdc or 110 Vac. The “LD” models come with an LED blown fuse indicator. The ASK-3 A terminal is useful for analog circuits such as the 4 to 20 mA signals, the circuit can be opened the input or output currents can easily be read with a multimeter.

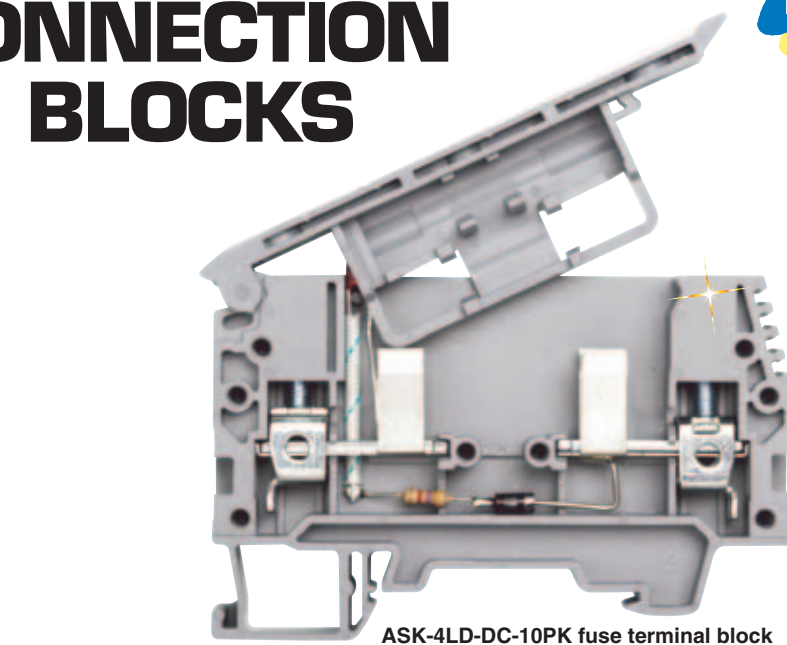


ASK-4LD-DC-10PK fuse terminal block with LED blown fuse indicator for 1¼ x ¼" fuse, \$65 for pack of 10.

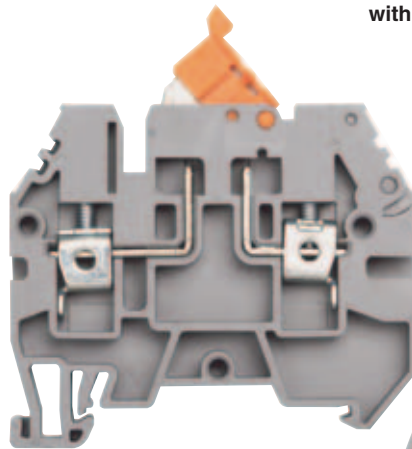

ASK-3A-20PK feed through disconnect terminal block, \$46 for pack of 20.

ASK-2LD-DC-10PK fuse terminal block with LED blown fuse indicator for 5 x 20 mm and 5 x 25 mm fuse, \$48 for pack of 10.

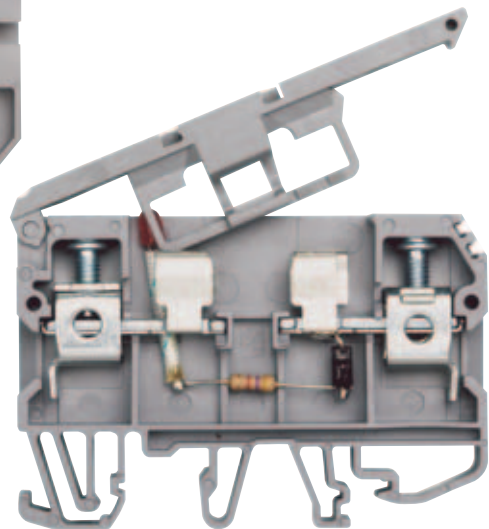

All models shown actual size.

SPECIFICATIONS

ELECTRICAL RATINGS	ASK-3A	ASK-2S	ASK-2LD	ASK-4S	ASL-4LD
Voltage/Current	500V/24 A	500V/6.3 A	500V/6.3 A	750V/6.3 A	750V/6.3 A
UL	600V/16 A	300V/6.3 A	300V/6.3 A	600V/6.3 A	600V/6.3 A
Insulation Strip Length	10 mm	12 mm	12 mm	12 mm	12 mm
AWG	26-10	26-8	26-8	22-8	22-8
Width	6 mm	8 mm	8 mm	10 mm	10 mm
End Plate-Partition	ASK-3A-EP	ASK-2-EP	ASK-2-EP		
Cross-Connectors/2	OM-476239				
Cross-Connectors/3	OM-476233				
Cross-Connectors/4	OM-476234				
Cross-Connectors/10	OM-476235				



OM-476234-10PK 4-position jumper for ASK-3A terminal block, \$18.25 for pack of 10, shown larger than actual size.

To Order (Specify Model Number)

MOST POPULAR MODELS HIGHLIGHTED!

FEED THROUGH TERMINAL BLOCKS					
MODEL NO.	PRICE	AMPS	AWG	FUSE SIZE	DESCRIPTION
ASK-3A-20PK	\$46	16	26-10		Disconnect feed through terminal blocks, 20 per pack
ASK-3A-10PK	30	16	26-10		Disconnect feed through terminal blocks, 10 per pack
ASK-2S-10PK	33	6.3	26-8	5 x 20 and 5 x 25 mm	300V fuse terminal blocks, 10 per pack
ASK-2S-25PK	68	6.3	26-8	5 x 20 and 5 x 25 mm	300V fuse terminal blocks, 25 per pack
ASK-2LD-AC-10PK	48	6.3	26-8	5 x 20 and 5 x 25 mm	110 Vac fuse terminal blocks with LED blown fuse indicator, 10 per pack
ASK-2LD-DC-10PK	48	6.3	26-8	5 x 20 and 5 x 25 mm	24 Vdc fuse terminal blocks with LED blown fuse indicator, 10 per pack
ASK-4S-25PK	120	6.3	22-8	1¼ x ¼"	600V fuse terminal blocks, 25 per pack
ASK-4S-10PK	60	6.3	22-8	1¼ x ¼"	600V fuse terminal blocks, 10 per pack
ASK-4LD-AC-10PK	65	6.3	22-8	1¼ x ¼"	110 Vac fuse terminal blocks with LED blown fuse indicator, 10 per pack
ASK-4LD-DC-10PK	65	6.3	22-8	1¼ x ¼"	24 Vdc fuse terminal blocks with LED blown fuse indicator, 10 per pack

ACCESSORIES

MODEL NO.	PRICE	PCS/PACK	DESCRIPTION
ASK-2-EP-10PK	\$7.00	10	End plate-partition for ASK-2S and 2LD
ASK-3A-EP-10PK	7.00	10	End plate-partition for ASK-3A
T-BLK-EB-10PK	5.00	10	DIN rail end bracket 10 pieces per pack
CROSS CONNECTORS			
MODEL NO.	PRICE	PCS/PACK	DESCRIPTION
OM-476232-10PK	\$7.50	10	2 position screw connection jumper for ASK-3A terminals
OM-476233-10PK	12.00	10	3 position screw connection jumper for ASK-3A terminals
OM-476234-10PK	18.25	10	4 position screw connection jumper for ASK-3A terminals
OM-476239-3PK	15.00	3	10 position screw connection jumper for ASK-3A terminals
MARKING TAGS			
MODEL NO.	PRICE	PCS/PER CARD	DESCRIPTION
MKR-NO-PRINT	\$3.00	50	Marking tag without print
MKR-1-10	3.00	50	Marking tag 1 to 10
MKR-11-20	3.00	50	Marking tag 11 to 20
MKR-1-50	3.00	50	Marking tag 1 to 50
MKR-51-100	3.00	50	Marking tag 51 to 100
MKR-101-150	3.00	50	Marking tag 101 to 150
MKR-151-200	3.00	50	Marking tag 151 to 200
MKR-201-250	3.00	50	Marking tag 201 to 250

Ordering Examples: ASK-3A-10PK, pack of 10 disconnect terminal blocks for 26-10 AWG rated for 16 A, plus ASK-3A-EP-10PK, pack of 10 end plates, and T-BLK-EB-10PK, pack of 10 DIN rail end brackets, \$30 + 7 + 5 = \$42.
 ASK-2LD-DC-10PK, pack of 10 fuse block terminal blocks with LED blown fuse indicator for 5 x 20 mm and 5 x 25 mm fuses, 6.3 A and 26-8 AWG, \$48.

omega.co.uk[®]

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

www.omega.co.uk



UNITED STATES

www.omega.com

1-800-TC-OMEGA
Stamford, CT.

UNITED KINGDOM

www.omega.co.uk

Manchester, England
0800-488-488
+44-(0)161-777-6611

CANADA

www.omega.ca

Laval(Quebec)
1-800-TC-OMEGA

FRANCE

www.omega.fr

0800-466-342

GERMANY

www.omega.de

Deckenfronn, Germany
0800-8266342

BENELUX

www.omega.nl

0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485, Ethernet and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters