

GENERAL PURPOSE AIR FILTER/REGULATORS FOR COMPRESSED AIR

NEW

B07 Series
Starts at
\$54⁵⁰

Most
Economical

B07-202-A1KA,
\$54.50, shown
smaller than
actual size.

- Full Flow Gauge Ports
- Excellent Flow and Regulation Characteristics
- High Efficiency Oil and Partial Removal
- 5 Micron Filter Element
- ¼" PTF Gauge Ports
- Maximum Pressure 10 bar (150 psig)
- Transparent Polycarbonate Bowl

General purpose air filter/regulators are designed for in-line use as a single regulating control filtering source for compressed air. These air regulator/filters are full flow ported for excellent flow and regulation characteristics. They include ¼" PTF threads, a transparent bowl, relieving diaphragm, gauge, automatic drain and a 0.3 to 7 bar (5 to 100 psig) pressure adjustment range. They are suitable for a wide range of pneumatic tools and components and an excellent point of use filter/regulator. These units can be panel mounted with a 30 mm (1.19") diameter mounting hole or can be used with the optional bracket and panel nut.

SPECIFICATIONS

Operating Temperature*:
-34 to 50°C (30 to 125°F)

Maximum Pressure: 10 bar (150 psig)

Materials:

Body: Zinc

Bonnet: Acetal

Bowl: Transparent Polycarbonate


Valve Seat: Acetal

Element :

B07: Sintered polypropylene

B39: Synthetic fiber and polyurethane foam

* Air supply must be dry enough to avoid ice formation at temperatures below 2°C (35°F)

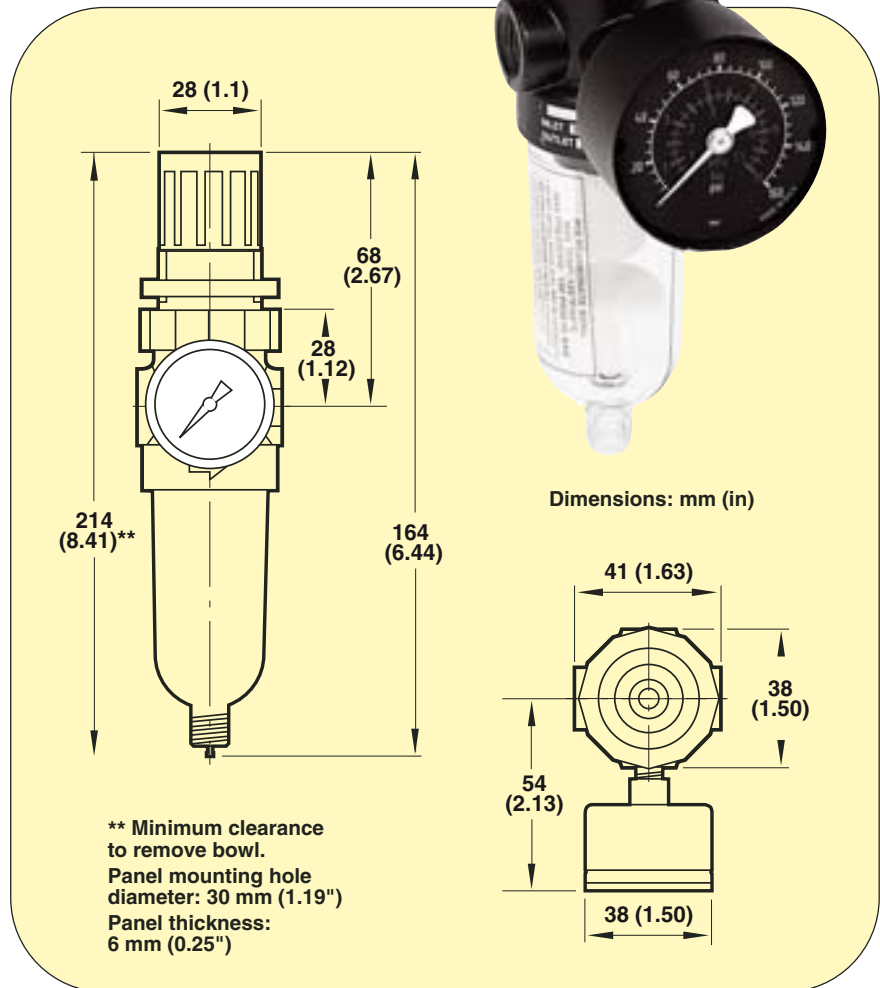

To Order (Specify Model Number)

AVAILABLE FOR FAST DELIVERY!

MODEL NO.	PRICE	PORT (in)	FLOW dm ³ /s (scfm)	WEIGHT kg (lb)
B07-202-A1KA	\$54.50	¼	6.5 (14)	0.26 (0.57)
B39-202-A0KA	95.00	¼	1.9 (4.0)	0.26 (0.57)
ACCESSORY				
OM-AIR-18-025-003	\$6.25	Mounting bracket and plastic panel nut		

Ordering Example: B07-202-A1KA, general purpose air filter/regulator with ¼" port and transparent bowl and OM-AIR-18-025-003, mounting bracket with panel nut, \$54.50 + 6.25 = \$60.75.

omega.co.uk[®]

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

www.omega.co.uk



UNITED STATES

www.omega.com

1-800-TC-OMEGA

Stamford, CT.

CANADA

www.omega.ca

Laval(Quebec)

1-800-TC-OMEGA

GERMANY

www.omega.de

Deckenpfronn, Germany

0800-8266342

UNITED KINGDOM

www.omega.co.uk

Manchester, England

0800-488-488

FRANCE

www.omega.fr

088-466-342

CZECH REPUBLIC

www.omegaeng.cz

Karviná, Czech Republic

596-311-899

BENELUX

www.omega.nl

0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Auto-Dialers and Alarm Monitoring Systems, Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485 and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters