


# DIN RAIL INTERFACE MODULES

**NEW**

DSUB Series  
Starts at  
**\$58**

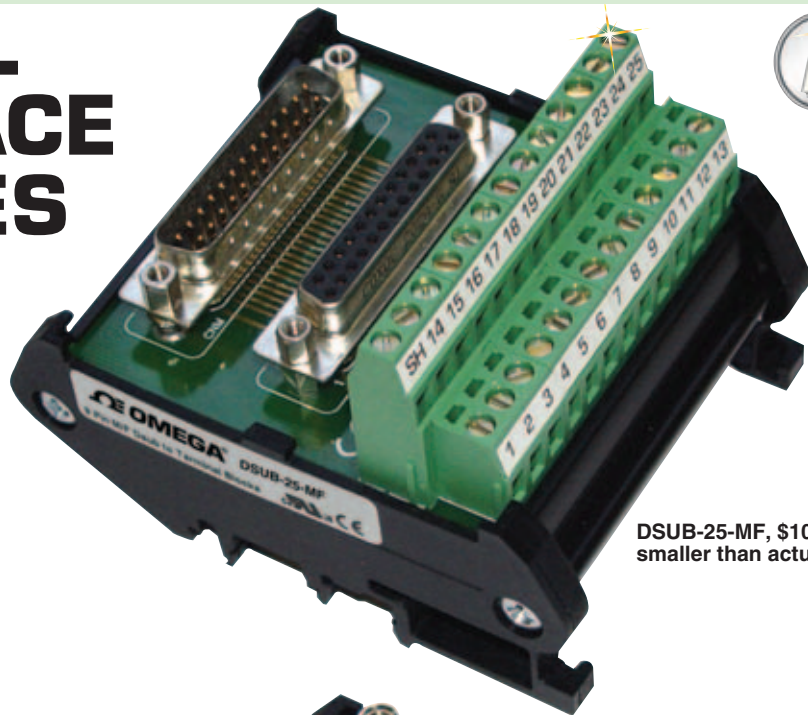

DSUB-25-MF, \$102, shown smaller than actual size.

- D-Subminiature Connectors
- 9-Pin, 15-Pin, and 25-Pin Models
- Male and Female Connectors
- Optional D-SUB Cables Available

The DSUB Series of DIN rail mounted interface modules provides a reliable “plug and play” interface for any industrial control system. Users can attach field wiring from the terminal blocks to their industrial control panel and then simply plug in their controller. These modules come with both male and female D-sub connectors for maximum flexibility.



DSUB-9-MF, \$58, shown larger than actual size.

## To Order (Specify Model Number)

**AVAILABLE FOR FAST DELIVERY!**

| MODEL NO.  | PRICE | DESCRIPTION                       |
|------------|-------|-----------------------------------|
| DSUB-9-MF  | \$58  | DIN rail interface module, 9-pin  |
| DSUB-15-MF | 80    | DIN rail interface module, 15-pin |
| DSUB-25-MF | 102   | DIN rail interface module, 25-pin |

## TECHNICAL DATA – INTERFACE MODULES

**Maximum Current:** 1 A

**Wire Range:** 22 – 14 AWG

**Operating Temperature:** -10 to 50°C  
(14 to 122°F)

### Dimensions:

**DSUB-9-MF:** 39 W x 93 L x 63 mm H  
(1.53 x 3.66 x 2.48")

**DSUB-15-MF:** 49 W x 93 L x 63 mm H  
(1.93 x 3.66 x 2.48")

**DSUB-25-MF:**  
73 W x 93 L x 63 mm H  
(2.87 x 3.66 x 2.48")

## ACCESSORIES

| MODEL NO.      | PRICE | DESCRIPTION  |
|----------------|-------|--|
| DSUB-9-MF-CBL  | \$25  | DSUB cable, 9-pin, 2 m (6.6'), male/female connectors  |
| DSUB-15-MF-CBL | 25    | DSUB cable, 15-pin, 2 m (6.6'), male/female connectors |
| DSUB-25-MF-CBL | 27    | DSUB cable, 25-pin, 2 m (6.6'), male/female connectors |

**Ordering Example:** DSUB-9-MF, DIN rail mount interface module, 9-pin, DSUB-9-MF-CBL, DSUB cable, 9-pin, \$58 + 25 = \$83.

# omega.co.uk<sup>®</sup>

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

[www.omega.co.uk](http://www.omega.co.uk)



#### UNITED STATES

[www.omega.com](http://www.omega.com)

1-800-TC-OMEGA  
Stamford, CT.

#### CANADA

[www.omega.ca](http://www.omega.ca)

Laval(Quebec)  
1-800-TC-OMEGA

#### GERMANY

[www.omega.de](http://www.omega.de)

Deckenfronn, Germany  
0800-8266342

#### UNITED KINGDOM

[www.omega.co.uk](http://www.omega.co.uk)

Manchester, England  
0800-488-488  
+44-(0)161-777-6611

#### FRANCE

[www.omega.fr](http://www.omega.fr)

0800-466-342

#### BENELUX

[www.omega.nl](http://www.omega.nl)

0800-099-33-44



## More than 100,000 Products Available!

### • Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

### • Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

### • pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

### • Data Acquisition

Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485, Ethernet and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

### • Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

### • Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters