



FUSE ACCESSORIES

BM Series
Starts at
\$31
Pack of 10



BM Series fuse blocks are compatible with the Edison MCL, MEQ, MEN, and MOL and for use with any 1/2 x 1/2" fuses.

SPECIFICATIONS

CLASS M SUPPLEMENTARY FUSEBLOCKS

Construction: Thermoplastic, UL flammability; 94 V



Shown smaller than actual size.

Ratings: 600 Vac, 30 A

Agency Approvals:

UL Recognized, Guide IZLT2, File E14853; CSA, Class 6225-01, File 47235

To Order (Specify Model Number)

MOST POPULAR MODELS HIGHLIGHTED!

MODEL NO.	PRICE	PKG	POLES
BM6031PQ-10PK	\$31	10	1
BM6032PQ-8PK	44	8	2
BM6033PQ-6PK	60	6	3

Comes with instruction sheet.

Ordering Example: BM6032PQ-10PK, 2 pole fuse blocks, package of 10, \$31.

R250 Series
Starts at
\$5



These R250 Series fuse blocks are compatible with Class R fuses, such as: Edison LENRK and ECNR.


SPECIFICATIONS

Construction: Thermoplastic, UL flammability; 94 V

Ampere Ratings: 1/10 to 600 A

Voltage Ratings: H250, 250 Vac; H600, 600 Vac; R250, 250 Vac; R600, 600 Vac

Agency Approvals: UL Listed, Guide IZLT, File E14853; CSA, Class 6225-01, File 47235

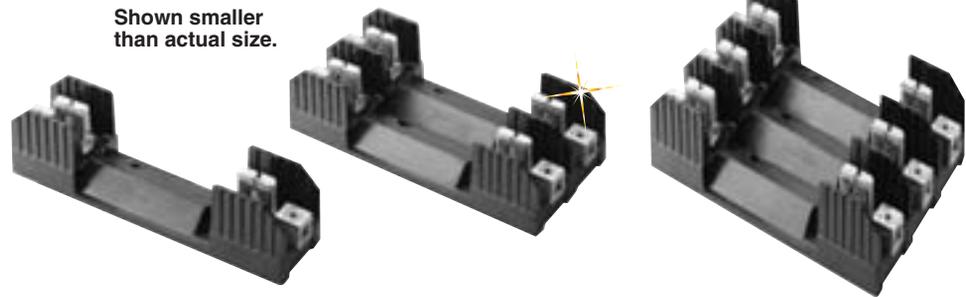

Shown smaller than actual size.

To Order (Specify Model Number)

MOST POPULAR MODELS HIGHLIGHTED!

MODEL NO.	PRICE	POLES
FUSE BLOCK ACCESSORIES FOR 250V		
R25030-1SR	\$5.00	1
R25030-2SR	7.50	2
R25030-3SR	11.00	3
R25060-1CR	10.00	1
R25060-2CR	19.00	2
R25060-3CR	27.00	3

Note: SR is a Screw type, clip with reinforced spring, CR is a Box lug type, clip with reinforced spring.

Comes with instruction sheet.

Ordering Example: R25030-1SR, screwtype fuse block, 1 pole, \$5.

FP Series
Starts at
\$9



FP-2, \$9.



FP-3, \$10.

Shown smaller than actual size.

Fusepullers

The FP-2 and FP-3 are tools to help easily remove fuses. FP-2 is for 1/2 to 1/16" diameter fuses. FP-3 is for 1 to 1/4" diameter fuses.

To Order (Specify Model Number)

MOST POPULAR MODELS HIGHLIGHTED!

MODEL NO.	PRICE	DESCRIPTION - FUSE DIAMETERS AND TYPES
FP-2	\$9	1/2 to 1/16", 0 to 60 A, 250 V and 0 to 30 A, 600 V
FP-3	10	1 to 1/4", 70 to 200 A, 250 V and 35 to 200 A, 600 V

Comes with instruction sheet.

Ordering Example: FP-2, 1/2 to 1/16" fuse puller, \$9.



UNITED STATES

www.omega.com
1-800-TC-OMEGA
Stamford, CT.

CANADA

www.omega.ca
Laval(Quebec)
1-800-TC-OMEGA

GERMANY

www.omega.de
Deckenpfronn, Germany
0800-8266342

UNITED KINGDOM

www.omega.co.uk
Manchester, England
0800-488-488

FRANCE

www.omega.fr
Guyancourt, France
088-466-342

CZECH REPUBLIC

www.omegaeng.cz
Karviná, Czech Republic
596-311-899

BENELUX

www.omega.nl
Amstelveen, NL
0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Glass Bulb Thermometers, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders Relative Humidity Measurement Instruments, RTD Probes, Elements and Assemblies, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples Thermowells and Head and Well Assemblies, Transmitters, Wire

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Auto-Dialers and Alarm Monitoring Systems, Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485 and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Strain Gages, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters