



FAST ACTING FUSES

Starts at
\$36
Pkg of 10



Fast Acting 600V Fuse

- Compact Dimensions
- High Interrupting Rating
- Fast-Acting Design Responds Quickly to Both Overloads and Short-Circuit Current

A fast-acting, high-interrupting capacity, current-limiting type fuse. The MCL style fuse feature provides an excellent choice for applications such as: street lighting holders, HID lighting, control circuits, electronic equipment protection.

SPECIFICATIONS

Dimensions: $\frac{1}{2}$ " ferrule, 1.5" length

Weight: Approx 0.2 lbs

Voltage Rating: MCL - 600 Vac

Ampere Rating: .1 to 50 A

Interrupting Rating: 100 K RMS amps

Agency Approvals: (0.1 to 30) UL Listed to 198G, File E162443; (0.1 to 30) CSA Cert. C22.2 Part 59.2, LR700489

Fast Acting 250V Fuse

- Compact Dimensions
- Economical Laminated Paper Tube Design

The MOL is an economical solution for over current protection. The MOL style fuse feature provides an excellent choice for applications such as: supplemental protection for noninductive control and lighting circuits.

SPECIFICATIONS

Dimensions: $\frac{1}{2}$ " ferrule, 1.5" length


Weight: Approx 0.2 lbs

Voltage Rating: MOL - 250 Vac

Ampere Rating: 0.5 to 30 A

Interrupting Rating: 10 K RMS amps

Agency Approvals: (0.5 - 30) UL Listed to 198G, File E162443; (0.5 - 30) CSA Cert. C22.2 Part 59.2, LR700489

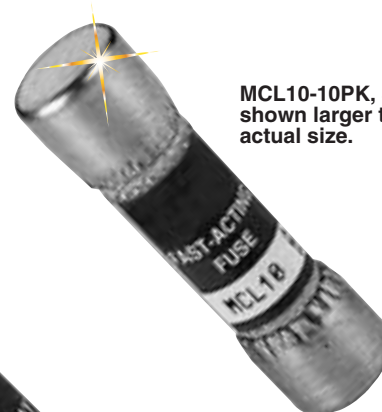

MCL10-10PK, \$37.50, shown larger than actual size.



MEQ30-10PK, \$44.25, shown larger than actual size.

To Order (Specify Model Number)

MODEL NO.	PKG. OF 10	AMP RATING
MCL.5-10PK	40.75	0.5
MCL1-10PK	37.50	1
MCL1.5-10PK	40.75	1.5
MCL2-10PK	37.50	2
MCL2.5-10PK	45.50	2.5
MCL3-10PK	37.50	3
MCL3.5-10PK	47.75	3.5
MCL4-10PK	38.50	4
MCL5-10PK	37.50	5
MCL6-10PK	36.00	6

MOST POPULAR MODELS HIGHLIGHTED!

MODEL NO.	PKG. OF 10	AMP RATING
MCL8-10PK	\$38.50	8
MCL10-10PK	37.50	10
MCL12-10PK	43.25	12
MCL15-10PK	37.50	15
MCL20-10PK	37.50	20
MCL25-10PK	37.50	25
MCL30-10PK	37.50	30
MCL35-10PK	47.75	35
MCL40-10PK	43.25	40
MCL50-10PK	49.00	50

MODEL NO.	PKG. OF 10	AMP RATING
MEQ.25-10PK	50.00	0.25
MEQ.5-10PK	46.75	0.5
MEQ1-10PK	44.25	1
MEQ1.5-10PK	46.75	1.5
MEQ2-10PK	44.25	2
MEQ2.5-10PK	46.75	2.5
MEQ3-10PK	44.25	3
MEQ3.5-10PK	50.00	3.5
MEQ4-10PK	44.25	4
MEQ4.5-10PK	53.75	4.5

MODEL NO.	PKG. OF 10	AMP RATING
MEQ5-10PK	44.25	5
MEQ6-10PK	44.25	6
MEQ7-10PK	46.75	7
MEQ8-10PK	44.25	8
MEQ10-10PK	44.25	10
MEQ12-10PK	44.25	12
MEQ15-10PK	44.25	15
MEQ20-10PK	44.25	20
MEQ25-10PK	44.25	25
MEQ30-10PK	44.25	30

Comes with instruction sheet.

Ordering Example: MCL10-10PK, 10 A fuse, package of 10, \$37.50.

TIME DELAY FUSES



Time-Delay 500V Fuses

- Compact Dimensions
- Fiber Tube Construction
- Time-Delay Allows Harmless Inductive Surges to Pass Without Needless Fuse Opening

The MEQ midget class time delay fuse is ideal for the many applications including supplemental protection of transformers, solenoids, and other high inrush circuits.

SPECIFICATIONS

Dimensions: 13/32" ferrule, 1.5" length

Weight: Approx 0.2 lbs

Voltage Rating: MEQ - 500 Vac

Ampere Rating: 0.1 to 30 A

Interrupting Rating: 10 K RMS amps

Agency Approvals: (0.1 - 30) UL Listed to 198G, File E162443; (0.1 - 30) CSA Cert. C22.2 Part 59.2, LR700489

Time-Delay 250V Fuses

- Compact Dimensions
- Fiber Tube Construction
- Dual-Element Construction Allows Harmless Inductive Surges to Pass Without Opening

The MEN midget class time delay fuse is ideal for the many applications including supplemental protection of small motors, transformers, solenoids, and other high inrush power electronic circuits.

SPECIFICATIONS

Dimensions: 13/32" ferrule, 1.5" length

Weight: Approx 0.2 lbs

Voltage Rating: MEN - 250 Vac

Ampere Rating: 0.5 to 30 A

Interrupting Rating: 10K RMS amps @ 125 V

Agency Approvals: UL Listed to 198G, File E162443; CSA Cert. C22.2 Part 59.2, LR700489



MEN10-10PK, \$16.25, shown actual size.



MOL10-10PK, \$8.25, shown larger than actual size.

To Order (Specify Model Number)

MODEL NO.	PKG. OF 10	AMP RATING
MEN.5-10PK	\$18.75	0.5
MEN.6-10PK	18.75	0.6
MEN1-10PK	17.50	1
MEN1.4-10PK	22.50	1.4
MEN1.5-10PK	18.75	1.5
MEN2-10PK	16.25	2
MEN2.5-10PK	17.50	2.5
MEN3-10PK	16.25	3
MEN3.5-10PK	16.25	3.5
MEN4-10PK	16.25	4
MODEL NO.	PKG. OF 10	AMP RATING
MOL.5-10PK	\$11.50	0.5
MOL1-10PK	9.25	1
MOL1.5-10PK	11.50	1.5
MOL2-10PK	9.25	2
MOL2.5-10PK	11.50	2.5
MOL3-10PK	9.25	3
MOL4-10PK	11.50	4
MOL5-10PK	9.25	5

MOST POPULAR MODELS HIGHLIGHTED!

MODEL NO.	PKG. OF 10	AMP RATING
MEN5-10PK	\$16.25	5
MEN6-10PK	17.50	6
MEN7-10PK	16.25	7
MEN8-10PK	16.25	8
MEN10-10PK	16.25	10
MEN12-10PK	18.75	12
MEN15-10PK	16.75	15
MEN20-10PK	17.50	20
MEN25-10PK	18.75	25
MEN30-10PK	17.50	30
MODEL NO.	PKG. OF 10	AMP RATING
MOL6-10PK	\$9.25	6
MOL8-10PK	9.25	8
MOL10-10PK	8.25	10
MOL15-10PK	8.25	10
MOL20-10PK	11.50	20
MOL25-10PK	11.50	25
MOL30-10PK	10.00	30

Comes with instruction sheet.

Ordering Example: MOL10-10PK, 10 A fuse, package of 10, \$8.25.



UNITED STATES

www.omega.com

1-800-TC-OMEGA
Stamford, CT.

CANADA

www.omega.ca

Laval(Quebec)
1-800-TC-OMEGA

GERMANY

www.omega.de

Deckenpfronn, Germany
0800-8266342

UNITED KINGDOM

www.omega.co.uk

Manchester, England
0800-488-488

FRANCE

www.omega.fr

Guyancourt, France
088-466-342

CZECH REPUBLIC

www.omegaeng.cz

Karviná, Czech Republic
596-311-899

BENELUX

www.omega.nl

Amstelveen, NL
0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Glass Bulb Thermometers, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders Relative Humidity Measurement Instruments, RTD Probes, Elements and Assemblies, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples Thermowells and Head and Well Assemblies, Transmitters, Wire

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Auto-Dialers and Alarm Monitoring Systems, Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485 and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Strain Gages, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters