



NEMA TYPE 12 PUSHBUTTON ENCLOSURES

**SCE-PB Series
Starts at
\$45**



- 0.075" Carbon Steel
- Continuously Welded Seams
- Captivated Cover Screws Thread Into Sealed Wells
- 4-Way Pushbutton Holes Accept all Brands of Oil-Tight Pushbuttons, Switches and Pilot Lights
- Hole Diameter is 30.5 mm (1.20")
- Immediate Removal of Cover is Permitted
- Oil-Resistant Gasket

Application


Designed to offer protection for oil-tight pushbuttons, switches, and pilot lights from dust, water, dirt and oil.

Finish


ANSI-61 gray powder over phosphatized surfaces.

Industry Standards



NEMA Type 12 & Type 13
UL Listed Type 12
CSA Type 12
IEC 60529 IP 55

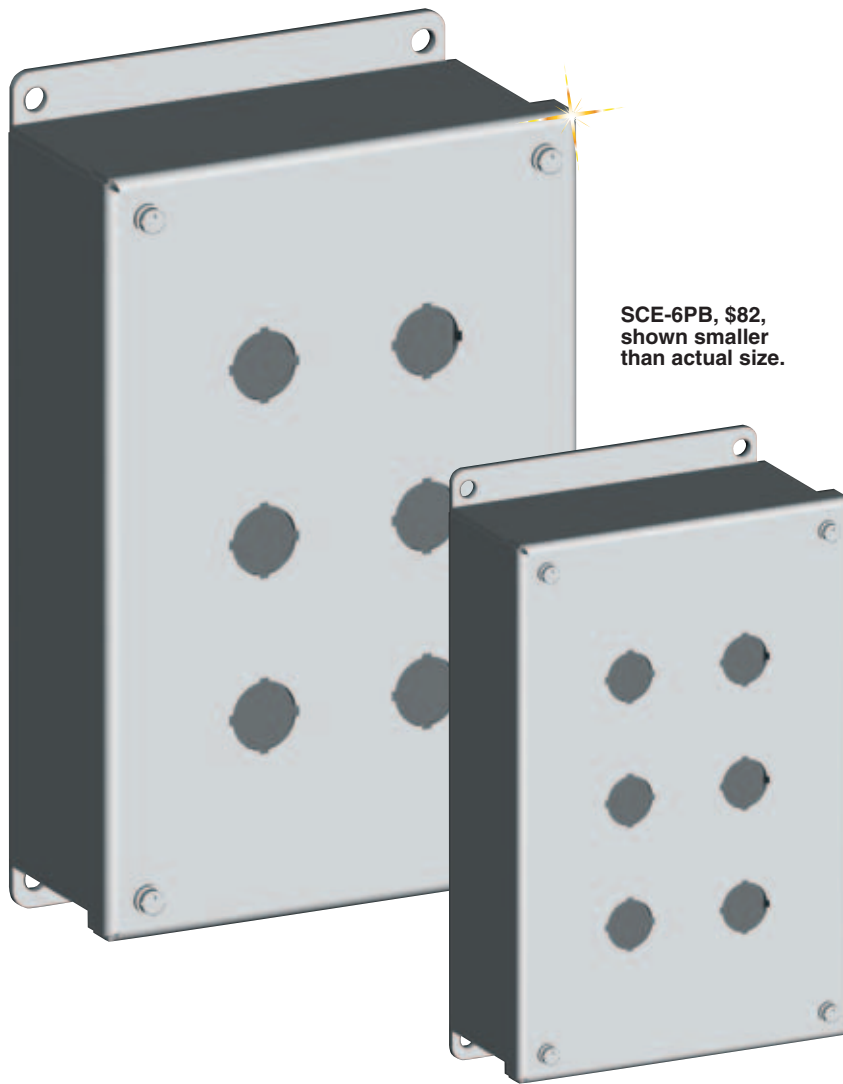


SCE-6PB, \$82, shown smaller than actual size.

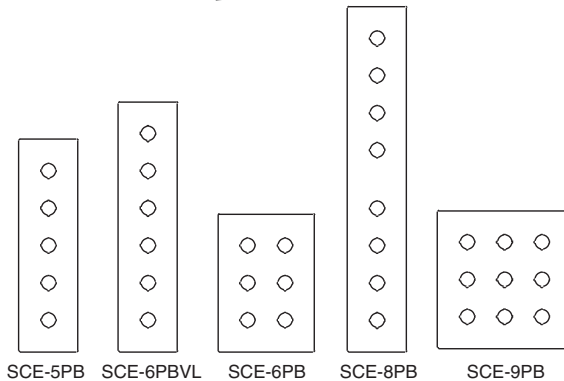


Type 12 Pushbutton Enclosures - Hole Arrangements

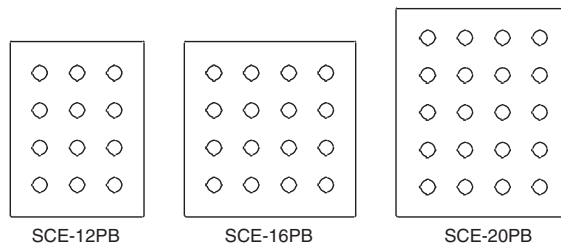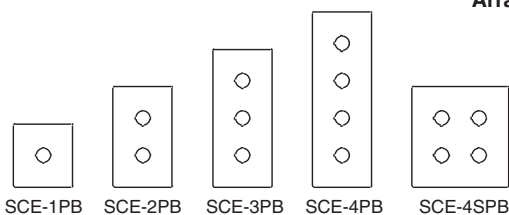


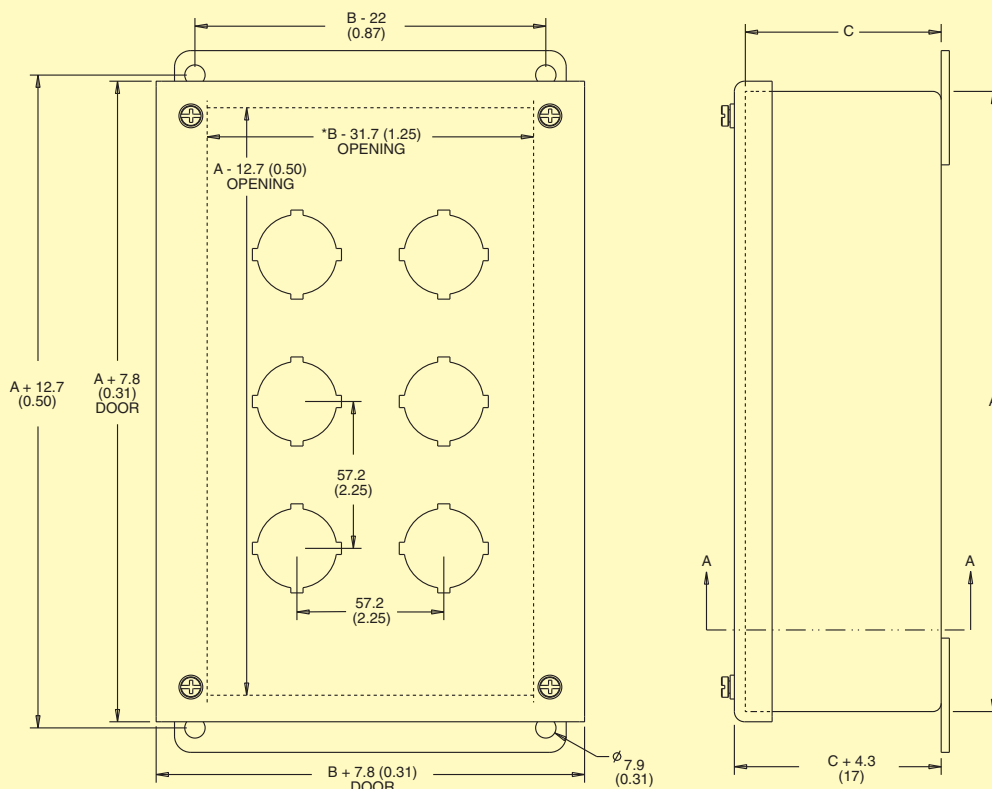

NOTE:
*B - 12.7 (0.50) ONE COLUMN OF PUSHBUTTONS

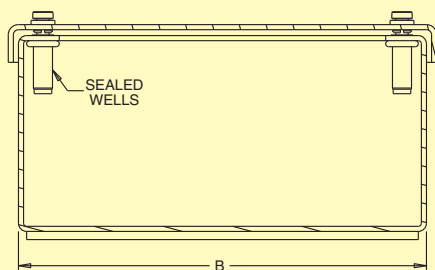

SECTION A-A

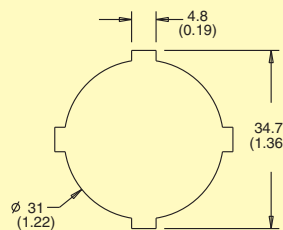

STANDARD 4-WAY

Ø = diameter
Dimensions: mm (in)

To Order (Specify Model Number)

MOST POPULAR MODELS HIGHLIGHTED!

MODEL NO.	PRICE	DESCRIPTION	HEIGHT (in) (A)	WIDTH (in) (B)	DEPTH (in) (C)
SCE-1PB	\$45	Type 12 30.5 mm pushbutton enclosures	3.50	3.25	2.75
SCE-2PB	51	Type 12 30.5 mm pushbutton enclosures	5.75	3.25	2.75
SCE-3PB	58	Type 12 30.5 mm pushbutton enclosures	8.00	8.00	2.75
SCE-4PB	64	Type 12 30.5 mm pushbutton enclosures	10.25	3.25	2.75
SCE-4SPB	72	Type 12 30.5 mm pushbutton enclosures	7.25	6.25	3.00
SCE-5PB	70	Type 12 30.5 mm pushbutton enclosures	12.50	3.25	2.75
SCE-6PB	82	Type 12 30.5 mm pushbutton enclosures	9.50	6.25	3.00
SCE-6PBVL	77	Type 12 30.5 mm pushbutton enclosures	14.75	3.25	2.75
SCE-8PB	92	Type 12 30.5 mm pushbutton enclosures	20.25	3.25	2.75
SCE-9PB	95	Type 12 30.5 mm pushbutton enclosures	9.50	8.50	3.00
SCE-12PB	106	Type 12 30.5 mm pushbutton enclosures	11.75	8.50	3.00
SCE-16PB	123	Type 12 30.5 mm pushbutton enclosures	11.75	10.75	3.00
SCE-20PB	133	Type 12 30.5 mm pushbutton enclosures	14.00	10.75	3.00

Ordering Examples: SCE-1PB, Type 12, 30.5 mm, pushbutton enclosure, 3.50 H x 3.25 W x 2.75" D, \$45.
SCE-4PB, Type 12, 30.5 mm pushbutton enclosure, 10.25 H x 3.25 W x 2.75" D, \$64.

omega.co.uk[®]

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

www.omega.co.uk



UNITED STATES

www.omega.com

1-800-TC-OMEGA
Stamford, CT.

UNITED KINGDOM

www.omega.co.uk

Manchester, England
0800-488-488
+44-(0)161-777-6611

CANADA

www.omega.ca

Laval(Quebec)
1-800-TC-OMEGA

FRANCE

www.omega.fr

0800-466-342

GERMANY

www.omega.de

Deckenfronn, Germany
0800-8266342

BENELUX

www.omega.nl

0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485, Ethernet and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters