







FEED THROUGH TERMINAL BLOCKS

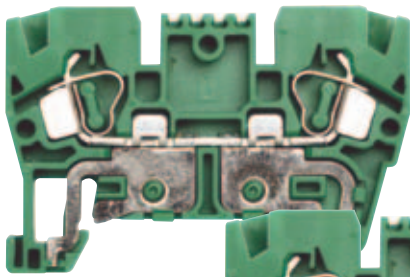

YBK-4T-10PK, \$25 for package of 10, shown actual size.

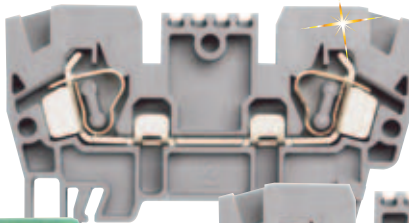

YBK-4-50PK, \$28 for package of 50, shown actual size.

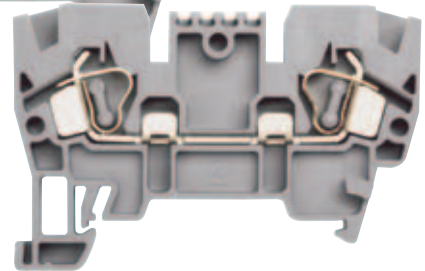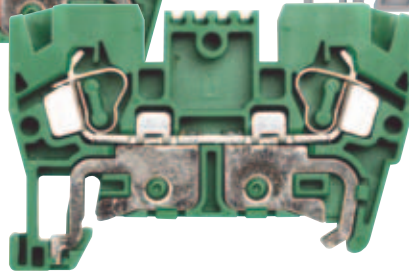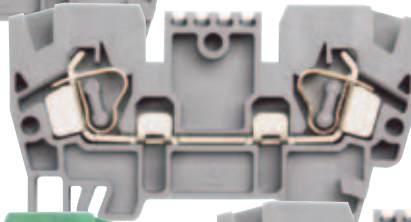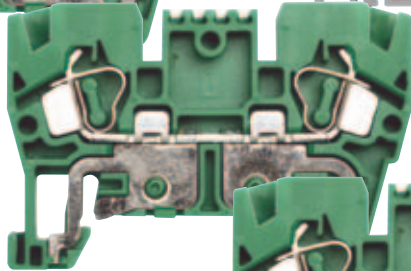

YBK Series
Starts at
\$0.44_{ea}
for package
of 50



- Tension Clamp for Fast Wire Termination and Reliable Secure Connection
- 600V Rated, UL 94 V2 Polyamide 6.6
- Full Line of Accessories: End Plates, Cross Connectors and Marking Tags
- Stocked in Colors Gray, Blue and Red; Also Available in Yellow, Beige and Green

YBK Series feed through terminal blocks are tension clamp connection style and are DIN rail mounted. The tension clamp can easily be opened with a small screwdriver inserted next to the wire entry, then slip in the field wire and remove the screwdriver for a reliable and secure connection. The YBK

terminal blocks come in all wire ranges and no pre-treatment of the wire is necessary, even for stranded wire. A full line of accessories are available including end plates, end brackets, cross connectors and marking tags. The YBK series also includes 4 size grounding terminal blocks.

SPECIFICATIONS

ELECTRICAL RATINGS	YBK-2.5	YBK-4	YBK-6	YBK-10
Voltage/Current	750V/22 A	750V/30 A	750V/40 A	750V/63 A
UL	600V/20 A	600V/26 A	600V/35 A	600V/55 A
Insulation Strip length	10 mm	12 mm	13 mm	13 mm
AWG	22-12	22-10	22-8	20-6
Width	5 mm	6 mm	8 mm	10 mm
End Plate-Partition	YBK-EP-2.5	YBK-EP-4	YBK-EP-6	YBK-EP-10
Cross-Connectors/2	OM-476222	OM-476232	OM-476242	OM-476252
Cross-Connectors/3	OM-476223	OM-476233	OM-476243	OM-476253
Cross-Connectors/4	OM-476224	OM-476234	OM-476244	OM-476254
Cross-Connectors/10	OM-476229	OM-476239	OM-476249	OM-476259
GROUND TENSION CLAMP TERMINAL BLOCKS				
ELECTRICAL RATINGS	YBK-2.5T	YBK-4T	YBK-6T	YBK-10T
Voltage/Current	750V/22 A	750V/30 A	750V/40 A	750V/63 A
UL	600V/20 A	600V/26 A	600V/35 A	600V/55 A
Insulation Strip Length	10 mm	12 mm	13 mm	13 mm
AWG	22-12	22-10	22-8	20-6
Width	5 mm	6 mm	8 mm	10 mm
End Plate-Partition	YBK-254T-EP	YBK-254T-EP	YBK-6T-EP	YBK-10T-EP



OM-476224-10PK, \$14.25 for package of 10, shown larger than actual size.

To Order (Specify Model Number)

MOST POPULAR MODELS HIGHLIGHTED!

FEED THROUGH TERMINAL BLOCKS				
MODEL NO.	PRICE	AMPS	AWG	DESCRIPTION
YBK-2.5-50PK	\$28.00	20	22-12	Feed through tension clamp terminal block, 50 per pack
YBK-2.5-25PK	18.00	20	22-12	Feed through tension clamp terminal block, 25 per pack
YBK-4-50PK	28.00	26	22-10	Feed through tension clamp terminal block, 50 per pack
YBK-4-25PK	18.00	26	22-10	Feed through tension clamp terminal block, 25 per pack
YBK-6-25PK	30.00	35	22-8	Feed through tension clamp terminal block, 25 per pack
YBK-6-10PK	15.00	35	22-8	Feed through tension clamp terminal block, 10 per pack
YBK-10-25PK	33.00	55	20-6	Feed through tension clamp terminal block, 25 per pack
YBK-10-10PK	15.00	55	20-6	Feed through tension clamp terminal block, 10 per pack
YBK-EP-2.5-10PK	3.00			End plate-partition for YBK-2.5, 10 per pack
YBK-EP-4-10PK	3.00			End plate-partition for YBK-4, 10 per pack
YBK-EP-6-10PK	3.00			End plate-partition for YBK-6, 10 per pack
YBK-EP-10-10PK	5.00			End plate-partition for YBK-10, 10 per pack
YBK-2.5T-10PK	16.00		22-12	Ground terminal block, 10 per pack
YBK-4T-10PK	25.00		22-10	Ground terminal block, 10 per pack
YBK-6T-10PK	30.00		22-8	Ground terminal block, 10 per pack
YBK-10T-5PK	22.00		20-6	Ground terminal block, 5 per pack
YBK-254T-EP-10PK	3.50			End plate for YBK-2.5T and 4T ground terminal
YBK-6T-EP-5PK	2.00			End plate for YBK-6T ground terminal
YBK-10T-EP-5PK	2.00			End plate for YBK-10T ground terminal
T-BLK-EB-10PK	5.00			DIN rail end bracket, 10 piece per pack

Note: Add "-R" for red and "-B" for blue colored terminal blocks, no additional charge.

ACCESSORIES

CROSS CONNECTORS							
MODEL NO.	PRICE	PCS/PKG	POSITIONS	MODEL NO.	PRICE	PCS/PKG	POSITIONS
OM-476222-10PK	\$7.25	10	2	OM-476242-10PK	\$8.00	10	2
OM-476223-10PK	10.50	10	3	OM-476243-10PK	12.75	10	3
OM-476224-10PK	14.25	10	4	OM-476244-10PK	19.50	10	4
OM-476229-3PK	13.50	3	10	OM-476249-3PK	16.00	3	10
OM-476232-10PK	7.50	10	2	OM-476252-10PK	9.75	10	2
OM-476233-10PK	12.00	10	3	OM-476253-10PK	15.25	10	3
OM-476234-10PK	18.25	10	4	OM-476254-10PK	23.50	10	4
OM-476239-3PK	15.00	3	10	OM-476259-3PK	19.25	3	10

MARKING TAGS			
MODEL NO.	PRICE	PCS/PER CARD	DESCRIPTION
MKR-NO-PRINT	\$3.00	50	Marking tag without print
MKR-1-10	3.00	50	Marking tag 1 to 10
MKR-11-20	3.00	50	Marking tag 11 to 20
MKR-1-50	3.00	50	Marking tag 1 to 50
MKR-51-100	3.00	50	Marking tag 51 to 100
MKR-101-150	3.00	50	Marking tag 101 to 150
MKR-151-200	3.00	50	Marking tag 151 to 200
MKR-201-250	3.00	50	Marking tag 201 to 250

Ordering Examples: YBK-2.5-50PK, 50 pieces feed through tension clamp terminal block to 12 AWG wire, rated at 20 A, and YBK-EP-2.5-10PK, one pack of end plates for YBK-2.5 terminals, \$28 + 3 = \$31.

YBK-2.5T-10PK, 10 pieces feed through ground terminals, and YBK-254T-EP-10PK, 10 pieces end plate partition for YBK-2.5T terminals \$16 + 3.50 = \$19.50.

omega.co.uk[®]

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

www.omega.co.uk



UNITED STATES

www.omega.com

1-800-TC-OMEGA
Stamford, CT.

UNITED KINGDOM

www.omega.co.uk

Manchester, England
0800-488-488
+44-(0)161-777-6611

CANADA

www.omega.ca

Laval(Quebec)
1-800-TC-OMEGA

FRANCE

www.omega.fr

0800-466-342

GERMANY

www.omega.de

Deckenfronn, Germany
0800-8266342

BENELUX

www.omega.nl

0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485, Ethernet and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters