


# OMB-DBK10

## 3-Slot Expansion-Card Enclosure for OMB-LOGBOOK and OMB-DAQBOARD-2000 Series

Model OMB-DBK10

**\$209**

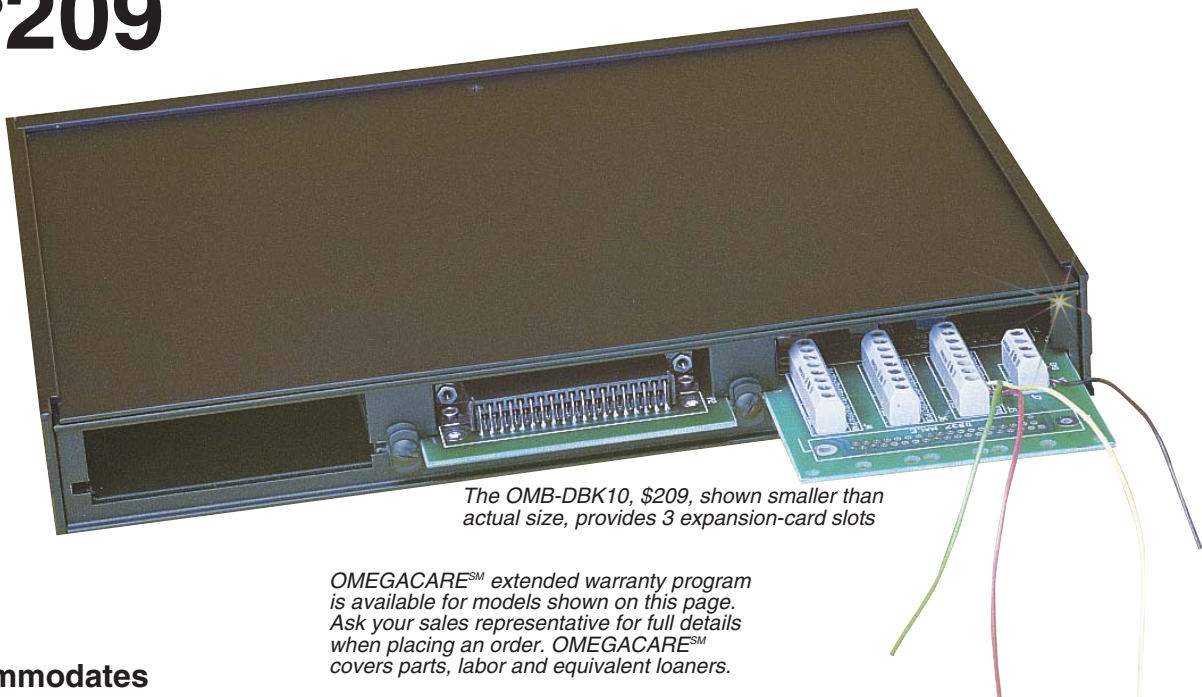

The OMB-DBK10, \$209, shown smaller than actual size, provides 3 expansion-card slots

OMEGACARE<sup>SM</sup> extended warranty program is available for models shown on this page. Ask your sales representative for full details when placing an order. OMEGACARE<sup>SM</sup> covers parts, labor and equivalent loaners.

- ✓ Accommodates Any Three Analog or Digital OMB-DBK Cards
- ✓ Ideal for Applications That Require Six or Fewer OMB-DBK Cards

The OMB-DBK10 is an all-metal expansion-card enclosure that accommodates up to three expansion cards for OMEGA's OMB-LOGBOOK and OMB-DAQBOARD-2000 Series data acquisition systems. This enclosure allows three expansion cards to easily slide into it without requiring removal of the signal connections. Two OMB-DBK10's are ideal for applications that require six or fewer expansion cards.

The use of an OMB-CA-37-x cable is required to daisy-chain all cards installed into OMB-DBK10 enclosures.

**Packaging.** You can stack the OMB-DBK10 beneath an OMB-LOGBOOK portable data acquisition module by means of the included fastener panels. The result is a compact and securely connected data acquisition system that you can conveniently carry from one application site to another.

### Specifications

- Capacity:** Accommodates any 3 OMB-DBK expansion cards
- Material:** Aluminum
- Finish:** Black, powder-coated
- Dimensions:** 221 x 285 x 35 mm (8.5 x 11 x 1.375")
- Weight:** 1.3 kg empty (3 lb); cards .25 to .75 kg each (8 to 12 oz)

**AVAILABLE FOR FAST DELIVERY!**

To Order (Specify Model Number)		
Model Number	Price	Description
OMB-DBK10	\$209	3-Slot Expansion-Card Enclosure

**Ordering Example:** OMB-DBK10 3-slot expansion-card enclosure, \$209.  
OCW-1 OMEGACARE<sup>SM</sup> extends standard 1-year warranty to a total of 2 years (\$20)  
\$209 + 20 + \$229.

# omega.co.uk<sup>®</sup>

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

[www.omega.co.uk](http://www.omega.co.uk)



#### UNITED STATES

[www.omega.com](http://www.omega.com)

1-800-TC-OMEGA  
Stamford, CT.

#### UNITED KINGDOM

[www.omega.co.uk](http://www.omega.co.uk)

Manchester, England  
0800-488-488  
+44-(0)161-777-6611

#### CANADA

[www.omega.ca](http://www.omega.ca)

Laval(Quebec)  
1-800-TC-OMEGA

#### FRANCE

[www.omega.fr](http://www.omega.fr)

0800-466-342

#### GERMANY

[www.omega.de](http://www.omega.de)

Deckenfronn, Germany  
0800-8266342

#### BENELUX

[www.omega.nl](http://www.omega.nl)

0800-099-33-44



## More than 100,000 Products Available!

### • Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

### • Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

### • pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

### • Data Acquisition

Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485, Ethernet and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

### • Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

### • Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters