

24-Channel Relay Output Board

OME-DB-24R/OME-DB-24RD

\$249
Basic Unit




- ✓ 24 Form C SPDT Relays
- ✓ OPTO-22 Compatible Connector
- ✓ Connects Directly to OME-DIO-24, OME-DIO-48, OME-DIO-144 or Other OPTO-22 Compatible Digital Output Board
- ✓ Switch up to 0.5A at 120 Vac; Switch up to 1A at 24 Vdc
- ✓ On Board Relay Driver Circuits
- ✓ LED's Indicate Relay Status
- ✓ Screw Terminals for easy Field Wiring

The OME-DB-24R consists of 24 form C, electromechanical relays for efficient switching of load by programmed control. The contact of each relay can control a 0.5 A /110 V load or 1 A/24 Vdc. The relay is energized by applying a 5 V signal to the appropriate relay channel on the 50-pin OPTO-22 compatible connector or 37-pin D-Sub connector. Twenty-four enunciator LED's, one for each relay, light when their associated relay is activated. To avoid overloading your PC's power supply, this board needs a +12 Vdc or +24 Vdc external power supply.

Specifications

Relay Type: 24 form C SPDT
Nominal Load:
 0.5 A @ 120 Vac, 1A @ 24 Vdc
Maximum Switching Power:
 60 VA, 24 W
Maximum Switching Voltage:
 120 Vac, 60 Vdc
Maximum Switching Current: 1A
Life Expectancy: mechanical (2 x 10⁷), electrical (2 x 10⁵)
Time Value: operate (6 ms)
Control Logic: input TTL high (+5 V) current, relay on

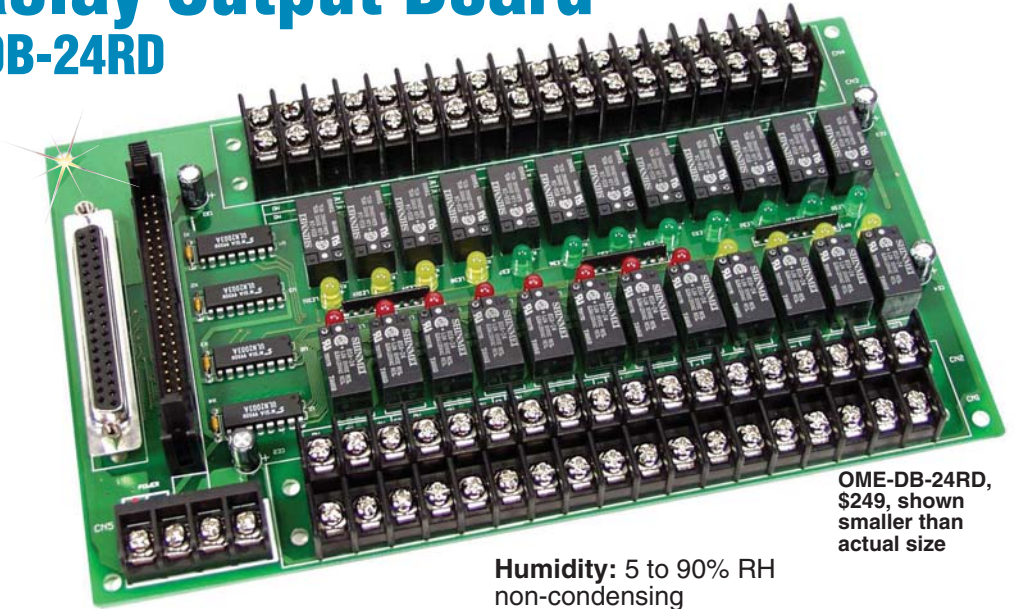

OME-DB-24RD, \$249, shown smaller than actual size

Power Consumption:
 +12 V @ 528 mA max;
 +5 V @ 150 mA max
Dimensions: 132 H x 225 mm W (8.1 x 4.5")
Operating Temperature:
 0 to 60°C (32 to 140°F)
Storage Temperature:
 -20 to 70°C (-4 to 158°F)

Humidity: 5 to 90% RH non-condensing
Connector: OME-DB-24, one 50-pin header; OME-DB-24RD, one 50-pin header and one 37-pin D-sub connector

OMEGACARESM extended warranty program is available for models shown on this page. Ask your sales representative for full details when placing an order. OMEGACARESM covers parts, labor and equivalent loaners

MOST POPULAR MODELS HIGHLIGHTED!

To Order (Specify Model Number)		
Model Number	Price	Description
OME-DB-24R/12	\$249	24-channel relay board (12 V version), includes 1.5 m (5') 50-pin flat cable
OME-DB-24R/24	249	24-channel relay board (24 V version), includes 1.5 m (5') 50-pin flat cable
OME-DB-24R/12/DIN	259	OME-DB-24R (12 V version) with DIN-rail mounting kit
OME-DB-24R/24/DIN	259	OME-DB-24R (24 V version) with DIN-rail mounting kit
OME-DB-24RD/12	249	24-channel relay board with 37-pin D-sub connector (12 V version), includes 1 m (3') 37-pin D-sub connector cable
OME-DB-24RD/24	249	24-channel relay board with 37-pin D-sub connector (24 V version), includes 1 m (3') 37-pin D-sub connector cable
OME-DB-24RD/12/DIN	259	OME-DB-24RD (12 V version) with DIN-rail mounting kit
OME-DB-24RD/24/DIN	259	OME-DB-24RD (24 V version) with DIN-rail mounting kit
OME-CA-5015	29	50-pin flat cable 1.5m (5')
OME-CA-3710	39	37-pin male-male D-sub connector cable 1 m (3')
OME-CA-3720	49	37-pin male-male D-sub connector cable 2 m (7')

Each board includes complete operator's manual on CD ROM.

Ordering Example: OME-DB-24R 16-channel isolated digital input board and OMEGACARESM 1 year extended warranty for OME-DB-24R (adds 1 year to standard 1 year warranty), \$249 + 25 = \$274.

omega.co.uk[®]

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

www.omega.co.uk



UNITED STATES

www.omega.com

1-800-TC-OMEGA
Stamford, CT.

UNITED KINGDOM

www.omega.co.uk

Manchester, England
0800-488-488
+44-(0)161-777-6611

CANADA

www.omega.ca

Laval(Quebec)
1-800-TC-OMEGA

FRANCE

www.omega.fr

0800-466-342

GERMANY

www.omega.de

Deckenfronn, Germany
0800-8266342

BENELUX

www.omega.nl

0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485, Ethernet and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters