

OPC Server


OPC Server Software License



OPC-SERVER License

£ **198**

- ✓ Easily Integrates NEWPORT[®] iSeries[™] Meters, Controllers and Signal Conditioners Into Any OPC Compliant Software
- ✓ Compatible With NEWPORT's EIS Family of Serial Servers; Use the Combination to Integrate Virtually Any Serial Device Into An OPC Compliant Software Through an Ethernet Connection
- ✓ Communicates Through a Standard Serial Port or Across an Ethernet Connection
- ✓ Free Downloadable Version Runs Unrestricted For Two Hours

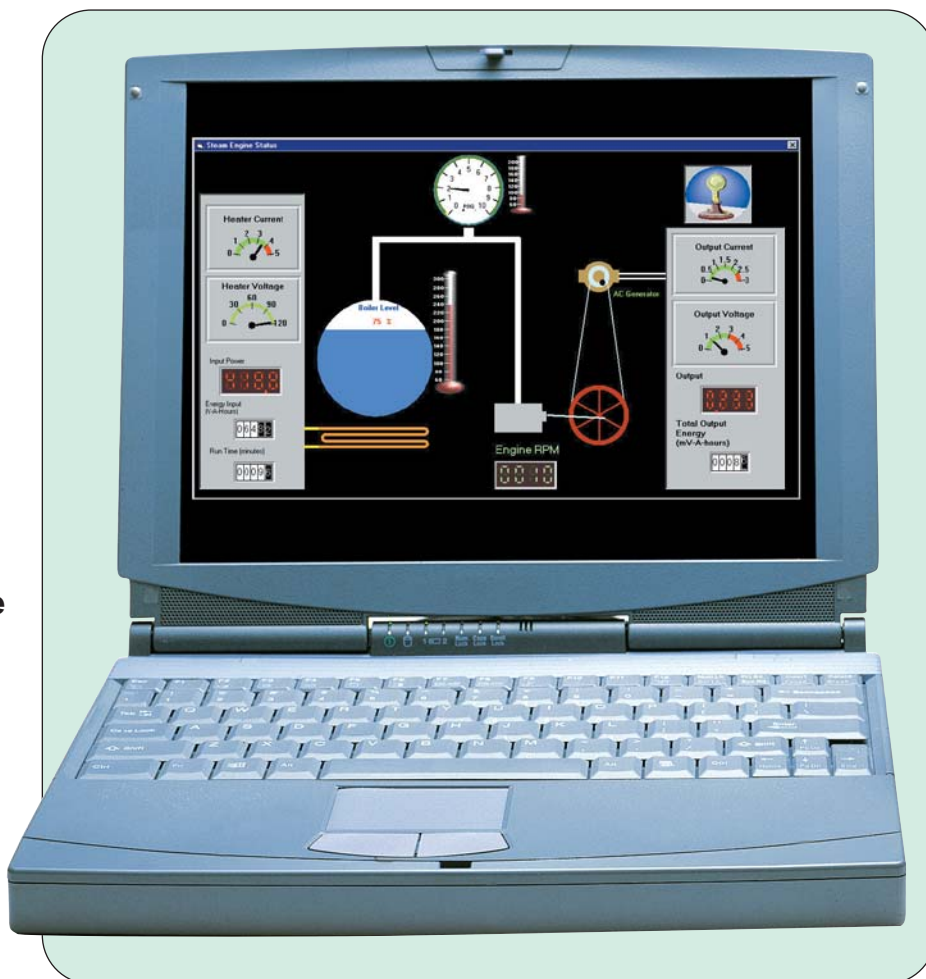

What is an OPC Server

OPC Servers are hardware drivers that are written to a common standard, OPC or "OLE for Process Control". OPC compliant programs (OPC Clients) for HMI, SCADA, DAS, etc. are available from NEWPORT, OMEGA, Wonderware, Iconics, Intellution, Rockwell Automation, and National Instruments, among others.

Hardware Support

The NEWPORT[™] OPC Server supports a wide variety of hardware including NEWPORT's iSeries[™] meters, controllers and signal conditioners. Because the Server is

designed to work directly with these products, setup is simple, typically taking only a few minutes. The OPC Server also supports NEWPORT's EIS family of Serial Servers. With a Serial Server you can connect virtually any serial device or instrument to a computer through an Ethernet connection.

Trial Version Available

A copy of the OPC Server can be downloaded from omega.co.uk. An unlimited runtime version of the OPC Server Software requires purchase of a license and entry of a unique License Activation Code. Without this code, the free OPC Server program will time-out after two hours. These two-hour sessions can be repeated as often as necessary to evaluate the software at no charge.

AVAILABLE FOR FAST DELIVERY!

To Order (Specify Model Number)

Model No.	Price	Description
OPC-SERVER LICENSE	£198	License for OPC server

Ordering Example: OPC-SERVER LICENSE, license for OPC server, £198.

omega.co.uk®

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

www.omega.co.uk



UNITED STATES

www.omega.com

1-800-TC-OMEGA

Stamford, CT.

CANADA

www.omega.ca

Laval(Quebec)

1-800-TC-OMEGA

GERMANY

www.omega.de

Deckenpfronn, Germany

0800-8266342

UNITED KINGDOM

www.omega.co.uk

Manchester, England

0800-488-488

FRANCE

www.omega.fr

088-466-342

CZECH REPUBLIC

www.omegaeng.cz

Karviná, Czech Republic

596-311-899

BENELUX

www.omega.nl

0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Auto-Dialers and Alarm Monitoring Systems, Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485 and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters