


LOW COST DIRECT READ ACRYLIC ROTOMETER KITS

FL-2500 Series



- ✓ Easy-to-Read Dual English and Metric Scales
- ✓ Interchangeable Scales for 6 Common Gases and Water
- ✓ Meters are Offered With or Without Built-In Needle Valves
- ✓ Economical and Compact
- ✓ Easy Disassembly and Assembly for Cleaning

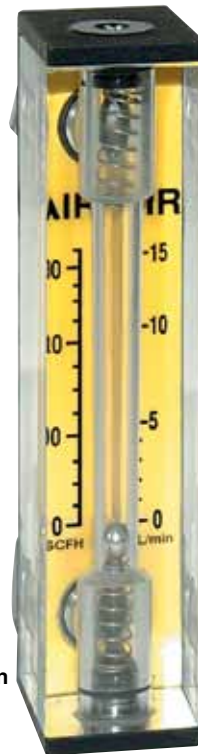

FL-2515 shown smaller than actual size.



FL-2514-V shown smaller than actual size.

The FL-2500 Series direct read rotometer kits offer versatility at a low cost. Each kit includes seven interchangeable direct read scales for air, water, Argon, CO₂, Helium, Nitrogen and Oxygen. These economical kits are ideal for laboratories, schools or processes that use multiple gases.

SPECIFICATIONS

Accuracy: ±5% of full scale reading
Maximum Temperature: 65°C (150°F)
Maximum Pressure: 6.9 bars (100 psig)
Meter Block: Clear machined acrylic
Float Materials: Black glass, stainless steel, tungsten carbide

O-Ring Seals: FKM with stainless fittings, Buna with brass fittings
Fittings: 1/8 NPT female connections, built-in needle valves and seal plugs, brass or stainless (model dependent)
Note: NIST calibration is not available on direct read meters.

To Order Visit omega.com/fl-2500_series for Pricing and Details

Brass Fittings Model No.	SS Fittings Model No.	Air	Water	Argon	CO ₂	Helium	Nitrogen	Oxygen	Float
		SLM (SCFH)	CCM (GPH)	SLM (SCFH)	SLM (SCFH)	SLM (SCFH)	SLM (SCFH)	SLM (SCFH)	
FL-2501	FL-2511	1.4 (2.8)	20 (0.3)	1.1 (2.25)	1.1 (2.5)	2 (4)	1.3 (2.75)	1.2 (2.5)	Glass
FL-2501-V	FL-2511-V	1.4 (2.8)	20 (0.3)	1.1 (2.25)	1.1 (2.5)	2 (4)	1.3 (2.75)	1.2 (2.5)	Glass
FL-2502	FL-2512	2.75 (5.5)	70 (1.1)	2.2 (5)	2.2 (5)	5.5 (11)	2.75 (5.5)	2.5 (5)	Stainless
FL-2502-V	FL-2512-V	2.75 (5.5)	70 (1.1)	2.2 (5)	2.2 (5)	5.5 (11)	2.75 (5.5)	2.5 (5)	Stainless
FL-2503	FL-2513	3.5 (7.0)	100 (1.5)	3 (6.5)	3 (6.5)	8 (17)	3.5 (7.5)	3.5 (7)	Carboly
FL-2503-V	FL-2513-V	3.5 (7.0)	100 (1.5)	3 (6.5)	3 (6.5)	8 (17)	3.5 (7.5)	3.5 (7)	Carboly
FL-2504	FL-2514	8.5 (18)	175 (2.75)	7 (15)	7 (15)	18 (40)	8 (16)	8 (16)	Glass
FL-2504-V	FL-2514-V	8.5 (18)	175 (2.75)	7 (15)	7 (15)	18 (40)	8 (16)	8 (16)	Glass
FL-2505	FL-2515	16 (32.5)	450 (6.5)	13 (26)	12 (25)	35 (70)	16 (32.5)	15 (30)	Stainless
FL-2505-V	FL-2515-V	16 (32.5)	450 (6.5)	13 (26)	12 (25)	35 (70)	16 (32.5)	15 (30)	Stainless
FL-2506	FL-2516	22 (45)	700 (11)	18 (37.5)	18 (37.5)	55 (110)	22 (45)	20 (42.5)	Carboly
FL-2506-V	FL-2516-V	22 (45)	700 (11)	18 (37.5)	18 (37.5)	55 (110)	22 (45)	20 (42.5)	Carboly
FL-2507	FL-2517	50 (100)	1400 (22)	40 (80)	35 (80)	110 (250)	45 (100)	45 (90)	Stainless
FL-2507-V	FL-2517-V	50 (100)	1400 (22)	40 (80)	35 (80)	110 (250)	45 (100)	45 (90)	Stainless

Comes complete with all 7 interchangeable direct reading dual scales (air scale comes installed, six other scales included separately) and operator's manual.

Ordering Examples: FL-2515-V, acrylic rotometer with valve and interchangeable scales for air, water, argon, CO₂, helium, nitrogen and oxygen.
 FL-2511-V, acrylic rotometer with valve and interchangeable scales for air, water, argon, CO₂, helium, nitrogen and oxygen.

omega.co.uk[®]

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

www.omega.co.uk



UNITED STATES

www.omega.com

1-800-TC-OMEGA
Stamford, CT.

UNITED KINGDOM

www.omega.co.uk

Manchester, England
0800-488-488
+44-(0)161-777-6611

CANADA

www.omega.ca

Laval(Quebec)
1-800-TC-OMEGA

FRANCE

www.omega.fr

0800-466-342

GERMANY

www.omega.de

Deckenfronn, Germany
0800-8266342

BENELUX

www.omega.nl

0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485, Ethernet and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters