

PROXIMITY SWITCHES

For Use with FL-500 Series Flowmeters

With 1 FNPT End Fittings


FL-500-RI
Starts at
\$87




Magnet force is used to trigger the 3-wire SPDT electric switch at any level of flow desired.

- Complete Switch Kits, Ready for Installation
- Easy Switch Point Setting Adjustment to Desired Flow Rate Indication
- Set High and Low Limits With 2 Proximity Switches
- One Switch Can Act as Deviation Alarm

The FL-500-RI proximity switches generate electrical signals at your predetermined flow rates, adding versatility and performance to the FL-500 Series flowmeters. Each switch kit contains all the necessary hardware for quick and trouble-free mounting. Kits consist of a ring-shaped ceramic magnet that fits around the float in the flowmeter and a proximity switch mounted in a rugged housing that easily clamps to the body of the flowmeter. As the changing flow causes the float to move within the tube, the magnet moves with it, and its magnetic field trips the proximity switch at the predetermined flow rate. Adjustment screw allows for easy flow rate adjustment. Add two switches to indicate both high and low flow rate limits.

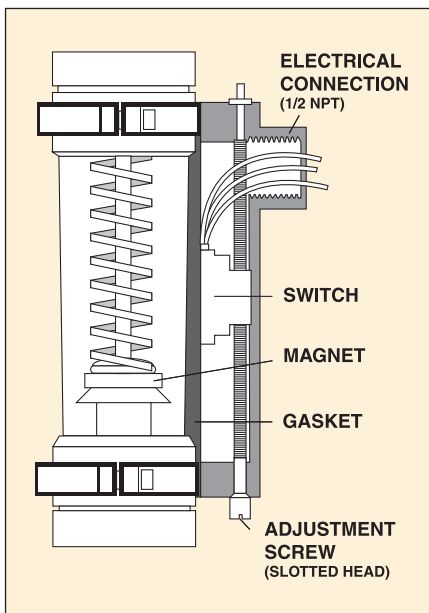

Note: Switch activates over a 25% of full scale band; above and below this band, the relay deactivates.

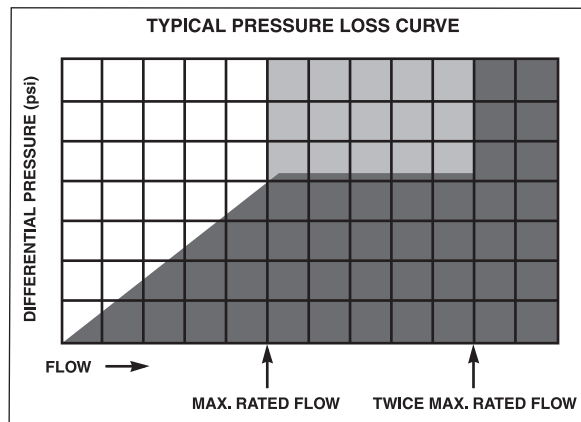

FL-500-RI switch, \$87, mounted on FL-515 in-line flowmeter, \$150, see page B-51. Shown smaller than actual size.

Switch Specifications

Contact Ratings:

- 12 Vdc at 0.25A
- 28 Vdc at 0.107A
- 120 Vac at 0.025A (at 77°F)

Dimensions: 152 x 89 mm (6 x 3 1/2")

AVAILABLE FOR FAST DELIVERY!

To Order (Specify Model Number)

Model No.	Price/Kit	For Use With The Following In-Line Flowmeter Models
FL-500-RI	\$87	FL-505, FL-510, FL-515
FL-500-R2	113	FL-530, FL-540, FL-550

Comes complete with one magnet, one switch housing, one foam gasket, two half collars, four cap screws with washers and operator's manual. Two nuts are also included and are needed only when two switches are mounted on one flowmeter.

Ordering Examples: FL-500-RI, proximity switch for FL-505, FL-510, FL-515 flowmeters, \$87. FL-500-RI, switch, and FL-515, flowmeter, \$87 + 150 = \$237.

omega.co.uk[®]

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

www.omega.co.uk



UNITED STATES

www.omega.com

1-800-TC-OMEGA
Stamford, CT.

UNITED KINGDOM

www.omega.co.uk

Manchester, England
0800-488-488
+44-(0)161-777-6611

CANADA

www.omega.ca

Laval(Quebec)
1-800-TC-OMEGA

FRANCE

www.omega.fr

0800-466-342

GERMANY

www.omega.de

Deckenfronn, Germany
0800-8266342

BENELUX

www.omega.nl

0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485, Ethernet and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters