

PUMP ACCESSORIES

for pumps shown on pages L-9 through L-10



ANTI-SIPHON INJECTION VALVE

Designed to prevent the liquid being pumped from siphoning through the pumphead during both the On and Off cycles, and to keep the liquid in the system from flowing backward through lines and fittings.

Ordering Example:
FPURV1, anti-siphon injection valve, \$31.

Model No.	Price	Tube Size OD	O-Ring
FPURV1	\$31	1/4"	EP
FPURV2	32	1/4"	AFLAS
FPURV3	31	3/8"	EP
FPURV4	32	3/8"	AFLAS



IN-LINE CHECK VALVE

In-line check valves are installed on the discharge side of the line and prevent the liquid being pumped from flowing backward. Constructed of durable polypropylene, with AFLAS® FKM O-rings.


Model No.	Price	Tube Size OD	O-Ring
FPUCV1	\$25	3/8"	AFLAS

PRESSURE RELIEF VALVE

In the event of excessive line pressure, this adjustable valve automatically opens, protecting your pump from damage from excessive pressure. An added feature is the priming valve, which eliminates problems caused by line pressure.

MOST POPULAR MODELS HIGHLIGHTED!

Model No.	Price	Tube Size OD	O-Ring
FPRV1	\$70	1/4"	EPDM
FPRV2	82	1/4"	FKM
FPRV3	70	3/8"	EPDM
FPRV4	82	3/8"	FKM

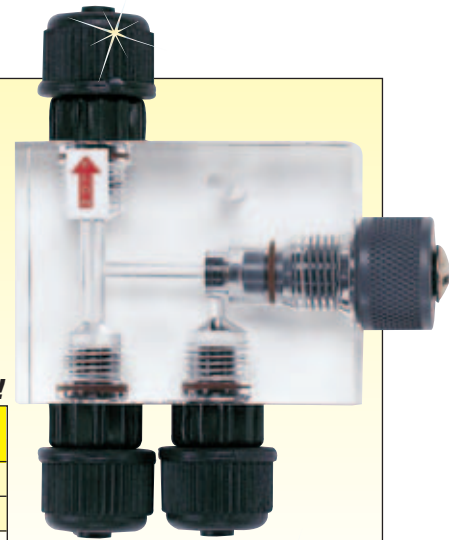

FEED INDICATOR

Verify solution feeding at a glance, no matter how cloudy or discolored the tubing becomes. The rhythmic rising and falling of the float indicates the positive flow, while the appearance of air bubbles indicates solution may be depleted. The indicator is an excellent troubleshooting and diagnostic tool. Available individually or in packages of 12.

MOST POPULAR MODELS HIGHLIGHTED!

Individual, \$31 each	12-Packs \$372	Tube Size OD	Float
Model No.	Model No.		
FPUSG1	FPUSGK1	3/8"	Glass
FPUSG2	FPUSGK2	1/4"	Glass
FPUSG3	FPUSGK3	3/8"	316SS
FPUSG4	—	1/4"	316SS



FOOT VALVE STRAINERS

Foot valve strainer bodies are constructed of molded polypropylene with polypropylene screens. The screens act as filters (strainers) to keep particles from entering the suction line and fouling the pumphead. They can be used either as a foot valve or as a bulkhead fitting. Strainers have a barbed fitting so one size will fit all tube sizes.

MOST POPULAR MODEL HIGHLIGHTED!

Bulkhead Model No.	Price	Tube Size OD	O-Ring	Barbed Model No.	Price
FPUSV-E	\$25	1/4"	EP	FPUBV-E	\$25
FPUSV-V	25	1/4"	AFLAS	FPUBV-V	25
FPUSV5*	32	3/8"	—	FPUBV5	37

* Fits FPUDT3000 Series pumps.



Accessory

Model No.	Price	Description
CM-4441	\$112	Reference Book: Systematic Methods of Chemical Process Design



omega.co.uk[®]

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

www.omega.co.uk



UNITED STATES

www.omega.com

1-800-TC-OMEGA
Stamford, CT.

UNITED KINGDOM

www.omega.co.uk

Manchester, England
0800-488-488
+44-(0)161-777-6611

CANADA

www.omega.ca

Laval(Quebec)
1-800-TC-OMEGA

FRANCE

www.omega.fr

0800-466-342

GERMANY

www.omega.de

Deckenfronn, Germany
0800-8266342

BENELUX

www.omega.nl

0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485, Ethernet and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters