



pH FIELD & LAB ELECTRODES

ALPHA® pH Combination Electrodes For Laboratory Use

RoHS

All electrodes shown smaller than actual size.

PHE-2121, general purpose lab, \$71.

PHE-2721, double junction for applications normally requiring calomel, \$81.

PHE-2114, general purpose, large bulb, \$80.

PHE-2414, large bulb sealed double junction, \$101.

PHE-357, \$995 shown smaller than actual size. See page B-30 in the GREEN BOOK® section of this handbook.

Each electrode supplied with either BNC (shown) or US standard connector.


To Order (Specify Model Number)						
Model No. BNC	Model No. US Std	Applications/Features	Length mm (in)	Diameter mm (in)	pH Range	Temp. Range °C (°F)
PHE-2121	PHE-2121-U	General purpose laboratory	150 (5.9)	12 (0.47)	0 to 14	0 to 100 (32 to 212)
PHE-2721	PHE-2721-U	Double junction reference suitable for applications that normally require calomel	150 (5.9)	12 (0.47)	0 to 14	0 to 100 (32 to 212)
PHE-2114	PHE-2114-U	General purpose, large bulb	110 (4.3)	12 (0.47)	0 to 13	0 to 100 (32 to 212)
PHE-2414	PHE-2414-U	Large bulb, sealed double junction	110 (4.3)	12 (0.47)	0 to 13	0 to 110 (32 to 230)
PHE-2314	PHE-2314-U	General purpose, large bulb sealed	110 (4.3)	12 (0.47)	0 to 13	0 to 110 (32 to 230)
PHE-2214	PHE-2214-U	Sealed inner, refillable outer junction	110 (4.3)	12 (0.47)	0 to 13	0 to 110 (32 to 230)
PHE-2319	PHE-2319-U	High pH, sealed	110 (4.3)	12 (0.47)	0 to 14	5 to 110 (41 to 230)
PHE-2116	PHE-2116-U	Rugged bulb design	140 (5.5)	12 (0.47)	0 to 14	5 to 110 (41 to 230)
PHE-2131	—	Test tubes, flasks	150 (5.9)	6 (0.24)	0 to 14	0 to 100 (32 to 212)
PHE-2731	PHE-2731-U	Test tubes, flasks for organics, proteins, metals	150 (5.9)	6 (0.24)	0 to 14	0 to 100 (32 to 212)
PHE-2123	PHE-2123-U6	Large test tubes, flasks	150 (5.9)	9.5 (0.37)	0 to 14	0 to 100 (32 to 212)
PHE-2723	PHE-2723-U	Large test tubes, flasks for organics, proteins, metals	150 (5.9)	9.5 (0.37)	0 to 14	0 to 100 (32 to 212)
PHE-2124	PHE-2124-U	Extra long for measurement in narrow vessels	300 (11.8)	9.5 (0.37)	0 to 14	0 to 100 (32 to 212)
PHE-1477	PHE-1477-U	Flat surfaces, PTFE double junction	127 (5.0)	12 (0.47)	1 to 10	0 to 60 (32 to 140)

pH FIELD & LAB ELECTRODES



Laboratory pH Combination Electrodes

For a complete selection of field and laboratory pH instrumentation, see Section B of the GREEN BOOK® section of this handbook.

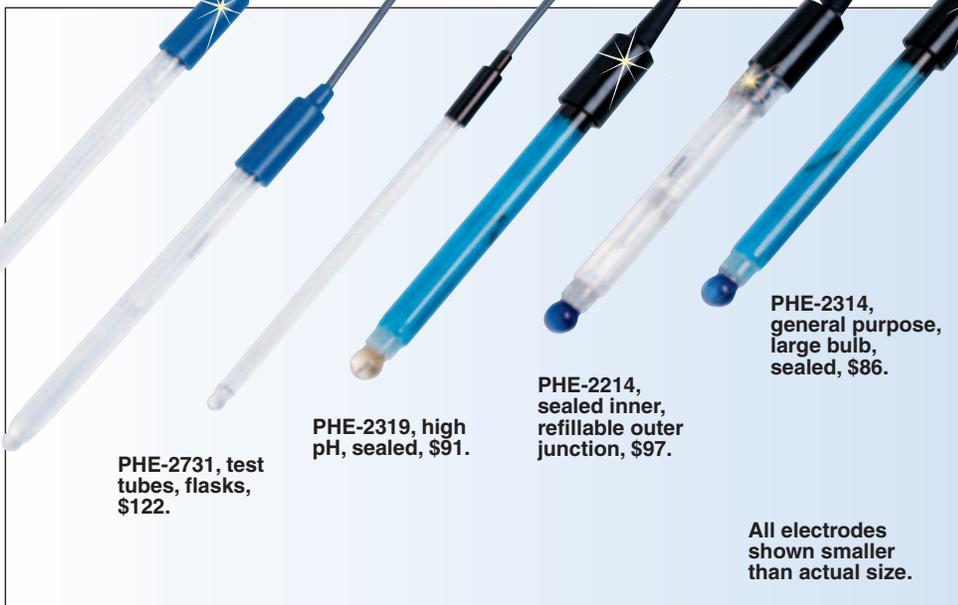

PHE-2124, extra long for narrow vessels, \$101.

PHE-2723, large test tubes, flasks for organics, proteins and metals, \$101.

PHE-2731, test tubes, flasks, \$122.

PHE-2319, high pH, sealed, \$91.

PHE-2214, sealed inner, refillable outer junction, \$97.

PHE-2314, general purpose, large bulb, sealed, \$86.

All electrodes shown smaller than actual size.

Recommended Reference Book: Advanced pH Measurement and Control, FW-332, \$89. See Section Y for Additional Books.



MOST POPULAR MODELS HIGHLIGHTED!

Reference Type	Liquid Junction	Body Material	Refillable or Gel	R @ 25°C (77°F) MΩ	Price	
					BNC	US Std
Ag/AgCl	Ceramic	Glass	Refillable	50 to 80	\$71	\$78
Ag/AgCl Double	Ceramic	Glass	Gel	50 to 80	81	88
Ag/AgCl	Annular Ceramic	Glass	Refillable	50	80	84
Ag/AgCl Double	Annular Ceramic	Glass	Gel	50	101	105
Ag/AgCl	Annular Ceramic	Glass	Gel	50	86	90
Ag/AgCl Double	Annular Ceramic	Glass	Gel/Refillable	50	97	101
Ag/AgCl	Annular Ceramic	Glass	Gel	250	91	95
Ag/AgCl	Annular Ceramic	Glass	Refillable	250	86	90
Ag/AgCl	Ceramic	Glass	Refillable	50 to 80	116	—
Ag/AgCl Double	Ceramic	Glass	Gel	50 to 80	122	129
Ag/AgCl	Ceramic	Glass	Refillable	50 to 80	84	91
Ag/AgCl Double	Ceramic	Glass	Gel	50 to 80	101	108
Ag/AgCl	Ceramic	Glass	Refillable	50 to 80	101	108
Ag/AgCl Double	PTFE	Poly Ether Sulfone	Gel	200	120	127

Comes complete with 0.75 to 1 m (2.5 to 3') cable and operator's manual.

Ordering Examples: PHE-2121, general purpose laboratory electrode, \$71.

PHE-2116, rugged bulb electrode, \$86.

omega.co.uk[®]

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

www.omega.co.uk



UNITED STATES

www.omega.com

1-800-TC-OMEGA
Stamford, CT.

CANADA

www.omega.ca

Laval(Quebec)
1-800-TC-OMEGA

GERMANY

www.omega.de

Deckenfronn, Germany
0800-8266342

UNITED KINGDOM

www.omega.co.uk

Manchester, England
0800-488-488
+44-(0)161-777-6611

FRANCE

www.omega.fr

0800-466-342

BENELUX

www.omega.nl

0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485, Ethernet and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters