



pH FIELD & LAB INSTRUMENTS

Compact Mini Digital pH Meter With Optional Mounting Bracket

PHH-715
\$198




- ✓ Portable or Wall Mount with Optional Bracket
- ✓ Large LCD Easy to Read Display
- ✓ Compact Size
- ✓ Battery or AC Power



PHE-1304 pH electrode, \$32, sold separately.

110/220 Vac adaptor (included).

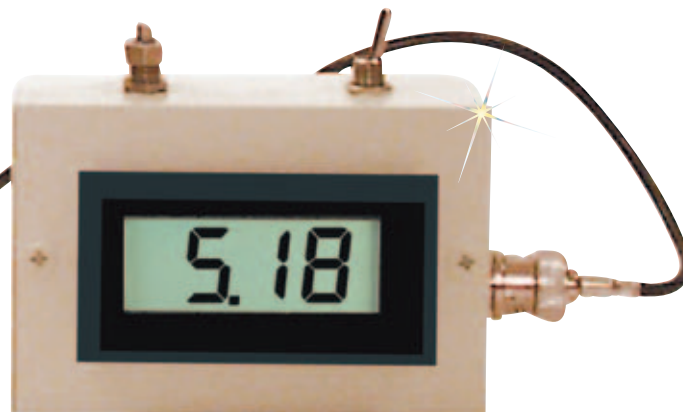

PHH-715, \$198, shown smaller than actual size.

AVAILABLE FOR FAST DELIVERY!

The PHH-715 digital pH meter provides a full scale, 0 to 14 pH measurement. This pH meter has an optional bracket for wall mounting or can be used as a portable unit. The PHH-715 can also be used with the AC power adaptor or from the supplied 9V NiCAD battery.

Specifications

Display: 3½ Digit LCD display

Accuracy/Range: ±0.01 pH/0.00 to 14.00 pH

pH Electrode: Optional

Electrode Connection: BNC

Operating Temperature: 0 to 50°C (32 to 122°F)

Power Supply: 9V NiCAD battery (included) or 110/220 Vac with adaptor (included)

Battery Life: Approx. 500 hours

Dimensions:

Instrument: 89 x 64 x 38 mm (3.5 x 2.5 x 1.5")

Optional Mounting Bracket:

6.3 H x 9.2 W x 3.9 mm D (2.5 x 3.63 x 1.55")

Weight: Approx. 454 g (1 lb)

To Order (Specify Model Number)

Model	Price	Description
PHH-715	\$198	Handheld pH meter (pH electrode optional)

Accessories

Model	Price	Description
PHH-715-BRACKET	\$35	Optional wall mounting bracket
PHH-715-AC	25	Replacement 110/220 AC adaptor
PHH-715-BATTERY	20	9V NiCAD replacement battery
PHE-1304	32	Optional general purpose pH electrode
PHE-1411	70	Optional double junction pH electrode
PHA-4	5	pH 4.00 buffer solution, 500 ml (1 pint) bottle
PHA-7	5	pH 7.00 buffer solution, 500 ml (1 pint) bottle
PHA-10	5	pH 10.00 buffer solution, 500 ml (1 pint) bottle

Comes complete with battery, AC power adaptor and operator's manual.

Ordering Example: PHH-715 pH meter with PHH-715-BRACKET mounting bracket, PHE-1411 double junction electrode and PHA-4 and PHA-7 buffer solutions, \$198 + 35 + 70 + 5 + 5 = \$313.

Recommended Reference Book: Chemical Engineering, CM-4226, \$59.95. See Section Y for Additional Books



omega.co.uk[®]

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

www.omega.co.uk



UNITED STATES

www.omega.com

1-800-TC-OMEGA
Stamford, CT.

UNITED KINGDOM

www.omega.co.uk

Manchester, England
0800-488-488
+44-(0)161-777-6611

CANADA

www.omega.ca

Laval(Quebec)
1-800-TC-OMEGA

FRANCE

www.omega.fr

0800-466-342

GERMANY

www.omega.de

Deckenfronn, Germany
0800-8266342

BENELUX

www.omega.nl

0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485, Ethernet and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters