



# TUBE AND HOSE ACCESSORIES

Tube and Hose Accessories Starts at \$3

## Hose Cutter

Heavy duty hose cutter for plastic tube and hose up to 1" OD.

## Tube Cutter


Make accurate "clean" cuts on tubing from 3 mm (1/8") to 19 mm (3/4") OD.

## Tubing Marker Clips

Easy-snap clips for marking and identifying tube runs. This complete kit comes in a plastic storage case and includes: 50 each #1 to 9, 50 each of 14 different letters (A, B, C, D, E, F, G, H, J, P, R, X, Y, Z).

## Tube Channels

Tube Channel mounts for securing multiple tubing runs. We offer a small and large tube channel. The small 10-Tube Channel is available in 3 sizes to fit tubing OD: 4 (5/32), 5 (3/16), 6 (1/4) [mm (in)] and can be mounted with self adhesive backing or #4 screw (not included). The large tube channel is available in 6, 7 and 10 channels for tubing sizes 10 mm (3/8") and 13 mm (1/2") and can be mounted with two screws (not included).

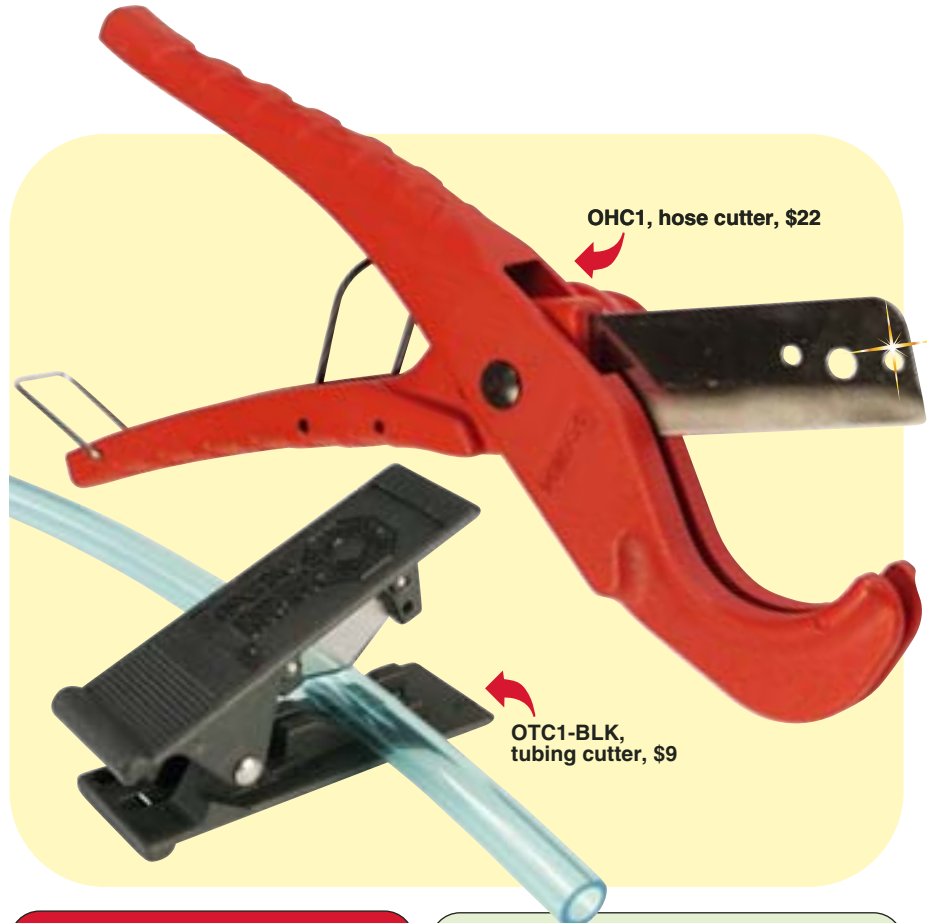

OHC1, hose cutter, \$22

OTC1-BLK, tubing cutter, \$9

OTMC1-KIT, tube marker kit, \$198



OLTC-12-6, large tube channel, \$6



OSTC-532-10, small tube channel, \$3



### To Order (Specify Model Number)

AVAILABLE FOR FAST DELIVERY!

#### HOSE CUTTER

MODEL NO.	PRICE	DESCRIPTION
OHC1	\$22	Hose cutter, red
OHC1-RE	8	Replacement blade, single

#### TUBE CUTTER

OTC1-R	\$9	Tubing cutter, red
OTC1-BLK	9	Tubing cutter, black
OTC1-BL	9	Tubing cutter, blue
OTC1-RE1	4	Replacement blade, single
OTC1-RE5	14	Replacement blades, 5-pack
OTC1-RE10	21	Replacement blades, 10-pack

#### TUBE MARKER KIT

OTMC1-KIT	\$198	Marker clip kit for 3 mm (1/8") tubing
OTMC2-KIT	209	Marker clip kit for 4 mm (5/32") tubing
OTMC3-KIT	242	Marker clip kit for 6 mm (1/4") tubing
OTMC4-KIT	406	Marker clip kit for 10 mm (3/8") tubing

#### TUBE CHANNEL

OLTC-38-7	\$5	Large tube channel, 10 mm (3/8") tubing, 7-channels
OLTC-38-10	6	Large tube channel, 10 mm (3/8") tubing, 10-channels
OLTC-12-6	6	Large tube channel, 13 mm (1/2") tubing, 6-channels
OSTC-532-10	3	Small tube channel, 4 mm (5/32") tubing, 10-channels
OSTC-316-10	3	Small tube channel, 5 mm (3/16") tubing, 10-channels
OSTC-14-10	3	Small tube channel, 6 mm (1/4") tubing, 10-channels

# omega.co.uk<sup>®</sup>

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

[www.omega.co.uk](http://www.omega.co.uk)



#### UNITED STATES

[www.omega.com](http://www.omega.com)

1-800-TC-OMEGA  
Stamford, CT.

#### CANADA

[www.omega.ca](http://www.omega.ca)

Laval(Quebec)  
1-800-TC-OMEGA

#### GERMANY

[www.omega.de](http://www.omega.de)

Deckenfronn, Germany  
0800-8266342

#### UNITED KINGDOM

[www.omega.co.uk](http://www.omega.co.uk)

Manchester, England  
0800-488-488  
+44-(0)161-777-6611

#### FRANCE

[www.omega.fr](http://www.omega.fr)

0800-466-342

#### BENELUX

[www.omega.nl](http://www.omega.nl)

0800-099-33-44



## More than 100,000 Products Available!

### • Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

### • Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

### • pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

### • Data Acquisition

Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485, Ethernet and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

### • Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

### • Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters