

OMEGAFLEX®

SILICONE TUBING PEROXIDE CURED

✓ Suitable for Many Peristaltic Pumps

✓ Broad Operating Temp. Range
[-73 to 177°C (-100 to 350°F)]

✓ Made from FDA Approved Ingredients

SPECIFICATIONS*

Hardness, Shore A ±: 50

Specific Gravity: 0.14

Tensile Strength, psi: 1100

Elongation at Break, %: 375

Brittle Temperature: -73°C (-100°F)


Max. Operating Temperature: -100°C (350°F)



TYSC-18116-100

\$35

Basic 100' Spool

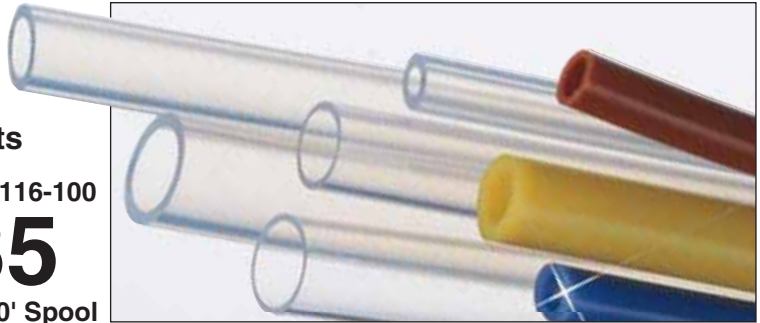

ALL MODELS AVAILABLE FOR FAST DELIVERY!

To Order (Specify Model Number)

1/6 to 3/4 ID TUBING - SILICONE TUBING, PEROXIDE CURED

Model No.	Price	Length (ft)	OD (in)	ID (in)	WALL (in)	Working psi @ 70°F	BURST psi @ 70°F
TYSC-18116-100	\$35	100	1/8	1/16	1/32	10	30
TYSC-316116-100	45	100	3/16	1/16	1/16	20	60
TYSC-532332-100	30	100	5/32	3/32	1/32	10	30
TYSC-732332-100	50	100	7/32	3/32	1/16	15	45
TYSC-31618-100	35	100	3/16	1/8	1/32	10	30
TYSC-1418-100	50	100	1/4	1/8	1/16	20	60
TYSC-51618-100	70	100	5/16	1/8	3/32	25	75
TYSC-3818-100	100	100	3/8	1/8	1/8	20	60
TYSC-932532-100	50	100	9/32	5/32	1/16	20	60
TYSC-1132532-100	75	100	11/32	5/32	3/32	20	60
TYSC-14316-100	40	100	1/4	3/16	1/32	5	15
TYSC-516316-100	55	100	5/16	3/16	1/16	20	60
TYSC-38316-100	85	100	3/8	3/16	3/32	20	60
TYSC-716316-100	135	100	7/16	3/16	1/8	15	45
TYSC-51614-100	50	100	5/16	1/4	1/32	10	30
TYSC-3814-100	65	100	3/8	1/4	1/16	5	15
TYSC-71614-100	105	100	7/16	1/4	3/32	20	60
TYSC-1214-100	145	100	1/2	1/4	1/8	15	45
TYSC-716516-100	80	100	7/16	5/16	1/16	10	30
TYSC-12516-100	125	100	1/2	5/16	3/32	10	30
TYSC-1238-100	90	100	1/2	1/8	1/16	10	30
TYSC-91638-100	145	100	9/16	1/8	3/32	10	30
TYSC-5838-100	200	100	5/8	1/8	1/8	10	30
TYSC-3438-100	320	100	3/4	3/8	3/16	15	45
TYSC-58716-100	60	100	5/8	7/16	3/32	10	30
TYSC-5812-100	110	100	5/8	1/2	1/16	5	15
TYSC-111612-100	175	100	11/16	1/2	3/32	5	15
TYSC-3412-100	230	100	3/4	1/2	1/8	10	30
TYSC-7812-100	390	100	7/8	1/2	3/16	10	30
TYSC-3458-100	140	100	3/4	5/8	1/16	5	15
TYSC-131658-100	210	100	13/16	5/8	3/32	5	15
TYSC-7858-100	285	100	7/8	5/8	1/8	5	15
TYSC-158-100	460	100	1	5/8	3/16	10	30
TYSC-134-50	165	50	1	3/4	1/8	5	15
TYSC-11834-50	260	50	1 1/8	3/4	3/16	10	30

Ordering Example: TYSC-1418-100, 100 feet of tubing, 1/4" OD x 1/8" ID, \$50.

Polyester Braid Reinforced Silicone tubing is available, contact Sales.

*Specifications listed are typical and are meant only as a guide. Each user must test the tubing under their operating conditions to determine the tubing's suitability for the particular application.

omega.co.uk[®]

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

www.omega.co.uk



UNITED STATES

www.omega.com

1-800-TC-OMEGA
Stamford, CT.

CANADA

www.omega.ca

Laval(Quebec)
1-800-TC-OMEGA

GERMANY

www.omega.de

Deckenfronn, Germany
0800-8266342

UNITED KINGDOM

www.omega.co.uk

Manchester, England
0800-488-488
+44-(0)161-777-6611

FRANCE

www.omega.fr

0800-466-342

BENELUX

www.omega.nl

0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485, Ethernet and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters