


**OMEGAFLEX®**

# THICK WALL PVC SUCTION TUBING

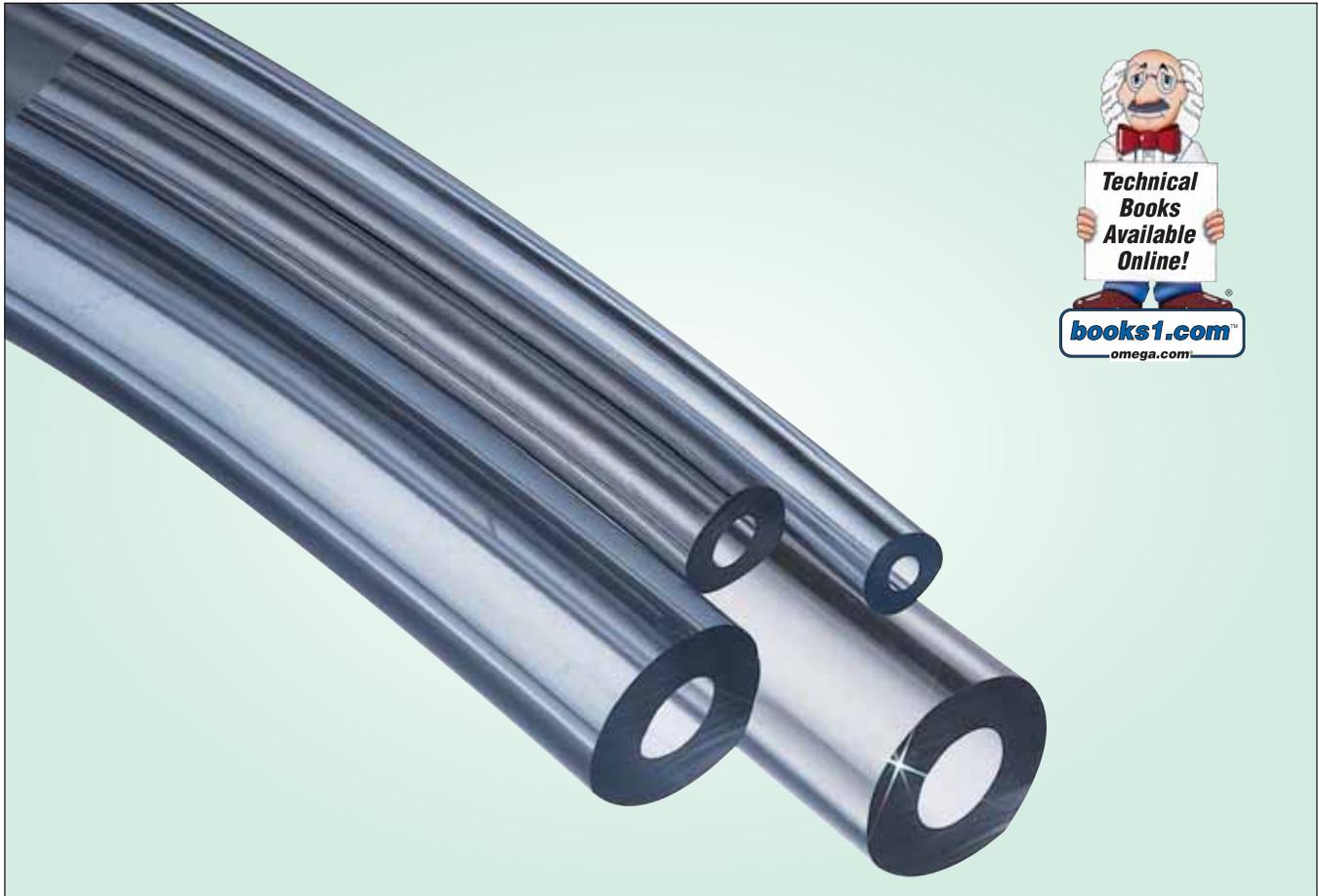

OMEGA's TYVYV thick wall PVC tubing combines the clarity, flexibility, and ease-of-use of standard vinyl tubing with the additional ability to handle full vacuum temperatures up to 160°F. In addition, TYVYV tubing handles somewhat higher operating pressures than our standard PVC tubing with an equivalent inside diameter.

### SPECIFICATIONS\*

**Hardness, Shore A:** 55  
**Specific Gravity:** 1.19  
**Tensile Strength, PSI:** 1650  
**Ultimate Elongation:** 450%  
**Operating Temperature Range:**  
 -32 to 71°C (-25 to 160°F)  
**Minimum Bend Radius:**  
 4 times the tube OD

TYVYV-916316-50

# \$64

Basic 50' Spool



**ALL MODELS AVAILABLE FOR FAST DELIVERY!**

### To Order (Specify Model No.)

Model No.	Price	Std Length (ft)	Vac Rate in/hg	O.D. (in)	I.D. (in)	Working psi at 73°F	lbs/50 ft
TYVYV-916316-50	\$ 64	50	30	3/16	3/16	62	6
TYVYV-5814-50	82	50	30	1/8	1/4	56	7
TYVYV-5814-10	41	10	30	1/8	1/4	56	7
TYVYV-7838-50	180	50	30	3/16	3/8	54	7.5
TYVYV-11812-50	210	50	30	1/2	1/2	52	22
TYVYV-13858-50	328	50	30	1 1/8	5/8	56	32
TYVYV-11234-50	478	50	30	1 1/2	3/4	46	36
TYVYV-21-50	1111	50	30	2	1	46	65

### Accessory

Model No.	Price	Description
FW-306	\$125	Reference Book: Valve Handbook

Ordering Example: TYVYV-7838-50, 50' of tubing, 3/16" OD, 3/8" ID, \$180.

\*Specifications given are typical and are meant only as a guide. Field testing is required to find the actual operating specifications in a given application.

T

# omega.co.uk<sup>®</sup>

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

[www.omega.co.uk](http://www.omega.co.uk)



#### UNITED STATES

[www.omega.com](http://www.omega.com)

1-800-TC-OMEGA  
Stamford, CT.

#### CANADA

[www.omega.ca](http://www.omega.ca)

Laval(Quebec)  
1-800-TC-OMEGA

#### GERMANY

[www.omega.de](http://www.omega.de)

Deckenfronn, Germany  
0800-8266342

#### UNITED KINGDOM

[www.omega.co.uk](http://www.omega.co.uk)

Manchester, England  
0800-488-488  
+44-(0)161-777-6611

#### FRANCE

[www.omega.fr](http://www.omega.fr)

0800-466-342

#### BENELUX

[www.omega.nl](http://www.omega.nl)

0800-099-33-44



## More than 100,000 Products Available!

### • Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

### • Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

### • pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

### • Data Acquisition

Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485, Ethernet and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

### • Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

### • Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters