


SEMI-CYLINDRICAL CERAMIC HEATERS

CRWS Series

- ✓ Rated to 982°C (1800°F)
- ✓ Helically Wound Iron-Chrome-Aluminum Wire

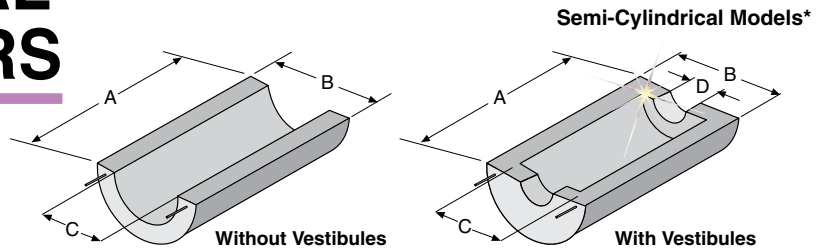

To Order

		Dimensions in cm (")				Without Vestibules	With Vestibules
Watts	Volts	A*	B	C	D	Model No.	Model No.
300	60	15 (6)	10 (4)	5 (2)	4 (1.5)	CRWS-62/60-A	CRWS-62/60-C-A
600	120	30 (12)	10 (4)	5 (2)	4 (1.5)	CRWS-122/120-A	CRWS-122/120-C-A
900	120	46 (18)	10 (4)	5 (2)	4 (1.5)	CRWS-182/120-A	CRWS-182/120-C-A
1200	240	61 (24)	10 (4)	5 (2)	4 (1.5)	CRWS-242/240-A	CRWS-242/240-C-A
425	120	15 (6)	13 (5)	8 (3)	5 (2)	CRWS-63/120-A	CRWS-63/120-C-A
850	120	30 (12)	13 (5)	8 (3)	5 (2)	CRWS-123/120-A	CRWS-123/120-C-A
1275	240	46 (18)	13 (5)	8 (3)	5 (2)	CRWS-183/240-A	CRWS-183/240-C-A
1700	240	61 (24)	13 (5)	8 (3)	5 (2)	CRWS-243/240-A	CRWS-243/240-C-A
565	120	15 (6)	15 (6)	10 (4)	6 (2.5)	CRWS-64/120-A	CRWS-64/120-C-A
1130	120	30 (12)	15 (6)	10 (4)	6 (2.5)	CRWS-124/120-A	CRWS-124/120-C-A
1700	240	46 (18)	15 (6)	10 (4)	6 (2.5)	CRWS-184/240-A	CRWS-184/240-C-A
2250	240	61 (24)	15 (6)	10 (4)	6 (2.5)	CRWS-244/240-A	CRWS-244/240-C-A
650	120	15 (6)	23 (9)	13 (5)	9 (3.5)	CRWS-65/120-A	CRWS-65/120-C-A
1300	240	30 (12)	23 (9)	13 (5)	9 (3.5)	CRWS-125/120-A	CRWS-125/120-C-A
1950	240	46 (18)	23 (9)	13 (5)	9 (3.5)	CRWS-185/240-A	CRWS-185/240-C-A
2600	240	61 (24)	23 (9)	13 (5)	9 (3.5)	CRWS-245/240-A	CRWS-245/240-C-A
850	120	15 (6)	25 (10)	15 (6)	10 (4)	CRWS-66/120-A	CRWS-66/120-C-A
1700	240	30 (12)	25 (10)	15 (6)	10 (4)	CRWS-126/240-A	CRWS-126/240-C-A
2550	240	46 (18)	25 (10)	15 (6)	10 (4)	CRWS-186/240-A	CRWS-186/240-C-A
3400	240**	61 (24)	25 (10)	15 (6)	10 (4)	CRWS-246/240-A	CRWS-246/240-C-A
920	240	15 (6)	28 (11)	18 (7)	13 (5)	CRWS-67/240-A	CRWS-67/240-C-A
1840	240	30 (12)	28 (11)	18 (7)	13 (5)	CRWS-127/240-A	CRWS-127/240-C-A
2760	240	46 (18)	28 (11)	18 (7)	13 (5)	CRWS-187/240-A	CRWS-187/240-C-A
3680	240**	61 (24)	28 (11)	18 (7)	13 (5)	CRWS-247/240-A	CRWS-247/240-C-A
1100	240	15 (6)	30 (12)	20 (8)	15 (6)	CRWS-68/240-A	CRWS-68/240-C-A
2200	240	30 (12)	30 (12)	20 (8)	15 (6)	CRWS-128/240-A	CRWS-128/240-C-A
3300	240	46 (18)	30 (12)	20 (8)	15 (6)	CRWS-188/240-A	CRWS-188/240-C-A
4400	240**	61*** (24)	30 (12)	20 (8)	15 (6)	CRWS-248/240-A	CRWS-248/240-C-A
2250	240	30 (12)	36 (14)	25 (10)	20 (8)	CRWS-1210/240-A	CRWS-1210/240-C-A
3400	240**	46 (18)	36 (14)	25 (10)	20 (8)	CRWS-1810/240-A	CRWS-1810/240-C-A
4500	240**	61*** (24)	36 (14)	25 (10)	20 (8)	CRWS-2410/240-A	CRWS-2410/240-C-A
2700	240	30 (12)	41 (16)	30 (12)	25 (10)	CRWS-1212/240-A	CRWS-1212/240-C-A
4050	240**	46 (18)	41 (16)	30 (12)	25 (10)	CRWS-1812/240-A	CRWS-1812/240-C-A
5400	240**	61*** (24)	41 (16)	30 (12)	25 (10)	CRWS-2412/240-A	CRWS-2412/240-C-A
3400	240**	30 (12)	48 (19)	38 (15)	33 (13)	CRWS-1215/240-A	CRWS-1215/240-C-A
5100	240**	46 (18)	48 (19)	38 (15)	33 (13)	CRWS-1815/240-A	CRWS-1815/240-C-A
6800	240**	61*** (24)	48 (19)	38 (15)	33 (13)	CRWS-2415/240-A	CRWS-2415/240-C-A
4100	240**	30 (12)	56 (22)	46 (18)	41 (16)	CRWS-1218/240-A	CRWS-1218/240-C-A
6150	240**	46 (18)	56 (22)	46 (18)	41 (16)	CRWS-1818/240-A	CRWS-1818/240-C-A
8200	240**	61*** (24)	56 (22)	46 (18)	41 (16)	CRWS-2418/240-A	CRWS-2418/240-C-A
4750	240**	30 (12)	64 (25)	53 (21)	48 (19)	CRWS-1221/240-A	CRWS-1221/240-C-A
7125	240**	46 (18)	64 (25)	53 (21)	48 (19)	CRWS-1821/240-A	CRWS-1821/240-C-A
9500	240**	61*** (24)	64 (25)	53 (21)	48 (19)	CRWS-2421/240-A	CRWS-2421/240-C-A

* Add 3" for units with vestibules. ** Dual 240 Vac circuits.

*** Using two 30 cm (12") long heaters; the indicated wattage is a total of two 30 cm (12") long heaters.

Ordering Example: CRWS-67/240-A, 920 Watt, 240 Vac heater, 15 cm (6") long, 18 cm (7") ID.

omega.co.uk®

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

www.omega.co.uk



UNITED STATES

www.omega.com

1-800-TC-OMEGA
Stamford, CT.

UNITED KINGDOM

www.omega.co.uk

Manchester, England
0800-488-488
+44-(0)161-777-6611

CANADA

www.omega.ca

Laval(Quebec)
1-800-TC-OMEGA

FRANCE

www.omega.fr

0800-466-342

GERMANY

www.omega.de

Deckenfronn, Germany
0800-8266342

BENELUX

www.omega.nl

0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485, Ethernet and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters