


HIGH TEMPERATURE MODULAR HOPPER HEATER

FSRM Series Starts at **\$330**



FSRM-0612/225W/240V, \$330, shown smaller than actual size.

Dimensions

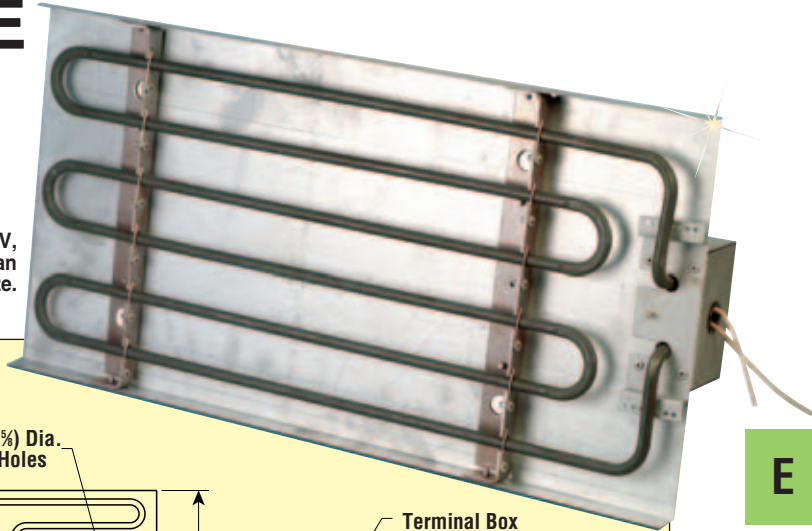

- ✓ INCOLOY® Sheath
- ✓ 225 to 2600 Watts
- ✓ 240 and 480 Volt
- ✓ 3 to 15 W/in²
- ✓ Up to 400°C (750°F) and Above Hopper Temperatures
- ✓ Custom Built to Fit Requirements

APPLICATIONS


- ✓ Electrostatic Precipitators
- ✓ Fabric Filter Dust Collecting Hoppers

ADVANTAGES

Made-to-order to your hopper specifications.

Low watt density design ensures long life while providing operating temperatures of 121 to 177°C (250 to 350°F) or higher.

Heaters can withstand upset conditions where temperatures in the hopper may be as high as 649°C (1200°F).

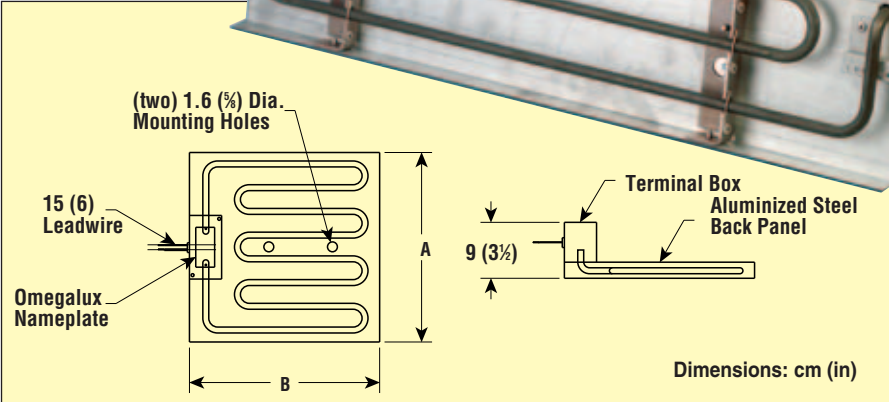

FEATURES

Manufactured from formed 9.5 mm (0.375") diameter INCOLOY® sheathed tubular low watt density elements for long life.

Equipped with 15 cm (6"), 16 gauge nickel plated copper lead wire with mica type high temperature insulation rated 450°C (842°F) for easy connection.

Shock and vibration resistant design.

Modules are fire resistant and not affected by internal hopper fires.

CONSTRUCTION

9.5 mm (0.375") Tubular Heating Elements are serpentine bent and mounted on a steel angle frame support with a backup aluminized steel sheet metal reflective encasement.

When installed on the sides of the hopper and insulated, they provide a blanket heat coverage effect.

OPTIONS

- Special Voltages
- Wattage
- Sizes
- Shapes

MOST POPULAR MODELS HIGHLIGHTED!

To Order (Specify Model Number)

Model No.	Price	Watts	Volts	W/in ²	Size cm (in)	Weight (Lb.)
FSRM-0612/225W/240V	\$330	225	240	3	15 x 30 (6 x 12)	8
FSRM-0612/450W/240V	330	450	240	6	15 x 30 (6 x 12)	8
FSRM-1212/550W/480V	350	550	480	3.8	30 x 30 (12 x 12)	16
FSRM-1212/450W/240V	350	450	240	3.1	30 x 30 (12 x 12)	16
FSRM-1212/900W/480V	350	900	480	6	30 x 30 (12 x 12)	16
FSRM-1218/650W/480V	370	650	480	3	30 x 46 (12 x 18)	24
FSRM-1218/1300W/480V	370	1300	480	6	30 x 46 (12 x 18)	24
FSRM-1818/1000W/480V	405	1000	480	3	46 x 46 (18 x 18)	32
FSRM-1818/2000W/480V	405	2000	480	6	46 x 46 (18 x 18)	32
FSRM-1224/875W/480V	395	875	480	3	30 x 61 (12 x 24)	32
FSRM-1224/1750W/480V	395	1750	480	6	30 x 61 (12 x 24)	32
FSRM-1248/2600W/480V	480	2600	480	4.5	30 x 122 (12 x 48)	64

Ordering Examples: FSRM-1218/650W/480V, 650 Watt, 480V hopper heater, \$370.

FSRM-1224/875W/480V, 875 Watt, 480V hopper heater, \$395.

omega.co.uk[®]

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

www.omega.co.uk



UNITED STATES

www.omega.com

1-800-TC-OMEGA
Stamford, CT.

CANADA

www.omega.ca

Laval(Quebec)
1-800-TC-OMEGA

GERMANY

www.omega.de

Deckenfronn, Germany
0800-8266342

UNITED KINGDOM

www.omega.co.uk

Manchester, England
0800-488-488
+44-(0)161-777-6611

FRANCE

www.omega.fr

0800-466-342

BENELUX

www.omega.nl

0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485, Ethernet and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters