

SIDE MOUNT FLUOROPOLYMER COVERED HEATERS

GTF6 and GTF9 Series Starts at

\$126



GTF6—6 Elements

- ✓ 6 Fluoropolymer Covered Stainless Steel Elements
- ✓ 10 W/in²
- ✓ 2 to 12 kW
- ✓ 240 and 480V, 3 Phase
- ✓ Moisture Resistant Terminal Enclosure

GTF9 – 9 Elements

- ✓ 9 Fluoropolymer Covered Stainless Steel Elements
- ✓ 10 W/in²
- ✓ 3 to 18 kW
- ✓ 240 and 480V, 3 Phase
- ✓ Moisture Resistant Terminal Enclosure



FEATURES

- ✓ Moisture Resistant Terminal Enclosure
- ✓ Side Mounted Construction with Mounting Flange
- ✓ Overtemperature Protection One Time Use Thermal Fuse (260°F), Field Replaceable
- ✓ Polypropylene Guard, Order Separately
- ✓ Custom Vertical Heights and Other Configurations Available
- ✓ Alternate Voltages and Single Phase Available

GTF6, \$126, shown smaller than actual size.



GTF9, \$150, shown smaller than actual size.

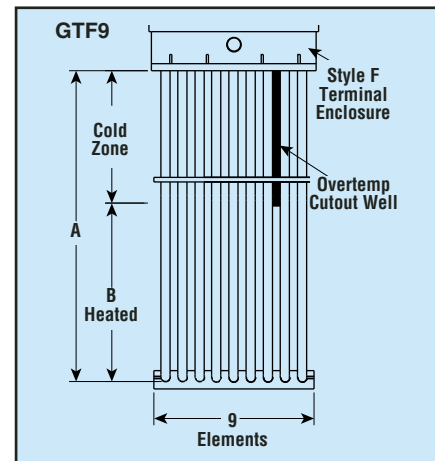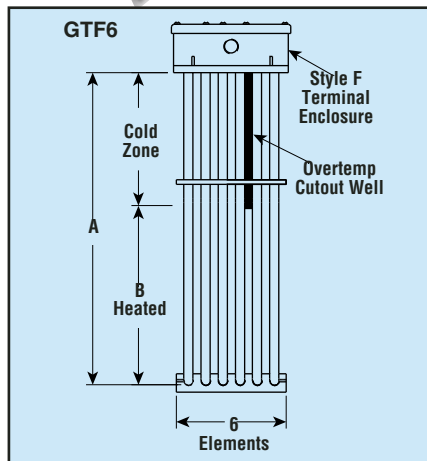

MOST POPULAR MODELS HIGHLIGHTED!

To Order (Specify Model Number)

kW	Volts	W/in ²	Phase	DIM (in)		Fluoropolymer Model No.	Price	Wt. (lb)	Guard ¹ Model No.	Guard ¹ Price
				A	B					
GTF6 — 6 Elements										
2	240	10	3	17	9	GTF6-22	\$655	19	GTF6-2G	\$126
2	480	10	3	17	9	GTF6-24	726	19		
3	240	10	3	23	15	GTF6-32	833	22	GTF6-3G	141
3	480	10	3	23	15	GTF6-34	833	22		
4	240	10	3	29	21	GTF6-42	1010	24	GTF6-4G	155
4	480	10	3	29	21	GTF6-44	1010	24		
6	240	10	3	35	27	GTF6-62	1182	27	GTF6-6G	172
6	480	10	3	35	27	GTF6-64	1182	27		
8	240	10	3	47	38	GTF6-82	1438	33	GTF6-8G	199
8	480	10	3	47	38	GTF6-84	1438	33		
10	240	10	3	59	47	GTF6-102	1546	40	GTF6-10G	262
10	480	10	3	59	47	GTF6-104	1546	40		
12	240	10	3	68	55	GTF6-122	889	45	GTF6-12G	299
12	480	10	3	68	55	GTF6-124	889	45		
GTF9 — 9 Elements										
3	240	10	3	17	9	GTF9-32	\$1001	28	GTF9-3G	\$150
3	480	10	3	17	9	GTF9-34	1001	28		
4.5	240	10	3	23	15	GTF9-452	1137	33	GTF9-45G	170
4.5	480	10	3	23	15	GTF9-454	1137	33		
6	240	10	3	29	21	GTF9-62	1376	36	GTF9-6G	180
6	480	10	3	29	21	GTF9-64	1376	36		
9	240	10	3	35	27	GTF9-92	1376	40	GTF9-9G	204
9	480	10	3	35	27	GTF9-94	1376	40		
12	240	10	3	47	38	GTF9-122	1608	49	GTF9-12G	236
12	480	10	3	47	38	GTF9-124	1608	49		
15	240	10	3	59	47	GTF9-152	1906	60	GTF9-15G	308
15	480	10	3	59	47	GTF9-154	1906	60		
18	240	10	3	68	55	GTF9-182	2108	67	GTF9-18G	359
18	480	10	3	68	55	GTF9-184	2108	67		

¹ Guard (not shown). Order separately by Model Number. Guard adds approximately 1/2" to overall heater dimensions.

Ordering Examples: GTF6-62, 240V, 6 kW, 6-element heater, \$689 and GTF6-6G, heater guard, \$172, \$1010 + 172 = \$1182. GTF9-122, 12 kW heater, \$1689.

omega.co.uk[®]

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

www.omega.co.uk



UNITED STATES

www.omega.com

1-800-TC-OMEGA
Stamford, CT.

CANADA

www.omega.ca

Laval(Quebec)
1-800-TC-OMEGA

GERMANY

www.omega.de

Deckenfronn, Germany
0800-8266342

UNITED KINGDOM

www.omega.co.uk

Manchester, England
0800-488-488
+44-(0)161-777-6611

FRANCE

www.omega.fr

0800-466-342

BENELUX

www.omega.nl

0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485, Ethernet and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters