

HEAVY DUTY PORTABLE HEATERS



TYPE HF PORTABLE SPACE HEATER

- ✓ 1.9, 2, 3, 4kW
- ✓ Lightweight
- ✓ Quick Response Element
- ✓ Quiet, Smooth-Running Motor & Fan
- ✓ Built-in Overheat Protection
- ✓ On-off Toggle Switch (AC Models)

Housing is heavy-gauge steel with handle and rubber feet. Finish is heat-resistant green Hammerloid.




Overheat protection. All heaters have integral, automatic thermal cutout. DC heaters are equipped with a DC magnetic contactor with thermal cutout wired in series with holding coil.

Dimensions. 11 $\frac{3}{8}$ "(29cm) wide, 13 $\frac{5}{16}$ "(33cm) tall, 8"(20cm) deep

Cord and plug. AC and DC HF heaters are supplied with 6-ft. cord and grounded polarized plug except 240VDC HF-403D DC, 120VAC HF-303 AC and 120VDC HF-303D DC.

Thermostat for automatic heating. See Type WR, page L-10

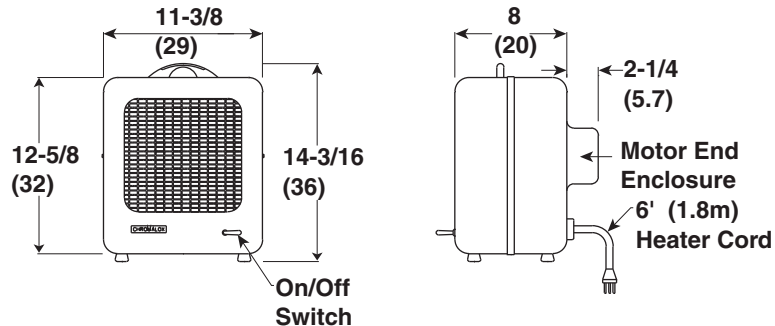

Dimensions in inches (cm)

To Order (Specify Model Number)

kW	Volts	Phase	Output BTU/hr	Amps	Air temp. rise °F*	Air spd. ft./min.*	Model No.	Price	Wt.* lbs. kg
AC (supplied with on-off switch)									
1.9	120	1	6483	15.8	46	140	HF-203G AC	£419	16 $\frac{1}{2}$ (7)
2	240	1	6824	8.3	46	140	HF-203G AC/240	419	16 $\frac{1}{2}$ (7)
3	120	1	10236	25	70	140	HF-303 AC***	505	19 (9)
3	240	1	10236	12.5	70	140	HF-303G AC	505	19 (9)
4	240	1	13648	16.7	92	140	HF-403G AC	585	19 (9)
DC									
1.9	120	1	6483	15.8	46	140	HF-203DG DC	805	16 $\frac{1}{2}$ (7)
2	240	1	6824	8.3	46	140	HF-203DG DC/240	805	16 $\frac{1}{2}$ (7)
3	240	1	10236	12.5	70	140	HF-303DG DC	840	19(9)
4	240	1	13648	16.7	92	140	HF-403D DC**	905	19(9)

*Approximate **Without cord & plug. ***Cord only, no plug

omega.co.uk[®]

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

www.omega.co.uk



UNITED STATES

www.omega.com

1-800-TC-OMEGA
Stamford, CT.

UNITED KINGDOM

www.omega.co.uk

Manchester, England
0800-488-488
+44-(0)161-777-6611

CANADA

www.omega.ca

Laval(Quebec)
1-800-TC-OMEGA

FRANCE

www.omega.fr

0800-466-342

GERMANY

www.omega.de

Deckenfronn, Germany
0800-8266342

BENELUX

www.omega.nl

0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485, Ethernet and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters