

1 cm ($\frac{3}{8}$ ") DIAMETER HEART CROSS-SECTION



LMS-43X1, \$67, shown smaller than actual size.

LMS Series Starts at **\$51**

- ✓ INCOLOY® Sheath
- ✓ 450 to 1750 Watts
- ✓ 120, 208, 240 and 480 Volt
- ✓ 41 to 47 W/in²
- ✓ 2½" Cold Ends
- ✓ 870°C (1600°F) Maximum Sheath Temperature
- ✓ Component of Radiant Heater (Type LN and LW)

APPLICATIONS

- Radiant Heating in Room Ambient
- Heating High Velocity Air
- Low Temperature Clamp-ons

ADVANTAGES


Specially constructed to provide excellent service life in radiant heating applications.

FEATURES

Lead Wire: Terminals useful wherever flexible leads are desired.

Work Temperatures: See Tubular Heater Overview at omega.com/heaters

Bending: Lengthwise only. Minimum inside bending radius 1". See bending requirements in the Tubular Heater Overview at omega.com/heaters

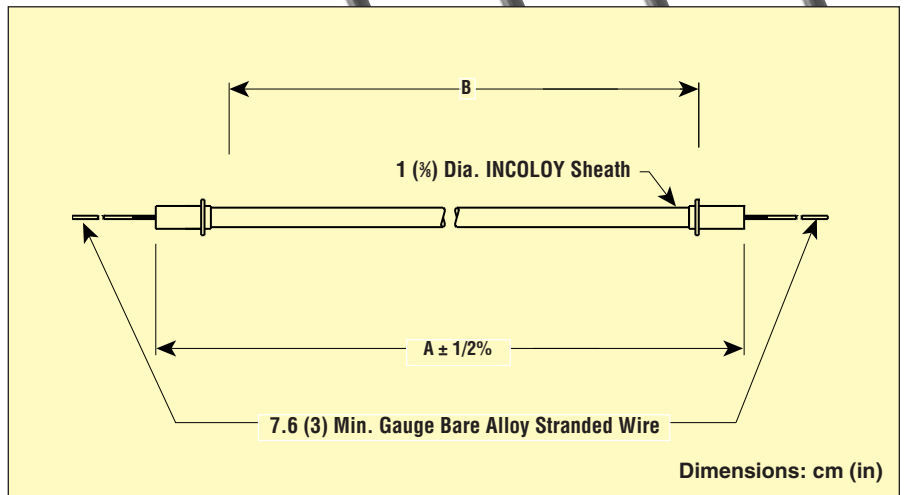

MOST POPULAR MODELS HIGHLIGHTED!

To Order (Specify Model Number)							
INCOLOY Sheath		Watts	Volts	W/in ²	Dimensions (In.)		Weight (Lb.)
Model No.	Price				Sheath A	Heated B	
LMS-15	\$51	450	120	48	12¼ (79)	8 (20)	1
LMS-21X1	55	725	208	44	18⅛ (60)	13⅞ (35)	1
LMS-21	55	725	240	44	18⅛ (60)	13⅞ (35)	1
LMS-30X1	62	1150	208	43	27 (69)	22¾ (78)	1
LMS-30	62	1150	240	43	27 (69)	22¾ (78)	1
LMS-43X1	67	1750	208	42	40 (102)	35¾ (91)	2
LMS-43	67	1750	240	42	40 (102)	35¾ (91)	2
LMS-43X2	67	1750	480	42	40 (102)	35¾ (91)	2

Ordering Examples: LMS-15, 450 W tubular heater, \$51. LMS-43, 1750 W tubular heater, \$67.

omega.co.uk[®]

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

www.omega.co.uk



UNITED STATES

www.omega.com

1-800-TC-OMEGA
Stamford, CT.

CANADA

www.omega.ca

Laval(Quebec)
1-800-TC-OMEGA

GERMANY

www.omega.de

Deckenfronn, Germany
0800-8266342

UNITED KINGDOM

www.omega.co.uk

Manchester, England
0800-488-488
+44-(0)161-777-6611

FRANCE

www.omega.fr

0800-466-342

BENELUX

www.omega.nl

0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485, Ethernet and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters