

CORROSIVE OIL & HIGHLY CORROSIVE SOLUTION APPLICATIONS

NWHOIS Series



To Order (Specify Model Number)

**MOST POPULAR
ITEMS HIGHLIGHTED**

kW	Volts	Ckt & Phase	Dimensions (In.)			Model No.	Price	Wt. (Lbs.)
			A	B	C			
Series 03 — 3 inch, 150 lb 304 passivated stainless steel vessel, 3 INCOLOY elements (15 W/in²) with side mounted thermostat (60 to 250°F) — 1" NPT pipe inlet and outlet								
2	240	1-3	32 ¹⁵ / ₁₆	22 ¹ / ₂	16 ¹ / ₂	NWHOIS-03-002P-E1/240	\$3279	70
2	480	1-3	32 ¹⁵ / ₁₆	22 ¹ / ₂	16 ¹ / ₂	NWHOIS-03-002P-E1/480	3279	70
4	240	1-3	42 ¹⁵ / ₁₆	32 ¹ / ₂	26 ¹ / ₂	NWHOIS-03-004P-E1/240	3495	80
4	480	1-3	42 ¹⁵ / ₁₆	32 ¹ / ₂	26 ¹ / ₂	NWHOIS-03-004P-E1/480	3495	80
6	240	1-3	55 ¹⁵ / ₁₆	45	39	NWHOIS-03-006P-E1/240	3784	98
6	480	1-3	55 ¹⁵ / ₁₆	45	39	NWHOIS-03-006P-E1/480	3784	98
Series 06 — 5 inch, 150 lb 304 passivated stainless steel vessel, 6 INCOLOY elements (15 W/in²) with side mounted thermostat (60 to 250°F) — 2" NPT pipe inlet and outlet								
8	240	1-3	4 ¹ / ₄	30	11 ¹ / ₂	NWHOISR-06-008P-E1/240	6069	140
8	480	1-3	4 ¹ / ₄	30	11 ¹ / ₂	NWHOISR-06-008P-E1/480	6069	140
12	240	1-3	60 ¹ / ₄	48 ¹ / ₂	20 ¹ / ₂	NWHOISR-06-012P-E1/240	7445	176
12	480	1-3	60 ¹ / ₄	48 ¹ / ₂	20 ¹ / ₂	NWHOISR-06-012P-E1/480	7445	176
Series 06 — 5 inch, 150 lb 304 passivated stainless steel vessel, 6 INCOLOY elements (23 W/in²) with side mounted thermostat (60 to 250°F) — 2" NPT pipe inlet and outlet								
25	240	2-3	73 ³ / ₈	61 ¹ / ₂	27 ¹ / ₈	NWHOIS-06-025P-E1/240	8402	176
25	480	1-3	73 ³ / ₈	61 ¹ / ₂	27 ¹ / ₈	NWHOIS-06-025P-E1/480	8402	176
30	240	2-3	86 ³ / ₈	74 ¹ / ₂	33 ¹ / ₂	NWHOIS-06-030P-E1/240	9407	240
30	480	1-3	86 ³ / ₈	74 ¹ / ₂	33 ¹ / ₂	NWHOIS-06-030P-E1/480	9407	240

Ordering Example: NWHOISR-06-008P-E1/480 is a 8 kW, 480 Volt Heater, \$6069.


Note — Refer to the Controls section for side mounted controls or control panels.

Ordering Information


To Order — Complete the Model Number using the Matrix provided.

Model	Corrosive Oil and Highly Corrosive Solution		
NWHO	Oil Circulation Heater		
IS	INCOLOY Elements — Stainless Steel Vessel		
R	Reduced Watt Density		
Code	Number of Elements		
03	Three		
06	Six		
Code	kW		
002P	2	008P	8
004P	4	012P	12
006P	6	025P	25
		030P	30
Code	Terminal Enclosure		
E1	General Purpose		
E2	Moisture Resistant/Explosion Resistant		
E3	Explosion Resistant		
E4	Moisture Resistant		
NWHOIS 03	002P	E1	Typical Model Number


Dimensions (Inches) NWHOIS-03

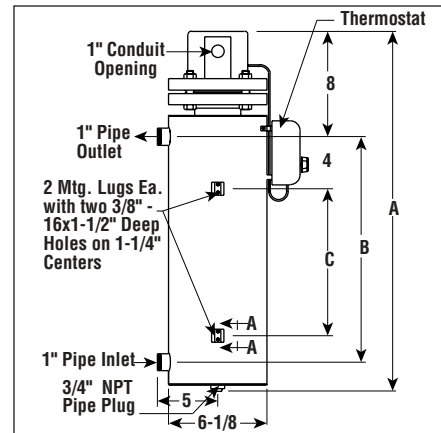

NWHOIS-06

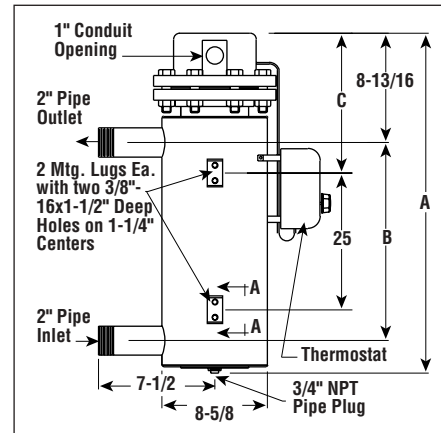

NWHOIS-AA

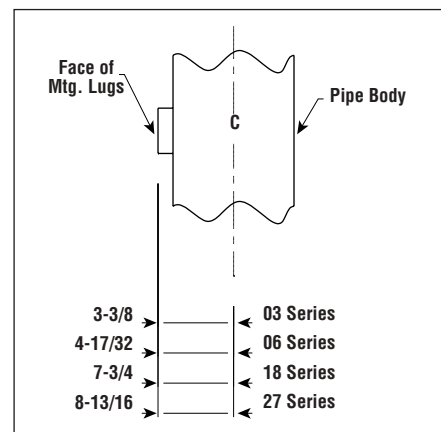

omega.co.uk[®]

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

www.omega.co.uk



UNITED STATES

www.omega.com

1-800-TC-OMEGA
Stamford, CT.

UNITED KINGDOM

www.omega.co.uk

Manchester, England
0800-488-488
+44-(0)161-777-6611

CANADA

www.omega.ca

Laval(Quebec)
1-800-TC-OMEGA

FRANCE

www.omega.fr

0800-466-342

GERMANY

www.omega.de

Deckenfronn, Germany
0800-8266342

BENELUX

www.omega.nl

0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485, Ethernet and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters