



ENCLOSURE HEATERS

For Protection from Freezing or Condensation in Enclosures

Available in a Variety of Lengths!



Series SRFE Starts at **\$31**



- ✓ 60 and 120 W Models
- ✓ Preset Thermostat Options
- ✓ Mounting Plates Standard

SRFE Series enclosure heaters feature an etched foil element encapsulated between layers of fiberglass-reinforced silicone rubber, and are factory vulcanized to an aluminum mounting plate. Mounting plates come with 11 mm (7/16") holes for mounting to subpanels or other mounting surfaces.


The built-in air-sensing thermostat maintains the temperature within the enclosure to prevent freezing or condensation. The SRFE enclosure heaters are mounted vertically or horizontally using the mounting plate; however, optional temperature control is achieved when mounting the heater vertically.

Options for the SRFE Series enclosure heaters include custom sizes and remote-mounted thermostats. Contact Engineering for more information.

SPECIFICATIONS

Operating Temperature: -40 to 176°C (-40 to 350°F)
Voltage: 115 Vac
Watt Density: 5 W/in²
Width: 64 mm (2.5")
Thickness: 3 mm (0.125")
Flange Width: 13 mm (0.5")
Mounting Holes: 11 mm (7/16") ID, located 25 mm (1") in from each end
Leads: 1219 mm (48") long, 22 AWG PFA insulated

SRFE-6, \$31, shown smaller than actual size.

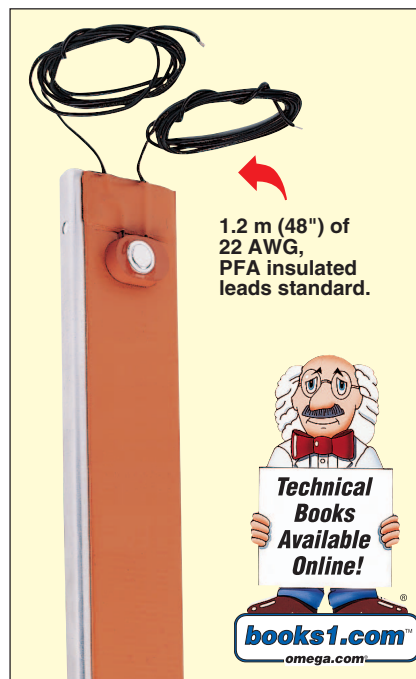

ALL MODELS AVAILABLE FOR FAST DELIVERY!

To Order (Specify Model Number)					
Model Number	Price	Length and Width mm (in)	Wattage	Thermostat Setpoint	
				Opens	Closes
SRFE-6	\$31	152 x 64 (6 x 2.5)	60	None	None
SRFE-6-40	104	152 x 64 (6 x 2.5)	60	60°F ±5°	40°F ±5°
SRFE-6-105	104	152 x 64 (6 x 2.5)	60	140°F ±5°	110°F ±5°
SRFE-6-150	104	152 x 64 (6 x 2.5)	60	180°F ±5°	150°F ±5°
SRFE-12	42	305 x 64 (12 x 2.5)	120	None	None
SRFE-12-40	113	305 x 64 (12 x 2.5)	120	60°F ±5°	40°F ±5°
SRFE-12-105	113	305 x 64 (12 x 2.5)	120	140°F ±5°	110°F ±5°
SRFE-12-150	113	305 x 64 (12 x 2.5)	120	180°F ±5°	150°F ±5°

Ordering Example: SRFE-6-105, 6" enclosure heater with 41°C (105°F) setpoint integral thermostat, \$104.

omega.co.uk®

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

www.omega.co.uk



UNITED STATES

www.omega.com

1-800-TC-OMEGA
Stamford, CT.

UNITED KINGDOM

www.omega.co.uk

Manchester, England
0800-488-488
+44-(0)161-777-6611

CANADA

www.omega.ca

Laval(Quebec)
1-800-TC-OMEGA

FRANCE

www.omega.fr

0800-466-342

GERMANY

www.omega.de

Deckenfronn, Germany
0800-8266342

BENELUX

www.omega.nl

0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485, Ethernet and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters