 



# 12.7 mm (0.5") DIAMETER HEART CROSS-SECTION



TI Series Starts at

**\$141**

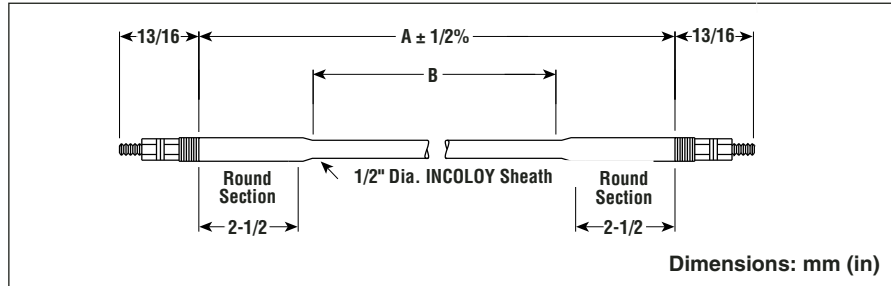

- ✓ INCOLOY Sheath
- ✓ 450 to 2500 Watts
- ✓ 120, 240 and 480 Volt
- ✓ 30 W/in<sup>2</sup>
- ✓ 1600°F Max Sheath Temp

## APPLICATIONS

High element surface temperature clamp-on or air heating applications or where extreme rigidity is required.

## ADVANTAGES

More uniform surface temperatures and resistance to deformation.

## FEATURES

**Type 4 Terminals:** Standard. Integral parts of the element are of high strength to resist bending during tightening of the wiring connections. Type 4 is threaded extension of the cold pin. See terminal detail drawing in the Tubular Heater Overview at [omega.com/heaters](http://omega.com/heaters)

**Work Temperatures:** See Tubular Heater Overview at [omega.com/heaters](http://omega.com/heaters)

**Bending:** Customer's minimum inside bending radius is 1½". See bending requirements in the Tubular Heater Overview at [omega.com/heaters](http://omega.com/heaters)

**MOST POPULAR MODELS HIGHLIGHTED!**

To Order (Specify Model Number)							
Watts	Volts	W/in <sup>2</sup>	Dimensions cm (in)		Incoloy Sheath		Weight (lb)
			Sheath A	Heated B	Model No.	Price	
450	120	30	41 (16)	24 (9½)	TI-1645/120	\$141	0.22 (0.5)
540	120	30	46 (18)	29 (11½)	TI-1845/120	143	0.22 (0.5)
635	120	30	51 (20)	34 (13½)	TI-2045/120	146	0.22 (0.5)
750	120	30	58 (23)	42 (16½)	TI-2345/120	149	0.22 (0.5)
750	240	30	58 (23)	42 (16½)	TI-2345/240	149	0.22 (0.5)
825	120	30	64 (25)	47 (18½)	TI-2545/120	151	0.22 (0.5)
825	240	30	64 (25)	47 (18½)	TI-2545/240	151	0.22 (0.5)
900	120	30	69 (27)	52 (20½)	TI-2745/120	154	0.22 (0.5)
900	240	30	69 (27)	52 (20½)	TI-2745/240	154	0.22 (0.5)
1000	120	30	71 (28)	55 (21½)	TI-2845/120	155	0.45 (1)
1000	240	30	71 (28)	55 (21½)	TI-2845/240	155	0.45 (1)
1100	120	30	76 (30)	60 (23½)	TI-3045/120	157	0.45 (1)
1100	240	30	76 (30)	60 (23½)	TI-3045/240	157	0.45 (1)
1200	120	30	81 (32)	65 (25½)	TI-3245/120	160	0.45 (1)
1200	240	30	81 (32)	65 (25½)	TI-3245/240	160	0.45 (1)
1275	120	30	86 (34)	70 (27½)	TI-3445/120	162	0.45 (1)
1275	240	30	86 (34)	70 (27½)	TI-3445/240	162	0.45 (1)
1350	120	30	91 (36)	75 (29½)	TI-3645/120	164	0.45 (1)
1350	240	30	91 (36)	75 (29½)	TI-3645/240	164	0.45 (1)
1425	120	30	97 (38)	80 (31½)	TI-3845/120	166	0.45 (1)
1425	240	30	97 (38)	80 (31½)	TI-3845/240	166	0.45 (1)
1500	120	30	102 (40)	85 (33½)	TI-4045/120	169	0.59 (1.3)
1500	240	30	102 (40)	85 (33½)	TI-4045/240	169	0.59 (1.3)
1650	120	30	110 (43½)	94 (37)	TI-4345/120	172	0.59 (1.3)
1650	240	30	110 (43½)	94 (37)	TI-4345/240	172	0.59 (1.3)
1725	120	30	112 (44)	95 (37½)	TI-4445/120	173	0.59 (1.3)
1725	240	30	112 (44)	95 (37½)	TI-4445/240	173	0.59 (1.3)
1800	120	30	117 (46)	100 (39½)	TI-4645/120	204	0.59 (1.3)
1800	240	30	117 (46)	100 (39½)	TI-4645/240	204	0.59 (1.3)
1875	120	30	122 (48)	105 (41½)	TI-4845/120	207	0.59 (1.3)
1875	240	30	122 (48)	105 (41½)	TI-4845/240	207	0.59 (1.3)
1950	120	30	127 (50)	110 (43½)	TI-5045/120	211	0.59 (1.3)
1950	240	30	127 (50)	110 (43½)	TI-5045/240	211	0.59 (1.3)
1950	480	30	127 (50)	110 (43½)	TI-5045/480	211	0.59 (1.3)
2000	120	30	138 (54¼)	120 (47⅞)	TI-5445/120	217	0.81 (1.8)
2000	240	30	138 (54¼)	120 (47⅞)	TI-5445/240	217	0.81 (1.8)
2000	480	30	138 (54¼)	120 (47⅞)	TI-5445/480	217	0.81 (1.8)
2250	120	30	147 (58)	131 (51½)	TI-5845/120	223	0.81 (1.8)
2250	240	30	147 (58)	131 (51½)	TI-5845/240	223	0.81 (1.8)
2250	480	30	147 (58)	131 (51½)	TI-5845/480	223	0.81 (1.8)
2500	120	30	152 (60)	136 (53½)	TI-6045/120	226	0.81 (1.8)
2500	240	30	152 (60)	136 (53½)	TI-6045/240	226	0.81 (1.8)
2500	480	30	152 (60)	136 (53½)	TI-6045/480	226	0.81 (1.8)

Ordering Examples: TI-4345/240, 1650 W, 240V heater, \$172.

TI-1645/120, 450W, 240V heater, \$141.

E

# omega.co.uk<sup>®</sup>

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

[www.omega.co.uk](http://www.omega.co.uk)



#### UNITED STATES

[www.omega.com](http://www.omega.com)

1-800-TC-OMEGA  
Stamford, CT.

#### CANADA

[www.omega.ca](http://www.omega.ca)

Laval(Quebec)  
1-800-TC-OMEGA

#### GERMANY

[www.omega.de](http://www.omega.de)

Deckenfronn, Germany  
0800-8266342

#### UNITED KINGDOM

[www.omega.co.uk](http://www.omega.co.uk)

Manchester, England  
0800-488-488  
+44-(0)161-777-6611

#### FRANCE

[www.omega.fr](http://www.omega.fr)

0800-466-342

#### BENELUX

[www.omega.nl](http://www.omega.nl)

0800-099-33-44



## More than 100,000 Products Available!

### • Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

### • Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

### • pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

### • Data Acquisition

Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485, Ethernet and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

### • Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

### • Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters