

# BOTTOM MOUNTING PLATES FOR LC1001/LC1011 SERIES LOAD CELLS ALLOY STEEL OR 17-4 PH STAINLESS STEEL


## LC1001/LC1011 Series Bottom Mounting Plates for Ranges 500 lb to 300,000 lb 227 kg to 136,116 kg

1 Newton = 0.2248 lb  
1 daNewton = 10 Newtons  
1 lb = 454 g  
1 t = 1000 kg = 2204 lb

Starts at  
**\$48**



LC1011-10K, \$895,  
load cell, shown  
smaller than actual size.

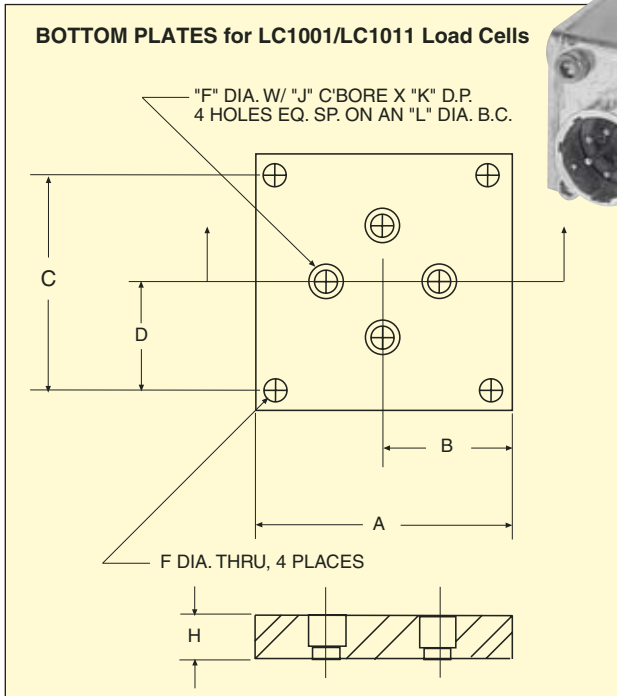

**MOST POPULAR MODELS HIGHLIGHTED!**

To Order (Specify Model Number)					Dimensions: mm (in)								
CAPACITY lb (kg)	PLATED STEEL	PRICE	STAINLESS STEEL	PRICE	A	B	C	D	F	H	J	K	L
500 to 50K (227 to 22,686)	LC1000-BP4	\$48	LC1000-BP4-SS	\$80	114 (4.50)	57 (2.25)	95 (3.75)	46 (1.88)	10 (0.41)	19 (0.750)	16 (0.625)	15 (0.59)	60 (2.38)
100K (45,372)	LC1000-BP6	68	LC1000-BP6-SS	140	152 (6.00)	76 (3.00)	121 (4.75)	60 (2.38)	13 (0.53)	25 (1.00)	20 (0.77)	18 (0.72)	102 (4.00)
200K (90,944)	LC1000-BP8	126	LC1000-BP8-SS	260	203 (8.00)	102 (4.00)	171 (6.75)	86 (3.38)	17 (0.66)	32 (1.25)	25 (1.00)	22 (0.88)	140 (5.50)
300K (136,116)	LC1000-BP9	146	N/A		229 (9.00)	114 (4.50)	191 (7.50)	95 (3.75)	20 (0.78)	38 (1.50)	30 (1.19)	27 (1.06)	140 (5.50)

**Ordering Examples:** LC1000-BP4-SS, stainless steel base plate for LC1001/LC1011 load cells, 500 to 50K lb range, \$80. LC1000-BP6, nickel-plated steel base plate for LC1001/LC1011 load cells, 100,000 lb range, \$68. LC1000-BP9, nickel-plated steel base plate for LC1001/LC1011 load cells, 300,000 lb range, \$146.

### ACCESSORY

MODEL NO.	PRICE	DESCRIPTION
ME-1810	\$50	Reference Book: Material and Design (Material Solution)



# omega.co.uk<sup>®</sup>

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

[www.omega.co.uk](http://www.omega.co.uk)



#### UNITED STATES

[www.omega.com](http://www.omega.com)

1-800-TC-OMEGA  
Stamford, CT.

#### CANADA

[www.omega.ca](http://www.omega.ca)

Laval(Quebec)  
1-800-TC-OMEGA

#### GERMANY

[www.omega.de](http://www.omega.de)

Deckenfronn, Germany  
0800-8266342

#### UNITED KINGDOM

[www.omega.co.uk](http://www.omega.co.uk)

Manchester, England  
0800-488-488  
+44-(0)161-777-6611

#### FRANCE

[www.omega.fr](http://www.omega.fr)

0800-466-342

#### BENELUX

[www.omega.nl](http://www.omega.nl)

0800-099-33-44



## More than 100,000 Products Available!

### • Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

### • Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

### • pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

### • Data Acquisition

Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485, Ethernet and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

### • Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

### • Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters