

PRESSURE TRANSDUCER OPTIONS AND ACCESSORIES

Options on this page are subject to availability on any specific model

General Options

Code	Description	Price
Temperature Compensation		
-TC1	-50 to 200F	£33.50
-TC2	-50 to 325°F	84
-TC3	-50 to 500°F	235

Bridge Resistance

-BR1K	1000Ω Bridge	£16.75
-BR5K	5000Ω Bridge	33.50

Calibration / Recalibration

-NC5	5-point Calibration*	£101
	0%, 50%, 100%, 50%, 0%	
-NC5T&C	5-Pt Ten&Comp.	201
-NC5C	5-point Comp.	101
-NC5T	5-point Tension	101
-NC11	11-point Calibration	
	20% increments @21°C	£168
-NC11T&C	11-Pt Ten&Comp.	335
-NC11C	11-point Comp.	168
-NC11T	11-point Tension	168
-NC-21	21-point Calibration	[*]
	10% increments @21°C	£235
-NC21T&C	5Pt Ten&Comp	469
-NC21C	5-point Comp.	235
-NC21T	5-point Tension	235

Extra Calibration Points	£16.75/pt
-NCX	Customer Specified
£101 set-up plus £16.75/point	
-CALSYS	System Calibration
5 pt, sensor and meter	
	£101

Mechanical Options

-OL	Overload Stops	£43.50
-OX	Oxygen Cleaning	43.50
-MB	Mounting Bracket	23.50

High Line Pressure

PX80 and PX83 Only

-LP2K	2000 psi	£50
-LP3K	3000 psi	84
-LP5K	5000 psi	131


Wetted Parts Options

-316SS	316 Stainless Steel	[*]
-HC	Hastelloy C	[*]
-MON	Monel	[*]
-INL	Inconel	[*]

Electrical Output Options

-5T	0 to 5 Vdc	+£23.50
to the "5V" Price		
-5V	0.5 to 5.5 Vdc	£80
-10T	0 to 10 Vdc	+£23.50
to the "10V" Price		
-10V	.5 to 10.5 Vdc	£80
-5Z	0 to 5 Vdc Isolated	£127
-I	4 to 20 mAdc	£111

* Standard with most Products

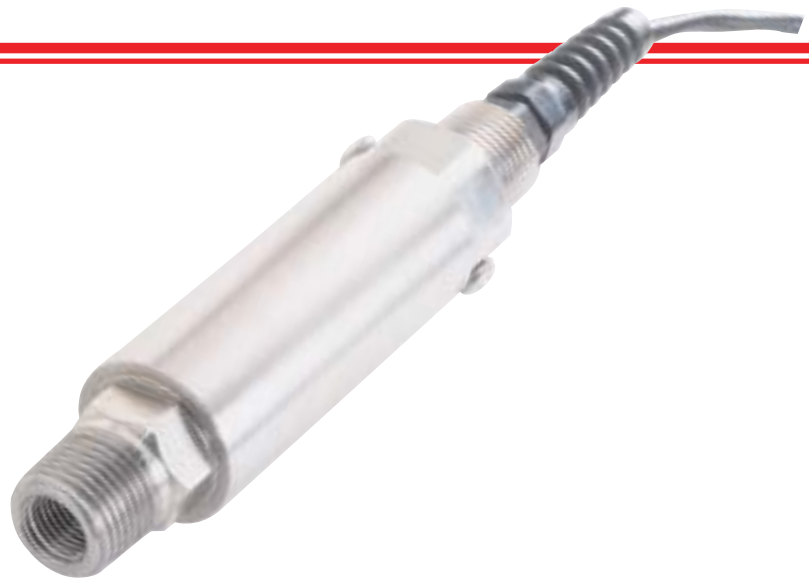

Miscellaneous Options

-Dual	Dual Bridge	£[*]
-IA	Improved Accuracy	£33.50
-WTC	Watertight Cable Exit	[*]
SI59K	Shunt, Internal, 59kΩ	[*]
SI90K	Shunt, Internal, 90kΩ	[*]
SI200K	Shunt, Internal, 200kΩ	[*]
SE59K	Shunt, External, 59kΩ	[*]
SE90K	Shunt, External, 90kΩ	[*]
SE200K	Shunt, External, 200kΩ	[*]

Cable/Connector Options

Additional Cable Length

"X" Feet	Cable Length
4-Conductor PVC	2.00/ft
4-Conductor Teflon	4.50/ft
6-Conductor PVC	2.75/ft
6-conductor Teflon	6.50/ft
Vented PVC Cable (2-cond)	2.50/ft
Vented PVC Cable (4-cond)	3.50/ft

Mating Connectors:

PT06F-8-4S	£17.75
PT06F-10-6S	17.75
PT06A-10-6S (SR)	17.75

Waterproof Strain Relief

for PT06A-10-6S	£13.50
for PTS06A-10-6S	£31.50

Cable/Connector Assemblies

PT06A-10-6S (SR) Cable Assemble	
£40 + Cable/ft charge	

Product Specific Options

PX81 Series	
316SS Wetted Parts	£67
PX90 Series	
Pressure Adaptor	£184
Cone or Lens Seal	£57

Pressure/Electrical Connections

Special Pressure Termination

Consult Engineering for Model Availability and Price

Special Electrical Termination

Consult Engineering for Model Availability and Price

[*] Price by Quotation when available on a specific model



omega.com[®]

Your One-Stop Source for Process Measurement and Control!

One Omega Drive | Stamford, CT 06907 | 1-888-TC-OMEGA (1-888-826-6342) | info@omega.com

www.omega.com



UNITED STATES

www.omega.com
1-800-TC-OMEGA
Stamford, CT.

CANADA

www.omega.ca
Laval(Quebec)
1-800-TC-OMEGA

GERMANY

www.omega.de
Deckenfronn, Germany
0800-8266342

UNITED KINGDOM

www.omega.co.uk
Manchester, England
0800-488-488

FRANCE

www.omega.fr
Guyancourt, France
088-466-342

CZECH REPUBLIC

www.omegaeng.cz
Karviná, Czech Republic
596-311-899

BENELUX

www.omega.nl
Amstelveen, NL
0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Glass Bulb Thermometers, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders Relative Humidity Measurement Instruments, RTD Probes, Elements and Assemblies, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples Thermowells and Head and Well Assemblies, Transmitters, Wire

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Auto-Dialers and Alarm Monitoring Systems, Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485 and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Strain Gages, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters

• [click here to go to the omega.com home page](http://www.omega.com) •