


Solid Probe Bayonet Style


With Stainless Steel Cable

- High-Temperature Design
- Wide Variety of Immersion Lengths, Styles and Mounting Arrangements Available
- Fast Delivery on Standard Configurations
- 304 Stainless Steel Construction
- Flexible 7.0 mm Stainless Steel Cable (1.5 m Standard)
- Glass Braid Insulated 7/0.32mm Stranded Thermocouple Wire
- Other Sheath and Insulation Materials Available, Consult Sales

From
£23

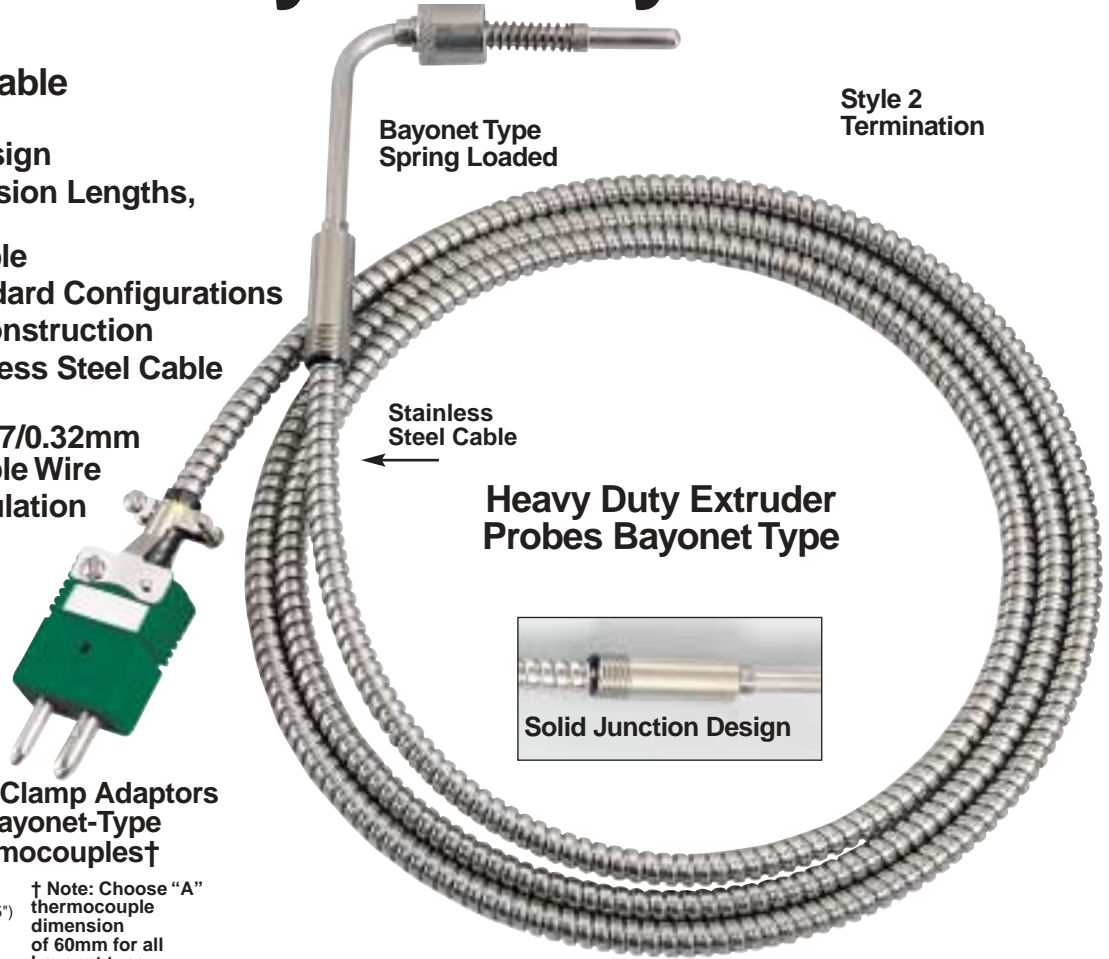

Style 2
Termination

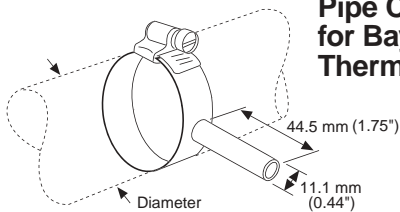


Pipe Clamp Adaptors for Bayonet-Type Thermocouples†

† Note: Choose "A" thermocouple dimension of 60mm for all bayonet type thermocouples used with pipe clamp adaptors.

To measure temperature of pipes without drilling.
Easily installed and removed.

Model Number	For Pipe Diameter (millimetre)	All Sizes £9.00 each. Material is Stainless Steel
BTC-1	13 to 22	
BTC-2	23 to 38	
BTC-3	34 to 57	
BTC-4	58 to 84	
BTC-5	85 to 107	
BTC-6	108 to 133	

 Adaptors for Bayonet-Type Thermocouples



Like a compression fitting, does not seal

Model Number	Length mm	Thread Size	Price
BTA-1BSP	22	1/8" BSPT	£4.90
BTA-2BSP	35	1/8" BSPT	5.70
BTA-3BSP	70	1/8" BSPT	6.60

Adaptor material is stainless steel

Discount Schedule	
1-24 Units.....Net	100-249 Units.....10%
25-99 Units.....7%	250 and up...Consult Sales

To Order (Specify Model Number)

Dimensions*	Type	Cold End Termination	Model Number	Price
<p>A = 60 mm (2.36") or 90 mm (3.54") B = 1.5 m (59")</p>	J	1	BTH-M00-J-□-1.5-1	£23.00
	J	2	BTH-M00-J-□-1.5-2	25.50
	K	1	BTH-M00-K-□-1.5-1	23.00
	K	2	BTH-M00-K-□-1.5-2	25.50
	T	1	BTH-M00-T-□-1.5-1	23.00
	T	2	BTH-M00-T-□-1.5-2	25.50
	E	1	BTH-M00-E-□-1.5-1	23.00
	E	2	BTH-M00-E-□-1.5-2	25.50
<p>A = 60 mm (2.36") or 90 mm (3.54") B = 1.5 m (59")</p>	J	1	BTH-M90-J-□-1.5-1	£23.75
	J	2	BTH-M90-J-□-1.5-2	27.00
	K	1	BTH-M90-K-□-1.5-1	23.75
	K	2	BTH-M90-K-□-1.5-2	27.00
	T	1	BTH-M90-T-□-1.5-1	23.75
	T	2	BTH-M90-T-□-1.5-2	27.00
	E	1	BTH-M90-E-□-1.5-1	23.75
	E	2	BTH-M90-E-□-1.5-2	27.00

* Note: Insert 60 or 90mm: Standard "A" Dimension in space (□). Longer "A" lengths available at £0.30/10mm "B" dimensions at 1.5m. For longer "B" lengths change 1.5 to desired length in metres, and add £5.90 per metre to price.

