

# Handheld Digital Thermometers

HH508  
£74



**HH508 Single K/J/E/T/S Input**  
Backlit LCD  
Accepts Type K/J/E/T/S Thermocouple Inputs  
MAX/MIN, AVG, REL, HOLD Functions  
Single Input



HH508, £74, shown smaller than actual size.

- ✓ IP65 Dustproof
- ✓ Water/Splash Resistant
- ✓ Warning Beeper with Hi/Lo Setting, Time Setting
- ✓ Clock and Elapsed Time
- ✓ 0.1° Resolution
- ✓ Differential Thermocouple Input
- ✓ Stated Accuracy @ 23 ± 5°C < 75% RH
- ✓ Battery Life: 200 Hours
- ✓ Dimensions: 192 H x 91 W x 53 mm D
- ✓ Weight: Approx. 255 g

Probes sold separately. Please see Section A for details.

**ALL MODELS AVAILABLE FOR FAST DELIVERY!**

HH509  
£80



**HH509 Dual K/J/E/T/S Input**  
Backlit LCD Display  
Accepts Types K/J/E/T/S Thermocouple Inputs  
MAX/MIN, AVG, REL, HOLD Functions  
Dual Input with Differential Function T1-T2

**HH509R**  
has all the same features as HH509 plus includes RS232 interface, cable, and software.




HH509, £80, shown smaller than actual size.

Specifications	HH508	HH509
Backlit LCD	•	•
No. of Digits	1999	1999
Probe (Type)	K/J/E/T/S	K/J/E/T/S
Input Channel	1	2
Range °C	-210-1767°C	-210-1767°C
Range °F	-346-1999°F	-346-1999°F
Resolution	0.1°/1°	0.1°/1°
Data/Hold	•	•
Max/Min	•	•
Relative	•	•
Hi/Lo Limits w/Beeper Warning	•	•
Display	1	1
T1-T2		•
Battery	9 V	9 V
RS-232C		
Auto Power Off	•	•
Basic Accuracy	0.1% +1°C	0.1% +1°C

## To Order (Specify Model Number)

Model Number	Price	Description
HH508	£74.00	Digital Thermometer
HH509	80.00	Digital Thermometer, Dual
HH509R	87.00	Digital Thermometer, Dual, with RS232
SC-GG-KI-30-1M	10.00	Extra type K beaded thermocouple (1 m long)
KTSS-HH-IEC	19.50	150 mm long, 3 mm dia. stainless steel type K probe with 300 mm retractable cable (expands to 1.2 m) terminating with mini plug
CAL-3-HH	50.00	Traceable calibration certificate
MN1604	2.00	Extra 9 V alkaline battery
SC-HH500	8.00	Soft carrying case

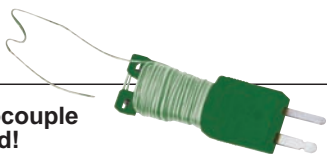

**Thermocouple Included!**

These models include a free 1 m Type K insulated beaded wire thermocouple with subminiature connector and wire spool caddy (one per channel). Order a Spare! Model No. SC-GG-KI-30-1M, £10

