

Stick Type Thermometers and Transducers

HHM60 Series
Starts at
\$60



- ✓ Brand New Series with CE-Mark Approval
- ✓ Highly Accurate Thermometer with Type K Thermocouple (HHM63C/HHM63F/HHM63K)
- ✓ DATA HOLD Function
- ✓ Models with 0.1°, 1° Resolution
- ✓ Auto-Ranging
- ✓ Stick-Type Easy-to-Hold Design
- ✓ Accuracy: Stated Accuracy at 23 ± 5°C <75% RH
- ✓ Battery Life: 200 Hours
- ✓ Dimensions: 170 H x 44 W x 40 mm D (6.7 x 1.8 x 1.6")
- ✓ Weight: Approx 150 g (5 oz)
- ✓ Valox Housing to Withstand Accidental Drops
- ✓ CE Marked

Order an Extra Set!



Accessories for Stick DMMs and Thermometers

Model No.	Price	Description
MN2400	\$3	Extra "AAA" alkaline battery
HHM60-TL	6	Extra set of test leads
CAL-3-HHM	125	NIST-traceable calibration

HHM64, \$69.



HHM64
Stick Type Multimeter
3200 count resolution
Analog bargraph function
Backlit LCD display
DCV accuracy:
0.25%

HHM63, \$86.



HHM63
Stick Type Multimeter
2500 count resolution with
Microprocessor-Based DMM
DCV Accuracy: 0.25%
Resistance accuracy: 0.3%
Backlit LCD display
Frequency accuracy
up to ± 0.05%
Frequency resolution
up to 0.001 Hz


All models shown
slightly smaller than
actual size.

HHM63C/HHM63F, \$102.



HHM63C/HHM63F
Multimeter Thermometer
2500 count resolution with
Microprocessor-Based DMM
DCV accuracy: 0.25%
Resistance accuracy: 0.3%
Backlit LCD display
Frequency accuracy
up to ± 0.05%
Frequency resolution
up to 0.001 Hz
Type K input
Temperature accuracy ± 2%

All Thermocouple Probes Sold Separately See OMEGA's Complete Line of Thermocouple Probes in Section A.

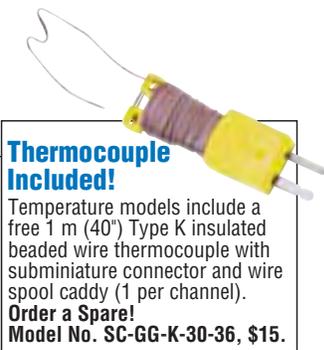

Thermocouple Included!
 Temperature models include a free 1 m (40") Type K insulated beaded wire thermocouple with subminiature connector and wire spool caddy (1 per channel).
Order a Spare!
 Model No. SC-GG-K-30-36, \$15.

Stick Type Temperature Transducer† (no display)

\$60

HH63KF-MV
 (°F measurement)
HH63KC-MV
 (°C measurement)

**HH63KF-MV/
 HH63KC-MV
 Temperature Transducer**
 Comes with Type K thermocouple, green LED power-on, annunciator, overload protection;
Accuracy: 0.3% rdg
 1 mV/deg analog output for temperature; connects to any DMM for display

Shown smaller than actual size.



†For Display, Plug Unit into any OMEGA® HHM Series Multimeter. Consult Manual for Instructions.

Stick Type Thermometer

\$80

HH63K

HH63K Stick Type Thermometer
 3½ digits 2000 counts leading of maximum, data hold, function overload protection
 24 Vac/Vdc
Accuracy: up to ±0.3% °C/°F switchable

Shown smaller than actual size.



Comes with beaded Type K thermocouple
 0.1/1.0° resolution

MOST POPULAR MODELS HIGHLIGHTED!

To Order (Specify Model Number)								
	Model No.	HHM64	HHM63C	HHM63F	HHM63	HH63KF-MV	HH63KC-MV	HH63K
	Price	\$69	\$102	\$102	\$86	\$60	\$60	\$80
	Resolution (Counts)	3200	2500	2500	2500	2000	2000	2000
F E A T U R E S	Range Auto	•	•	•	•			
	Input Impedance MΩ	>10	>10	>10	>10			
	Analog Bargraph	•						
	Analog Output					1 mv/F°	1 mv/C°	
	Range °C		-20~1370				-50~1300°	-50~1300
	Range °F			-4~2498		-58~2372		-58~2000
	Backlit LCD	•	•	•	•			
	Data Hold	•	•	•	•			•
	Capacitance		25 µF	25 µF	25 µF			
	Frequency		5 MHz	5 MHz	5 MHz			
Vdc/Vac-Autoranging	600	600	600	600				
Continuity	•	•	•	•				
Resistance	•	25 MΩ	25 MΩ	25 MΩ				
Diode Test	•	•	•	•				
DCV Ω	Basic Accuracy, %	0.25	0.25	0.25	0.25			
	Basic Accuracy, %	0.3	0.3	0.3	0.3			

Comes with soft vinyl carrying case, 4 "AAA" alkaline batteries, set of safety test leads, Type K beaded wire thermocouple (temperature models only) and complete operator's manual.
Ordering Example: HH63K, stick thermometer with beaded wire thermocouple, \$80.



omega.co.uk[®]

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

www.omega.co.uk



UNITED STATES

www.omega.com

1-800-TC-OMEGA
Stamford, CT.

UNITED KINGDOM

www.omega.co.uk

Manchester, England
0800-488-488
+44-(0)161-777-6611

CANADA

www.omega.ca

Laval(Quebec)
1-800-TC-OMEGA

FRANCE

www.omega.fr

0800-466-342

GERMANY

www.omega.de

Deckenfronn, Germany
0800-8266342

BENELUX

www.omega.nl

0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485, Ethernet and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters