



Quick Disconnect Thermocouple Probe Assemblies with High Temperature Miniature Connectors

- ✓ Environmentally Friendly Cadmium-Free Liquid Crystal Polymer
- ✓ Miniature Probes with Sheath Diameters from 0.25 to 3mm
- ✓ 150 and 300mm Lengths †
- ✓ 304, 321SS, Super OMEGA CLAD™ XL and Inconel Sheaths, with Grounded, Ungrounded or Exposed Junction
- ✓ Terminations are Colour-Coded and Identified with Calibration Letter Code
- ✓ Quick Disconnect Probes Supplied with Mating Connector and Cable Clamp
- ✓ Made with Class 1 (Special Limits of Error) Material

Models Highlighted have SUPEROMEGA CLAD™ XL Sheaths! See Page A-84 for Details

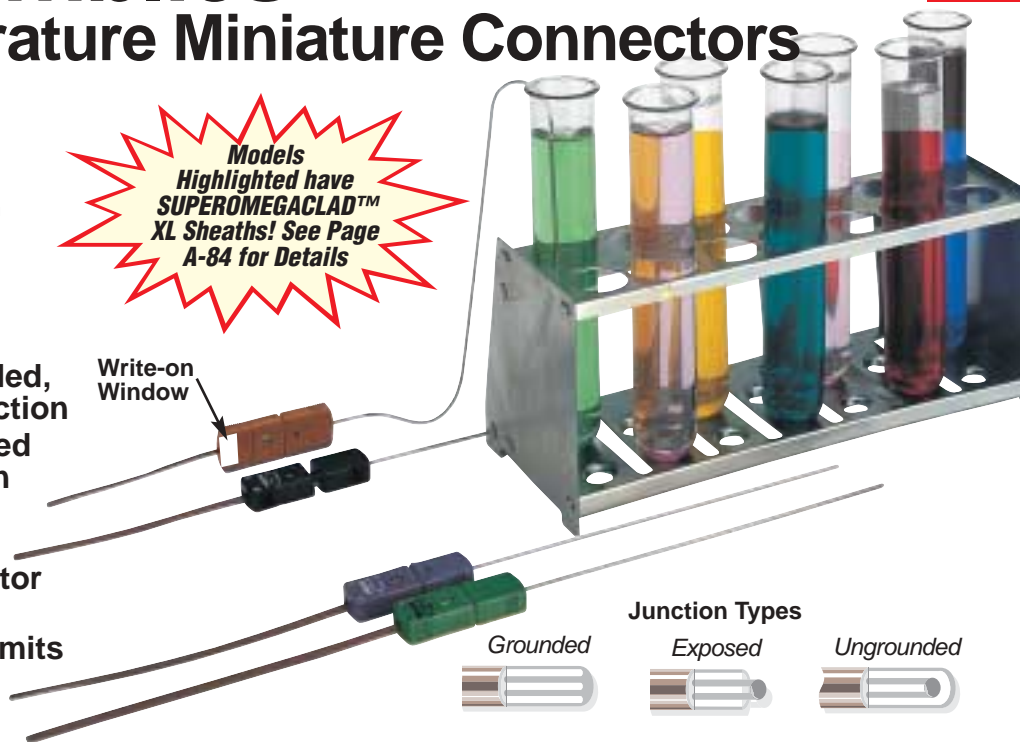

ALL MODELS IN STOCK FOR FAST DELIVERY!

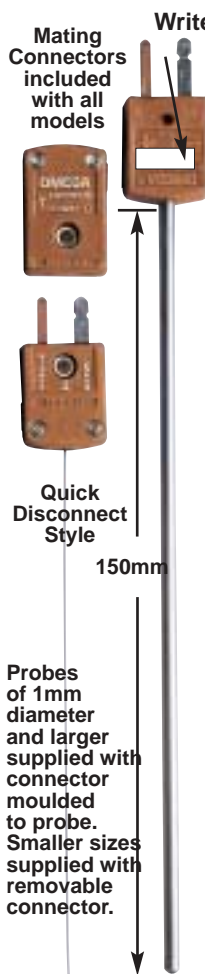

To Order (Specify Model Number)									
Thermocouple Alloy	Sheath Dia. mm	Model Number 150mm Length	Price		Model Number 300mm Length	Price		Price per add'l 150mm	
			G/E	U		G/E	U		
IRON-CONSTANTAN 304 SS Sheath	0.25	HJMQSS-M025(*)-150	£42.00	£58.00	HJMQSS-M025(*)-300	£43.00	£59.00	£1.05	
	0.50	HJMQSS-M050(*)-150	25.50	27.00	HJMQSS-M050(*)-300	26.00	27.50	0.55	
	0.75	HJMQSS-M075(*)-150	25.50	27.00	HJMQSS-M075(*)-300	26.00	27.50	0.55	
	1.0	HJMQSS-M100(*)-150	25.50	27.00	HJMQSS-M100(*)-300	26.00	27.50	0.55	
	1.5	HJMQSS-M150(*)-150	22.25	23.75	HJMQSS-M150(*)-300	22.75	24.50	0.65	
3.0	HJMQSS-M300(*)-150	22.25	23.75	HJMQSS-M300(*)-300	23.00	24.50	0.80		
CHROMEGLA™-ALOMEGA™ 304 SS Sheath	0.25	HKMQSS-M025(*)-150	42.00	58.00	HKMQSS-M025(*)-300	43.00	59.00	1.05	
	0.50	HKMQSS-M050(*)-150	25.50	27.00	HKMQSS-M050(*)-300	26.00	27.50	0.55	
	0.75	HKMQSS-M075(*)-150	25.50	27.00	HKMQSS-M075(*)-300	26.00	27.50	0.55	
	1.0	HKMQSS-M100(*)-150	25.50	27.00	HKMQSS-M100(*)-300	26.00	27.50	0.55	
	1.5	HKMQSS-M150(*)-150	22.25	23.75	HKMQSS-M150(*)-300	22.75	24.50	0.65	
3.0	HKMQSS-M300(*)-150	22.25	23.75	HKMQSS-M300(*)-300	23.00	24.50	0.80		
CHROMEGLA™-ALOMEGA™ Super OMEGA CLAD™ XL Sheath	0.50	HKMQXL-M050(*)-150	28.00	29.50	HKMQXL-M050(*)-300	28.50	30.00	0.55	
	0.75	HKMQXL-M075(*)-150	28.00	29.50	HKMQXL-M075(*)-300	28.50	30.00	0.55	
	1.0	HKMQXL-M100(*)-150	28.00	29.50	HKMQXL-M100(*)-300	28.50	30.00	0.55	
	1.5	HKMQXL-M150(*)-150	24.50	26.00	HKMQXL-M150(*)-300	25.50	27.00	0.70	
	3.0	HKMQXL-M300(*)-150	24.50	26.00	HKMQXL-M300(*)-300	25.50	27.00	1.45	
OMEGA-P™-OMEGA-N™ Super OMEGA CLAD™ XL Sheath	0.50	HNMQXL-M050(*)-150	28.00	29.50	HNMQXL-M050(*)-300	28.50	30.00	0.55	
	0.75	HNMQXL-M075(*)-150	28.00	29.50	HNMQXL-M075(*)-300	28.50	30.00	0.55	
	1.0	HNMQXL-M100(*)-150	28.00	29.50	HNMQXL-M100(*)-300	28.50	30.00	0.55	
	1.5	HNMQXL-M150(*)-150	24.50	26.00	HNMQXL-M150(*)-300	25.50	27.00	0.70	
	3.0	HNMQXL-M300(*)-150	24.50	26.00	HNMQXL-M300(*)-300	25.50	27.00	1.45	
CHROMEGLA™-CONSTANTAN 304 SS Sheath	0.25	HEMQSS-M025(*)-150	42.00	58.00	HEMQSS-M025(*)-300	43.00	59.00	1.05	
	0.50	HEMQSS-M050(*)-150	25.50	27.00	HEMQSS-M050(*)-300	26.00	27.50	0.55	
	0.75	HEMQSS-M075(*)-150	25.50	27.00	HEMQSS-M075(*)-300	26.00	27.50	0.55	
	1.0	HEMQSS-M100(*)-150	25.50	27.00	HEMQSS-M100(*)-300	26.00	27.50	0.55	
	1.5	HEMQSS-M150(*)-150	22.25	23.75	HEMQSS-M150(*)-300	22.75	24.50	0.65	
3.0	HEMQSS-M300(*)-150	22.25	23.75	HEMQSS-M300(*)-300	23.00	24.50	0.80		
COPPER-CONSTANTAN 304 SS Sheath	0.50	HTMQSS-M050(*)-150	25.50	27.00	HTMQSS-M050(*)-300	26.00	27.50	0.55	
	0.75	HTMQSS-M075(*)-150	25.50	27.00	HTMQSS-M075(*)-300	26.00	27.50	0.55	
	1.0	HTMQSS-M100(*)-150	25.50	27.00	HTMQSS-M100(*)-300	26.00	27.50	0.55	
	1.5	HTMQSS-M150(*)-150	22.25	23.75	HTMQSS-M150(*)-300	22.75	24.50	0.65	
	3.0	HTMQSS-M300(*)-150	22.25	23.75	HTMQSS-M300(*)-300	23.00	24.50	0.80	

*Specify junction type: G (Grounded), E (Exposed) or U (Ungrounded) †Other lengths available, consult Sales Department
 To Order with Inconel Sheath, change 'SS' in model number to 'IN'. Example: HKMQIN-M100G-150. No additional charge.
 To Order with 321 SS Sheath, change 'SS' in model number to '321SS'. Example: HKMQ321SS-M150E-300. No additional charge.
 Ordering Example: HKMQSS-M075G-150-FT, subminiature quick disconnect probe, type K, stainless steel sheath, 0.75mm O.D., grounded junction, 150mm long, with integral ferrite core in male connector, £25.50 + 3.30 = £28.80