


# Glass Insulated High Temperature Heater Hook-Up Wire



**CAUTION AND WARNING!**  
Fire and electrical shock may result if products are used improperly or installed or used by nonqualified personnel. See inside back cover for additional warnings.

## HTGG Series

- ✓ 250°C (482°F) Temperature Rating
- ✓ UL & CSA Certified
- ✓ Single Stranded "A" Nickel Conductor
- ✓ Glass Insulation with Treated Glass Overbraid
- ✓ Ideal for Applications Where Outgassing May Be a Problem
- ✓ Treated Glass Braid

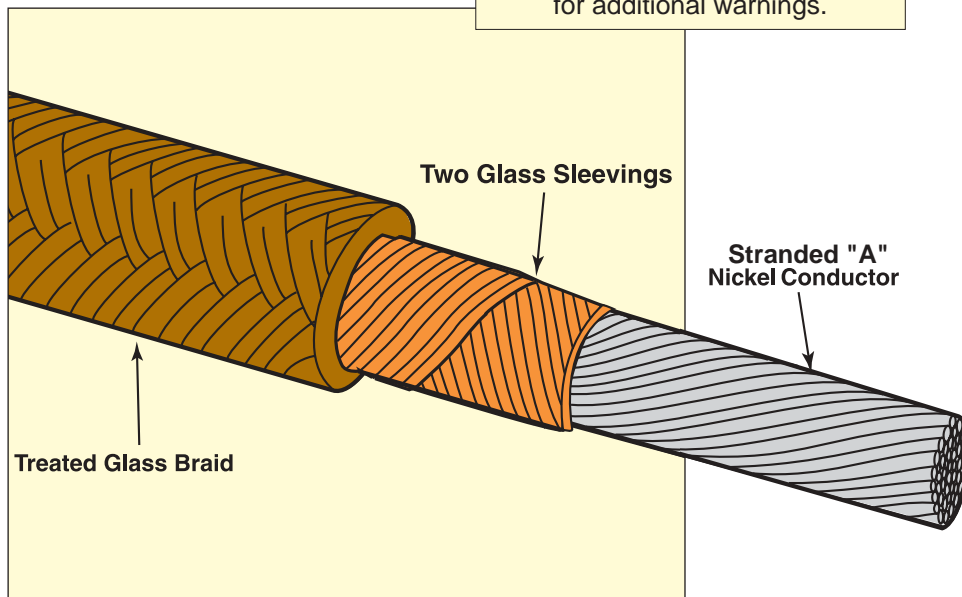

Discount Schedule	
15 to 29m .....	20%
30 to 59m .....	30%
60 to 149m .....	40%
150m and up .....	60%

Additional Heater Hook-up Wire is shown in the OMEGALUX Complete Electric Heaters Handbook & Encyclopedia™ and also online at: [www.omega.co.uk](http://www.omega.co.uk)

HTGG high-temperature lead wire is specifically engineered for cartridge, band and strip heaters in 250°C (482°F) applications where outgassing may be a problem. This product is also commonly used in higher temperature applications.

## MOST POPULAR MODELS HIGHLIGHTED!

## ALL MODELS STOCKED FOR FAST DELIVERY!

To Order (Specify Model Number)						
Gauge	Model No.	Type Price/Metre	Stranded	Volts	NOM OD,mm ± 1.5mm (in ± .006")	Approx. Wt. Kg/300m (lb/1000 ft)
22	HTGG-1NI-322S/C	£2.80	7 x 30	300	2.24 (.088)	3.4 (7.5)
20	HTGG-1NI-320S/C	3.10	10 x 30	300	2.38 (.094)	4.1 (9.0)
18	HTGG-1NI-318S/C	3.90	16 x 30	300	2.61 (.103)	5.2 (11.5)
16	HTGG-1NI-316S/C	5.50	26 x 30	300	2.84 (.112)	7.0 (15.5)
14	HTGG-1NI-314S/C	8.40	41 x 30	300	3.23 (.127)	11.8 (26.0)
12	HTGG-1NI-312S/C	12.00	65 x 30	300	3.68 (.145)	16.3 (36.0)
10	HTGG-1NI-310S/C	18.25	105 x 30	300	4.62 (.182)	23.4 (51.5)

Standard colour natural (off-white)

Ordering Example: HTGG-1NI-322S/C, a 15 metre spool of 22 gauge stranded wire, £2.80 x 15 - 20% = £33.60  
See Heater Hook-up Wire Introduction for current carrying capacity and derating.

