

Standard Conduit Box Connector Systems

JPCB

- ✓ Quick Disconnect
- ✓ Color-Coded
- ✓ 5 Standard Rectangular Connectors or 6 Round Connector Terminals
- ✓ 3-Prong Models Also Available
- ✓ Quick Release Snap Action Handle
- ✓ 3/4 NPT Fittings




JPCB-5-K-F.

JPCB-5-K-M.

To Order Visit omega.com/jpcb_tjpcb_rjpcb for Pricing and Details

Model No.	Description
JPCB-5(*)-M	5-circuit standard conduit box, male
JPCB-5(*)-F	5-circuit standard conduit box, female
JPCB-5(*)-MF	5-circuit standard conduit box, male/female pair
TJPCB-4(*)-M	4-circuit 3-prong conduit box, male
TJPCB-4(*)-F	4-circuit 3-prong conduit box, female
TJPCB-4(*)-MF	4-circuit 3-prong conduit box, male/female pair
RJPCB-6(*)-M	6-circuit round connector conduit box, male
RJPCB-6(*)-F	6-circuit round connector conduit box, female
RJPCB-6(*)-MF	6-circuit round connector conduit box, male/female pair

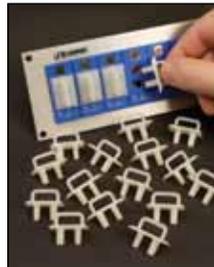

Supply of standard size SPJ-CAP-12 package of 12 Wire and cable clamp (JB-CC) sold separately.



Wire and cable clamp (JB-CC) sold separately.


All models shown smaller than actual size.

*Specify Calibration: J, K, T, E, R/S or U, ANSI color coded.

Ordering Example: JPCB-5-K-MF, 5-circuit junction box, Type K, male/female pair.

Miniature Conduit Box Connector Systems

- ✓ 3/4 NPT Fittings
- ✓ Quick Disconnect Miniature Connectors
- ✓ Color-Coded
- ✓ Up to 6 Positions Available
- ✓ Straight, Right Hand, Left Hand and Butt End Configurations

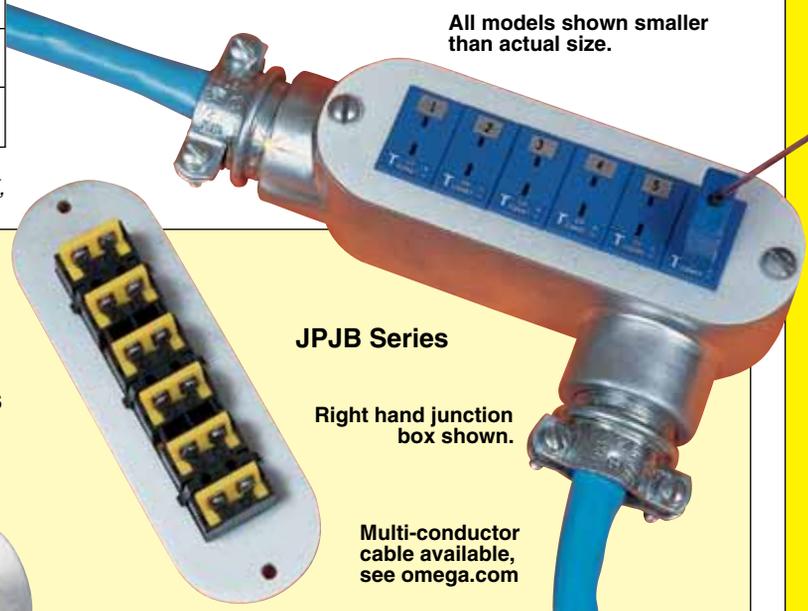

JPJB Series

Right hand junction box shown.

Multi-conductor cable available, see omega.com

JPJB-6-K-ST.



Dust Cap

Supply of our miniature design MPJ-CAP-12, package of 12, see omega.com

Model No.	Description
JPJB-(†)-(*)-ST	Junction box, straight
JPJB-(†)-(*)-RH	Junction box, right hand
JPJB-(†)-(*)-LH	Junction box, left hand
JPJB-(†)-(*)-BE	Junction box, butt end

† Specify number of positions, 1, 2, 3, 4, 5 or 6.

* Specify Calibration: J, K, T, E, R/S, N or U.

Ordering Example: JPJB-5-T-RH, 5-position junction box, Type T, right hand configuration.

omega.co.uk®

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

www.omega.co.uk



UNITED STATES

www.omega.com

1-800-TC-OMEGA
Stamford, CT.

UNITED KINGDOM

www.omega.co.uk

Manchester, England
0800-488-488
+44-(0)161-777-6611

CANADA

www.omega.ca

Laval(Quebec)
1-800-TC-OMEGA

FRANCE

www.omega.fr

0800-466-342

GERMANY

www.omega.de

Deckenfronn, Germany
0800-8266342

BENELUX

www.omega.nl

0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485, Ethernet and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters