


Tubular Thermistor Sensors For Immersion Temperature Measurements



ON-403-PP
\$70

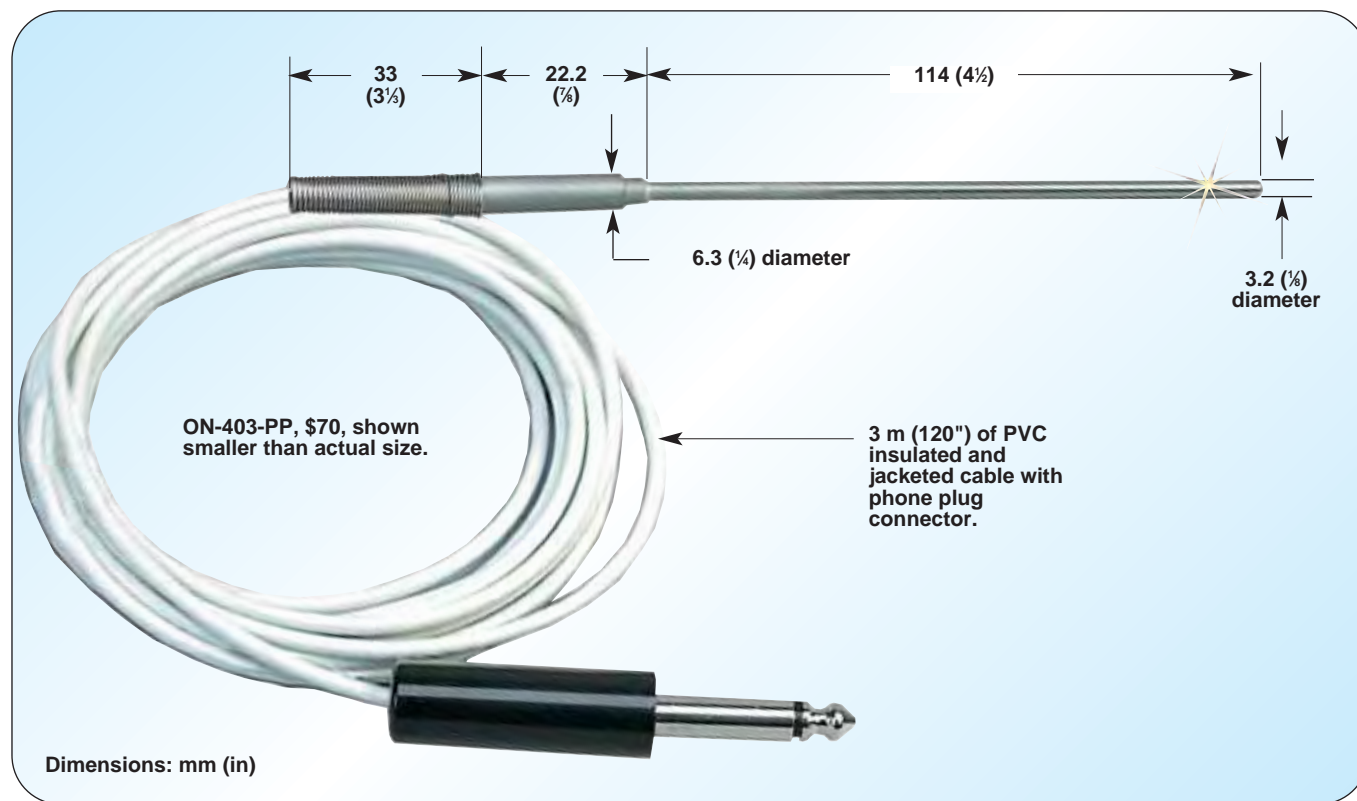

- ✓ 300 Series Stainless Steel Probe for Rugged-Duty Liquid Immersion Use
- ✓ Probe is Immersible to End of Transition
- ✓ Provided with 3 m (120") of PVC Cable and Phone Plug Connector

AVAILABLE FOR FAST DELIVERY!

To Order (Specify Model Number)				
Model Number	Price	Resistance @ 25°C	Interchangeability @ 0 to 70°C	Cable Termination
ON-403-PP	\$70	2252 Ω @ 25°C	±0.1°C	Phone plug

Notes: For additional cable length, add required length (in inches) to end of the model number and **\$0.80/ft** to the price.

Ordering Examples: **ON-403-PP**, tubular stainless steel immersion thermistor sensor, 2252 Ω at 25°C, interchangeability is ±0.1°C, 3 m (120") of PVC insulated and jacketed cable and phone plug connector, **\$70**. **ON-403-PP-240**, tubular stainless steel immersion thermistor sensor, 2252 Ω at 25°C, interchangeability is ±0.1°C, 6 m (240") of PVC insulated and jacketed cable with phone plug, \$70 + (10 x \$0.80) = **\$78**.

Accessories

Model Number	Price	Description
450-ATH	\$295	Handheld thermometer, thermistor input
HH41	400	Handheld thermistor thermometer
HH42	480	Handheld thermistor thermometer with RS232 communications
SSLK-14-18	8	1/4" tube OD, 1/8" NPT, 316 SS compression fitting

omega.co.uk[®]

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

www.omega.co.uk



UNITED STATES

www.omega.com

1-800-TC-OMEGA
Stamford, CT.

CANADA

www.omega.ca

Laval(Quebec)
1-800-TC-OMEGA

GERMANY

www.omega.de

Deckenfronn, Germany
0800-8266342

UNITED KINGDOM

www.omega.co.uk

Manchester, England
0800-488-488
+44-(0)161-777-6611

FRANCE

www.omega.fr

0800-466-342

BENELUX

www.omega.nl

0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485, Ethernet and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters