

OMEGALUX[®] Indicators

Phase Sequence Indicator

Checks 3-Phase Wiring for "ABC" or "BAC" Hookup

PHSEQ
\$90



Insulated test leads included.

The OMEGALUX[®] PHSEQ connects to any 3-phase circuit from 115 to 700 V. The test leads follow an easy-to-remember red, white, and blue "ABC" color code. Proper phase sequence will illuminate the "ABC" lamp. A reversed sequence will illuminate the "BAC" lamp, and an open-phase condition will illuminate both lamps.

- ✓ Covers Range from 115 to 700 V
- ✓ Auto-Ranging
- ✓ Rugged, Solid State Design

Specifications

Voltage: 115 to 700 V, 50/60 Hz
Dimensions: 31.75 x 38.1 x 50.8 mm (1½ x 1½ x 2")
Leads: 60.96 cm (24") length with alligator clip termination
Weight: 113 g (4 oz)

AVAILABLE FOR FAST DELIVERY!

To Order (Specify Model No.)

Model No.	Price	Description
PHSEQ	\$90	Phase sequence indicator
SC-450S	10	Optional carrying case

Ordering Example: PHSEQ, phase sequence indicator, with SC-450S carrying case, \$90 + 10 = \$100.

Motor Rotation Indicator

Determines Correct Power Connection for Clockwise or Counter-Clockwise Motor Rotation

MTR-1
All Models
\$90




- ✓ Gives Proper Connection Sequence
- ✓ No External Power Required
- ✓ Solid State Construction

The MTR-1 works on any single or multiple 3-phase motor installation and allows all motors in a multiple installation to run in the proper direction without trial and error. Open windings or demagnetized windings can also be identified using the MTR-1.

Specifications

Size: 53.97 x 82.55 x 28.57 mm (2.125 x 3.25 x 1.125")
Leads: 609 mm (24") length with alligator clip termination
Power: 9 V battery
Battery Life: 20 hours
Weight: 113 g (4 oz)

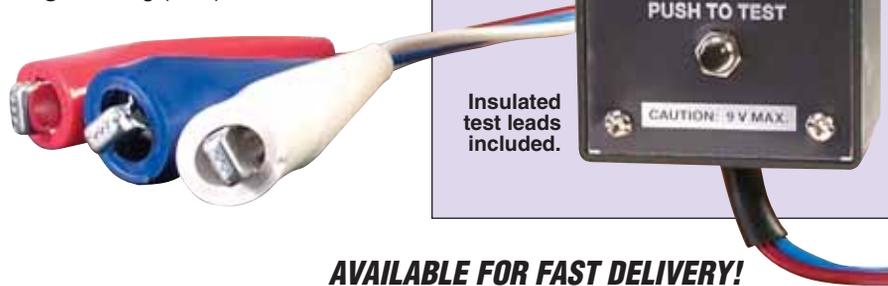

Insulated test leads included.

AVAILABLE FOR FAST DELIVERY!

To Order (Specify Model Number)

Model No.	Price	Description
MTR-1	\$90	Motor rotation indicator
SC-450S	10	Optional carrying case

Ordering Example: MTR-1, motor rotation indicator, \$90. SC-450S, optional carrying case, \$10, \$90 + 10 = \$100.

omega.co.uk[®]

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

www.omega.co.uk



UNITED STATES

www.omega.com

1-800-TC-OMEGA
Stamford, CT.

UNITED KINGDOM

www.omega.co.uk

Manchester, England
0800-488-488
+44-(0)161-777-6611

CANADA

www.omega.ca

Laval(Quebec)
1-800-TC-OMEGA

FRANCE

www.omega.fr

0800-466-342

GERMANY

www.omega.de

Deckenfronn, Germany
0800-8266342

BENELUX

www.omega.nl

0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485, Ethernet and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters