




# CUT TO LENGTH RTD FOR FIELD ADAPTABLE APPLICATIONS

PRCTL Series  
Starts at  
**\$55**



- Field Cuttable to the Length Needed Using a Tubing Cutter (3" Length Minimum)
- Available in 100 Ω DIN Platinum Class "A" or Class "B" Standard
- 3-Wire Configuration Standard, 4-Wire Available
- All Sensors Supplied with IEC60751/ASTM E-1137 Color Codes
- ¼, ⅜, 6 and 4.5 mm Diameters Standard
- PFA Insulated Lead Wires
- Temperature Range: -200 to 260°C

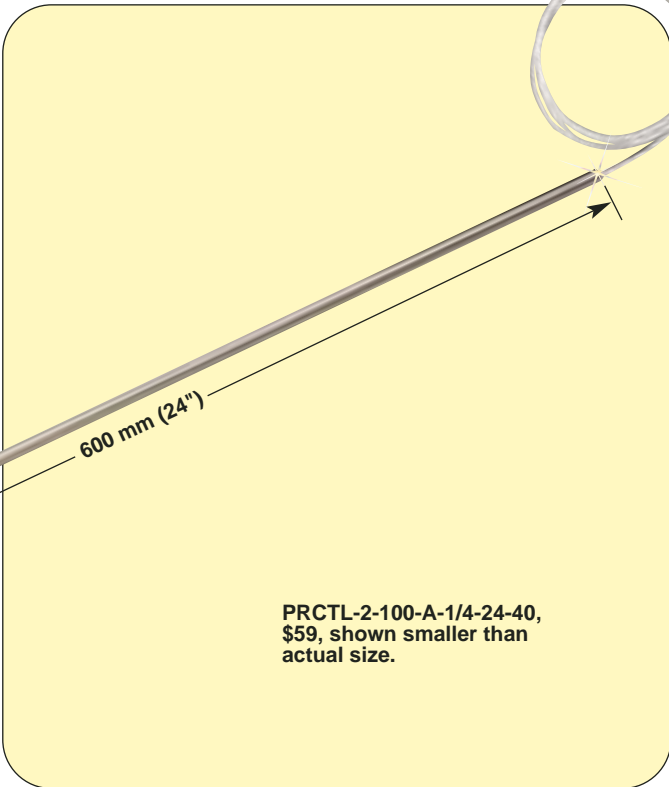

## Standard Dimensions

To Order (Specify Model Number)			MOST POPULAR MODELS HIGHLIGHTED!			
MODEL NO.	RESISTANCE AT 0°C	SHEATH DIAMETER	SENSOR LENGTH	NO. OF WIRES	WIRE LENGTH	PRICE
PRCTL-2-100-A-1/4-24-40	100 Ω, Class A	¼"	24"	3	40"	\$59
PRCTL-2-100-A-3/16-24-40	100 Ω, Class A	⅜"	24"	3	40"	\$59
PRCTL-2-100-B-1/4-24-40	100 Ω, Class B	¼"	24"	3	40"	\$55
PRCTL-2-100-B-3/16-24-40	100 Ω, Class B	⅜"	24"	3	40"	\$55

**Options:** For 4 wire configuration change "2" to "3" in the model number. For sheath lengths greater than 24" change model number to length desired and add \$1 per inch to the price. For wire lengths greater than 40", change model number to length desired and add \$1 per foot to the price.

**Ordering Examples:** PRCTL-2-100-B-1/4-24-40, ¼" diameter x 24" long sheath with 3 wires 40" long, 100 Ω Class "B" platinum RTD, \$55. PRCTL-2-100-A-3/16-36-40, ⅜" diameter x 36" long sheath with 3 wires 80" long, 100 Ω Class "A" platinum RTD, \$59.

## Metric Dimensions

To Order (Specify Model Number)			MOST POPULAR MODELS HIGHLIGHTED!			
MODEL NO.	RESISTANCE AT 0°C	SHEATH DIAMETER	SENSOR LENGTH	NO. OF WIRES	WIRE LENGTH	PRICE
PRCTL-2-100-A-M6-600-1	100 Ω, Class A	6 mm	600 mm	3	1 m	\$59
PRCTL-2-100-A-M4.5-600-1	100 Ω, Class A	4.5 mm	600 mm	3	1 m	\$59
PRCTL-2-100-B-M6-600-1	100 Ω, Class B	6 mm	600 mm	3	1 m	\$55
PRCTL-2-100-B-M4.5-600-1	100 Ω, Class B	4.5 mm	600 mm	3	1 m	\$55

**Options:** For 4 wire configuration change "2" to "3" in the model number. For sheath lengths greater than 24" change model number to length desired and add \$1 per inch to the price. For wire lengths greater than 40", change model number to length desired and add \$1 per foot to the price.

**Ordering Examples:** PRCTL-2-100-B-M6-600-1, 600 mm diameter x 600 mm long sheath with 3 wires 1 m long, 100 Ω Class "B" platinum RTD, \$55. PRCTL-2-100-A-M4.5-600-1, 4.5 mm diameter x 600 mm long sheath with 3 wires 1 m long, 100 Ω Class "A" platinum RTD, \$59.

# omega.co.uk<sup>®</sup>

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

[www.omega.co.uk](http://www.omega.co.uk)



#### UNITED STATES

[www.omega.com](http://www.omega.com)

1-800-TC-OMEGA  
Stamford, CT.

#### UNITED KINGDOM

[www.omega.co.uk](http://www.omega.co.uk)

Manchester, England  
0800-488-488  
+44-(0)161-777-6611

#### CANADA

[www.omega.ca](http://www.omega.ca)

Laval(Quebec)  
1-800-TC-OMEGA

#### FRANCE

[www.omega.fr](http://www.omega.fr)

0800-466-342

#### GERMANY

[www.omega.de](http://www.omega.de)

Deckenfronn, Germany  
0800-8266342

#### BENELUX

[www.omega.nl](http://www.omega.nl)

0800-099-33-44



## More than 100,000 Products Available!

### • Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

### • Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

### • pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

### • Data Acquisition

Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485, Ethernet and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

### • Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

### • Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters