

Thermocouple Terminals

Barrier Strip Jackets

- ✓ Color-Coded to Calibration Type
- ✓ Complete with Calibration Type Terminal Lugs Installed, pkg of 6 (Order Below)
- ✓ Combination Phillips/Slot Screws
- ✓ Spade Lugs Accept Wire from 24 AWG to 16 AWG

Material: Glass filled nylon


Temperature Rating: 220°C (425°F)

BSJ-(**), barrier strip jackets, package of 6 (up to 12 channels), shown actual size.

We make running changes when technical advances allow. Check at time of ordering for additional features.

SL(*)-20 spade lugs, package of 20

TL(*)-20 terminal lugs, package of 20

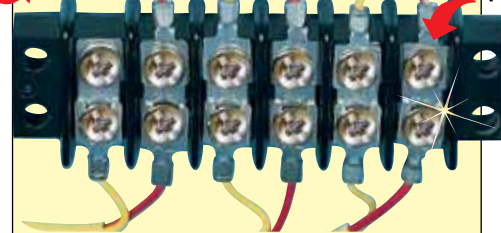

TL(*)-20 terminal lugs, package of 20

Crimping Tool


Easy-to-Use Ratchet Action

To attach the thermocouple spade lugs to your thermocouple wire. Operates on a ratchet principle to assure a complete crimp every time.

Ordering Example: CRIMPING TOOL

For Our Complete Line of Thermocouple Terminals Visit:
omega.com/tclugs

G

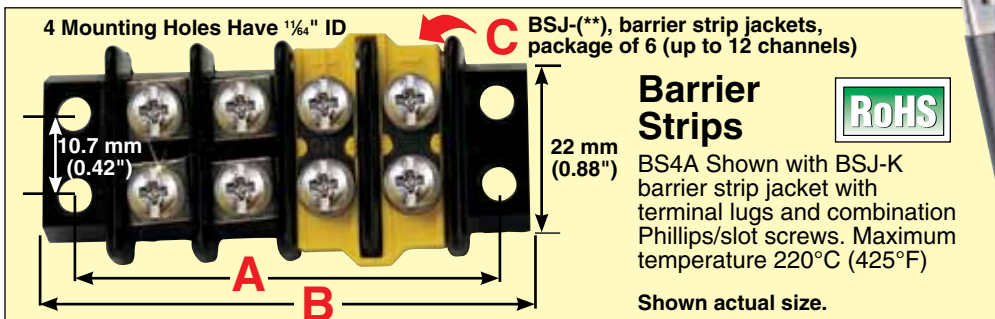

Alloy Types

Order Code	Thermocouple Alloy
CH	CHROMEGA®
AL	ALOMEGA®
IR	Iron
CO	Constantan
CP	Copper (also R/S positive lead)
11	Type R negative compensating lead
405	Type C positive compensating lead
426	Type C negative compensating lead
203	Type D positive compensating lead
225	Type D negative compensating lead
200	Type G positive compensating lead
226	Type G negative compensating lead

Now Available Type N (OMEGALLOY®)

OMEGALLOY®	OMEGA-P®	OMEGA-N®
Spade lug	SLNP-20	SLNN-20
Terminal lug	TLNP-20	TLNN-20

Number of Terminals	Dimensions mm (inch)		Model Number
	A	B	
2	33.34 (1.31)	41.28 (1.63)	BS2A
3	44.45 (1.75)	52.39 (2.06)	BS3A
4	55.55 (2.19)	63.50 (2.50)	BS4A
5	66.80 (2.63)	74.60 (2.94)	BS5A
6	77.79 (3.06)	85.73 (3.38)	BS6A
8	100.08 (3.94)	107.95 (4.25)	BS8A
10	122.24 (4.82)	130.18 (5.13)	BS10A
12	144.47 (5.69)	152.40 (6.00)	BS12A
16	188.92 (7.44)	196.85 (7.75)	BS16A
20	244.48 (9.63)	252.42 (9.94)	BS20A

Note: Terminal lugs and spade lugs sold separately.

Terminal Lugs and Spade Lugs

To Order		
Key	Model No.	Description
A	TL(*)-20	Terminal lugs, package of 20
B	SL(*)-20	Spade lugs, package of 20 (not available for C, D, and G calibrations)
C	BSJ-(**)	Barrier strip jacket with terminal lugs (package of 6 for up to 12 channels)

* Specify alloy type from chart above.

** Specify calibration: J, K, T, E, R/S, U or N.

Ordering Example: TLCH-20, terminal lugs, CHROMEGA®, pkg of 20.

omega.co.uk®

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

www.omega.co.uk



UNITED STATES

www.omega.com

1-800-TC-OMEGA
Stamford, CT.

CANADA

www.omega.ca

Laval(Quebec)
1-800-TC-OMEGA

GERMANY

www.omega.de

Deckenpfronn, Germany
0800-8266342

UNITED KINGDOM

www.omega.co.uk

Manchester, England
0800-488-488
+44-(0)161-777-6611

FRANCE

www.omega.fr

0800-466-342

BENELUX

www.omega.nl

0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers, Plug-in Cards, Signal Conditioners, USB, RS232, RS485, Ethernet and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters